

ソリッドエンドミル

MP4EC

NEW

4枚刃エムエスプラス自動旋盤用エンドミル



DC<6

DC≥6

炭素鋼・合金鋼・鋳鉄 (<30HRC)	工具鋼・プリハードン鋼・高硬度鋼 (≤45HRC)	高硬度鋼 (≤55HRC)	高硬度鋼 (>55HRC)	オーステナイト系 ステンレス鋼	チタン合金 耐熱合金	銅合金	アルミニウム合金
○	○	○		○	○	○	

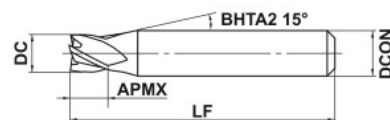


図1

 


図2

 


図3



3 ≤ DC ≤ 12	DC=14			
- 0.010	- 0.010			
- 0.030	- 0.040			
4 ≤ DCON ≤ 6	7 ≤ DCON ≤ 10	DCON=12		
0	0	0		
- 0.008	- 0.009	- 0.011		

●4枚刃スクエアタイプ

(mm)

呼び記号	DC	APMX	LF	DCON	刃数	在庫	図
MP4ECD0300S04	3	4.5	50	4	4	●	1
MP4ECD0350S04	3.5	5	50	4	4	●	1
MP4ECD0400S04	4	6	50	4	4	●	2
MP4ECD0500S06	5	7.5	50	6	4	●	1
MP4ECD0600S06	6	9	50	6	4	●	2
MP4ECD0700S07	7	10.5	50	7	4	●	2
MP4ECD0800S07	8	12	50	7	4	●	3
MP4ECD0800S08	8	12	50	8	4	●	2
MP4ECD0900S10	9	13.5	50	10	4	●	1
MP4ECD1000S07	10	15	50	7	4	●	3
MP4ECD1000S10	10	15	50	10	4	●	2
MP4ECD1200S10	12	15	50	10	4	●	3
MP4ECD1200S12	12	15	50	12	4	●	2
MP4ECD1400S10	14	15	50	10	4	●	3

●：標準在庫品

製品NEWSはこちらから▶



ISO13399

▶ J002