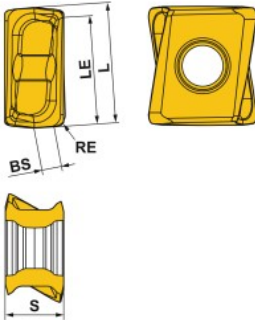
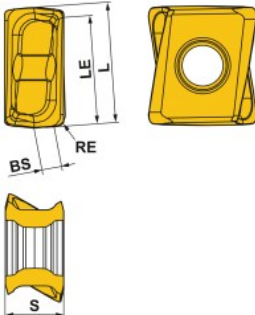


VPX200 深切込み用長刃形を含む

インサート

被削材	P	銅												切削状態(目安)： ●：安定切削 ●：一般切削 ★：不安定切削
	M	ステンレス鋼												
	N <th>非鉄金属</th> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <th>ホーニング： E：丸ホーニング F：シャープエッジ</th>	非鉄金属												ホーニング： E：丸ホーニング F：シャープエッジ
	S <th>耐熱合金、チタン合金</th> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td>	耐熱合金、チタン合金												
	H <th>高硬度鋼</th> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td>	高硬度鋼												

インサート 外観	呼 び 記 号	精度	ホー ニ ン グ	コーティング								超硬	寸法(mm)					形 状
				NEW MV1020★	MC5020	MP6120	MP6130	MP7130	MP9120	MP9130	VP15TF	TF15	L	RE	LE	S	BS	
	LOGU0904020PNER-L	G E	●	●	●	●	●	●	●	●			8.7	0.2	7.6	4.3	1.7	 規格は右勝手(R)のみです。
	LOGU0904040PNER-L	G E	●	●	●	●	●	●	●	●			8.7	0.4	7.6	4.3	1.5	
	LOGU0904080PNER-L	G E	●	●	●	●	●	●	●	●			8.7	0.8	7.6	4.3	1.2	
	LOGU0904100PNER-L	G E	●	●	●	●	●	●	●	●			8.7	1.0	7.6	4.3	1.0	
	LOGU0904120PNER-L	G E	●	●	●	●	●	●	●	●			8.7	1.2	7.6	4.3	0.8	
	LOGU0904160PNER-L	G E	●	●	●	●	●	●	●	●			8.7	1.6	7.6	4.3	0.5	
	LOGU0904020PNFR-L	G F									●		8.7	0.2	7.6	4.3	1.7	
	LOGU0904040PNFR-L	G F									●		8.7	0.4	7.6	4.3	1.5	
	LOGU0904080PNFR-L	G F									●		8.7	0.8	7.6	4.3	1.2	
	LOGU0904100PNFR-L	G F									●		8.7	1.0	7.6	4.3	1.0	
	LOGU0904120PNFR-L	G F									●		8.7	1.2	7.6	4.3	0.8	
	LOGU0904160PNFR-L	G F									●		8.7	1.6	7.6	4.3	0.5	
	LOGU0904020PNER-M	G E	●	●	●	●	●	●	●	●			8.7	0.2	7.6	4.3	1.7	 規格は右勝手(R)のみです。
	LOGU0904040PNER-M	G E	●	●	●	●	●	●	●	●			8.7	0.4	7.6	4.3	1.6	
	LOGU0904080PNER-M	G E	●	●	●	●	●	●	●	●			8.7	0.8	7.6	4.3	1.2	
	LOGU0904100PNER-M	G E	●	●	●	●	●	●	●	●			8.7	1.0	7.6	4.3	1.0	
	LOGU0904120PNER-M	G E	●	●	●	●	●	●	●	●			8.7	1.2	7.6	4.3	0.9	
	LOGU0904160PNER-M	G E	●	●	●	●	●	●	●	●			8.7	1.6	7.6	4.3	0.5	
	LOGU0904020PNFR-M	G F									●		8.7	0.2	7.6	4.3	1.7	
	LOGU0904040PNFR-M	G F									●		8.7	0.4	7.6	4.3	1.6	
	LOGU0904080PNFR-M	G F									●		8.7	0.8	7.6	4.3	1.2	
	LOGU0904100PNFR-M	G F									●		8.7	1.0	7.6	4.3	1.0	
	LOGU0904120PNFR-M	G F									●		8.7	1.2	7.6	4.3	0.9	
	LOGU0904160PNFR-M	G F									●		8.7	1.6	7.6	4.3	0.5	

* MV1020は日本限定発売材種です。

L

カッタ

ISO13399	➤ L003
切削條件	➤ L168—L192
部品	➤ P001
技術資料	➤ Q001

L161