

多機能用



AJX

- P
銅
- M
ステンレス鋼
- K
鋳鉄
- N
- S
耐熱合金
- H
高硬度鋼



図1


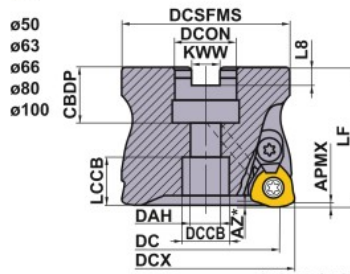


図2

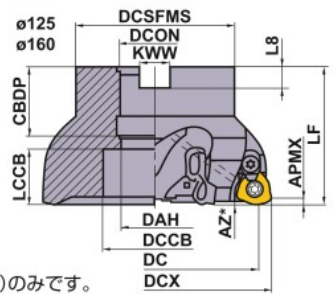

規格は右勝手(R)のみです。

DCX (mm)		セットボルト 呼び記号	形状
取付径 インチサイズ	取付径 ミリサイズ		
φ50, φ63	φ50, φ63(DCON=22)	HSC10030H	① ②
	φ63(DCON=27), φ80	HSC12035H	
φ80, φ100	φ100	HSC16040H	
φ125	φ125, φ160	MBA20040H	②
φ160		MBA24045H	

■アーバタイプ

クーラント穴あり

DCX=ミリサイズ, 取付=インチサイズ

DCX (mm)	呼び記号	在庫	刃数	寸法 (mm)			WT (kg)	APMX (mm)	RMPX	図	インサートタイプ
				DC	LF	DCON					
50	AJX12R05003B	●	3	38.3	50	22.225	0.4	1.2	2°	1	JDM1204
50	AJX12R05004B	●	4	38.3	50	22.225	0.4	1.2	2°	1	JDM1204
50	AJX09R05005B	●	5	40.0	50	22.225	0.5	1.2	1.1°	1	JDM09T3
63	AJX14R06303B	●	3	51.1	50	22.225	0.7	1.2	2.8°	1	JDM1405
63	AJX14R06304B	●	4	51.1	50	22.225	0.7	1.2	2.8°	1	JDM1405
63	AJX12R06305B	●	5	51.3	50	22.225	0.9	1.2	1.5°	1	JDM1204
80	AJX14R08004D	●	4	68.1	63	31.75	1.3	1.2	1.8°	1	JDM1405
80	AJX14R08005D	●	5	68.1	63	31.75	1.3	1.2	1.8°	1	JDM1405
80	AJX12R08006D	●	6	68.3	63	31.75	1.7	1.2	1.1°	1	JDM1204
100	AJX14R10005D	●	5	88.1	63	31.75	2.4	1.2	1.2°	1	JDM1405
100	AJX14R10006D	●	6	88.1	63	31.75	2.4	1.2	1.2°	1	JDM1405
100	AJX12R10007D	●	7	88.3	63	31.75	2.9	1.2	0.8°	1	JDM1204
125	AJX14R12505E	●	5	113.2	63	38.1	3.3	1.2	0.8°	2	JDM1405
125	AJX14R12507E	●	7	113.2	63	38.1	3.3	1.2	0.8°	2	JDM1405
160	AJX14R16006F	●	6	148.2	63	50.8	5.0	1.2	0.5°	2	JDM1405
160	AJX14R16008F	●	8	148.2	63	50.8	5.0	1.2	0.5°	2	JDM1405

L

DCX=ミリサイズ, 取付=ミリサイズ

DCX (mm)	呼び記号	在庫	刃数	寸法 (mm)			WT (kg)	APMX (mm)	RMPX	図	インサートタイプ	
				DC	LF	DCON						
50	AJX12-050A03R	●	3	38.3	50	22	0.4	1.2	2°	1	JDM1204	
50	AJX12-050A04R	●	4	38.3	50	22	0.4	1.2	2°	1	JDM1204	
50	AJX09-050A05R	●	5	40.0	50	22	0.5	1.2	1.1°	1	JDM09T3	
63	AJX14-063A03R	●	3	51.1	50	22	0.7	1.2	2.8°	1	JDM1405	
63	AJX14-063A04R	●	4	51.1	50	22	0.7	1.2	2.8°	1	JDM1405	
63	AJX12-063A05R	●	5	51.3	50	22	0.9	1.2	1.5°	1	JDM1204	
NEW	63	AJX14-063X03R	●	3	51.1	50	27	0.6	1.2	2.8	1	JDM1405
NEW	63	AJX14-063X04R	●	4	51.1	50	27	0.6	1.2	2.8	1	JDM1405
NEW	63	AJX12-063X05R	●	5	51.3	50	27	0.6	1.2	1.5	1	JDM1204
NEW	66	AJX14-066X03R	●	3	54.1	50	27	0.6	1.2	2.6	1	JDM1405
NEW	66	AJX14-066X04R	●	4	54.1	50	27	0.6	1.2	2.6	1	JDM1405
NEW	66	AJX12-066X05R	●	5	54.3	50	27	0.7	1.2	1.4	1	JDM1204
80	AJX14-080A04R	●	4	68.1	50	27	1.2	1.2	1.8°	1	JDM1405	
80	AJX14-080A05R	●	5	68.1	50	27	1.2	1.2	1.8°	1	JDM1405	
80	AJX12-080A06R	●	6	68.3	50	27	1.2	1.2	1.1°	1	JDM1204	
100	AJX14-100A05R	●	5	88.1	63	32	2.4	1.2	1.2°	1	JDM1405	
100	AJX14-100A06R	●	6	88.1	63	32	2.4	1.2	1.2°	1	JDM1405	
100	AJX12-100A07R	●	7	88.3	63	32	2.6	1.2	0.8°	1	JDM1204	

●: 標準在庫品

製品NEWSはこちらから▶

