


ネガティブインサート(穴つき)

G級精度

NEW

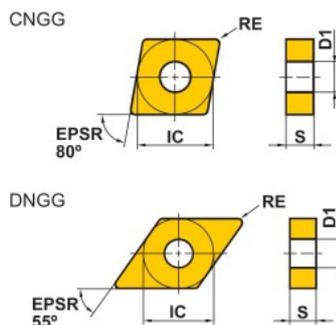

(mm)

呼び記号	切削領域	MP9005	MP9015	MP9025	MT9015	IC	S	RE	D1
CNGG1204V5-FS	F	●	●		●	12.7	4.76	0.05	5.16
CNGG120401-FS	F	●	●	●	●	12.7	4.76	0.1	5.16
CNGG120402-FS	F	●	●	●	●	12.7	4.76	0.2	5.16
CNGG120404-FS	F	●	●	●	●	12.7	4.76	0.4	5.16
CNGG120408-FS	F	●	●	●	●	12.7	4.76	0.8	5.16
CNGG120402-LS	L	●	●	●	●	12.7	4.76	0.2	5.16
CNGG120404-LS	L	●	●	●	●	12.7	4.76	0.4	5.16
CNGG120408-LS	L	●	●	●	●	12.7	4.76	0.8	5.16
DNGG150402-FS	F	●	●	●	●	12.7	4.76	0.2	5.16
DNGG150404-FS	F	●	●	●	●	12.7	4.76	0.4	5.16
DNGG150408-FS	F	●	●	●	●	12.7	4.76	0.8	5.16
DNGG150604-FS	F	●	●	●	●	12.7	6.35	0.4	5.16
DNGG150608-FS	F	●	●	●	●	12.7	6.35	0.8	5.16
DNGG150402-LS	L	●	●	●	●	12.7	4.76	0.2	5.16
DNGG150404-LS	L	●	●	●	●	12.7	4.76	0.4	5.16
DNGG150408-LS	L	●	●	●	●	12.7	4.76	0.8	5.16
DNGG150604-LS	L	●	●	●	●	12.7	6.35	0.4	5.16
DNGG150608-LS	L	●	●	●	●	12.7	6.35	0.8	5.16