 
 
 
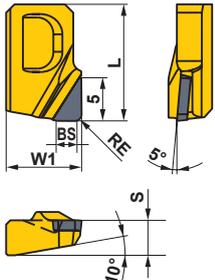
 
 
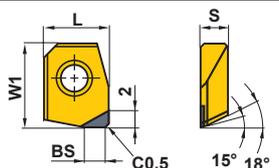
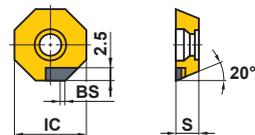


CBN&PCDインサート

対応カッタ インサート 外観	呼び記号	精度	CBN		PCD		寸法 (mm)					形状
			MB730	MD220 MD2030	L	W1	IC	S	BS	RE		
	GDCN2004PDFR3	C		●	20	12.7	—	4.76	—	1.2		
	NF10000 QF10000											
	GDCN2004ZDTR1	C		●	20	12.7	—	4.76	1.4	0.8		
	NR10000											
	GDCN2004PDR	C		●	20	12.7	—	4.76	—	1.2		
	AF10000											
	GOER1404PXFR2	E		●	14	9	—	4.2	2	0.4		
	GOER1408PXFR2	E		●	14	9	—	4.2	2	0.8		
	LDCN190412R	C	●	●	19.05	12.7	—	4.76	—	1.2	 本図は右勝手(R)を示す。	
	LDCN190412L	C		●	19.05	12.7	—	4.76	—	1.2		
	NP-GDCN2004PDSR3	C	●		20	12.7	—	4.76	—	0.8		
	NF10000											
	NP-GDCW1240PDFR2	C		●	9.5	12	—	4	2	—		
	V10000											
	OEMX12T3ETR1	M	●		—	—	12.7	3.97	1	—		
	OCTACUT											

●：標準在庫品
(1ケース 1個入りです)