
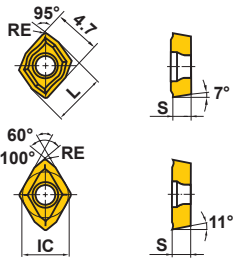

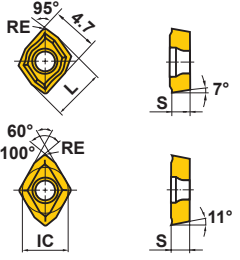
 
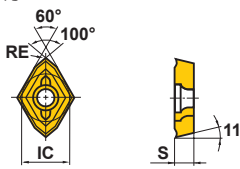

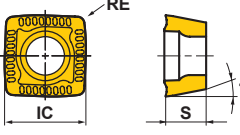

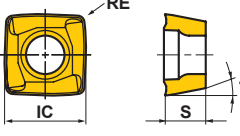


ドリル用インサート

対応ドリル インサート 外観	呼び記号	精度	コーティング						寸法 (mm)				形状
			VP15TF	UP20M	GP20M	UE6020	US735	MC1020	MC5020	IC	L	S	
 <p>GCMT GPMT</p>	TAF GCMT040204-U1	M	●						—	5.0	2.38	0.4	<p>U1プレーカ</p> 
	GPMT060204-U1	M	●	●					5.56	—	2.38	0.4	
	GPMT070204-U1	M	●	●					6.35	—	2.38	0.4	
	GPMT090304-U1	M	●	●					7.94	—	3.18	0.4	
	GPMT11T308-U1	M	●	●					9.525	—	3.97	0.8	
	GPMT140408-U1	M	●	●					12.7	—	4.76	0.8	
 <p>GCMT GPMT</p>	TAF GCMT040204-U2	M	●	●					—	5.0	2.38	0.4	<p>U2プレーカ</p> 
	GPMT060204-U2	M	●	●	●	●			5.56	—	2.38	0.4	
	GPMT070204-U2	M	●	●	●	●			6.35	—	2.38	0.4	
	GPMT090304-U2	M	●	●	●	●			7.94	—	3.18	0.4	
	GPMT11T308-U2	M	●	●	●	●			9.525	—	3.97	0.8	
	GPMT140408-U2	M	●	●	●	●			12.7	—	4.76	0.8	
	TAF GPMT060204-U3	M	●		●	●			5.56	—	2.38	0.4	<p>U3プレーカ</p> 
	GPMT070204-U3	M	●		●	●			6.35	—	2.38	0.4	
	GPMT090304-U3	M	●		●	●			7.94	—	3.18	0.4	
	GPMT11T308-U3	M	●		●	●			9.525	—	3.97	0.8	
	GPMT140408-U3	M	●		●	●			12.7	—	4.76	0.8	
	MXV SOMX063005-UM	M	●				●	●	6	—	3	0.5	
	SOMX073505-UM	M	●				●	●	7	—	3.5	0.5	
	SOMX084005-UM	M	●				●	●	8.3	—	4	0.5	
	SOMX094506-UM	M	●				●	●	9.7	—	4.5	0.6	
	SOMX115506-UM	M	●				●	●	11.6	—	5.5	0.6	
	SOMX136008-UM	M	●				●	●	13.8	—	6	0.8	
	SOMX166508-UM	M	●				●	●	16.5	—	6.5	0.8	
	SOMX187008-UM	M	●				●	●	18.2	—	7	0.8	
	MXV SOMX063005-US	M	●						6	—	3	0.5	
	SOMX073505-US	M	●						7	—	3.5	0.5	
	SOMX084005-US	M	●						8.3	—	4	0.5	
	SOMX094506-US	M	●						9.7	—	4.5	0.6	
	SOMX115506-US	M	●						11.6	—	5.5	0.6	
	SOMX136008-US	M	●						13.8	—	6	0.8	
	SOMX166508-US	M	●						16.5	—	6.5	0.8	
	SOMX187008-US	M	●						18.2	—	7	0.8	

回転工具用インサート

●: 標準在庫品  
(1ケース10個入りです)