

B6KD

ブリストアパックドリル

六角軸ドリル

製品情報



対象被削材



技術資料 >> 1982

ISO13399記号 >> 1966

マークの見方 >> 1607

ドリル選定目安表 >> 1619

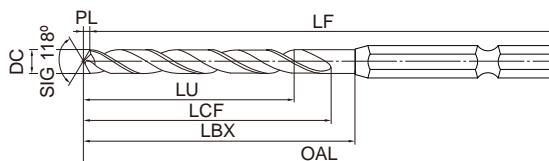


図1

※LU（加工深さ）はLCF（溝長）-3DCを目安にご使用ください。

●：標準在庫 単位（mm）

呼び記号	DC	LCF	LBX	OAL	LF	PL	在庫	図番	呼び記号	DC	LCF	LBX	OAL	LF	PL	在庫	図番
B6KDD0100	1.0	18		70.3	70	0.3	●	1	B6KDD0470	4.7	46		115.4	114	1.4	●	1
B6KDD0120	1.2	20		72.4	72	0.4	●	1	B6KDD0480	4.8	51		115.4	114	1.4	●	1
B6KDD0150	1.5	23		78.5	78	0.5	●	1	B6KDD0490	4.9	51		118.5	117	1.5	●	1
B6KDD0160	1.6	25		80.5	80	0.5	●	1	B6KDD0500	5.0	51		118.5	117	1.5	●	1
B6KDD0180	1.8	28		82.5	82	0.5	●	1	B6KDD0510	5.1	51		118.5	117	1.5	●	1
B6KDD0200	2.0	23		85.6	85	0.6	●	1	B6KDD0520	5.2	51		121.6	120	1.6	●	1
B6KDD0210	2.1	23		85.6	85	0.6	●	1	B6KDD0530	5.3	51		121.6	120	1.6	●	1
B6KDD0220	2.2	26		88.7	88	0.7	●	1	B6KDD0540	5.4	56		121.6	120	1.6	●	1
B6KDD0230	2.3	26		88.7	88	0.7	●	1	B6KDD0550	5.5	56		121.7	120	1.7	●	1
B6KDD0240	2.4	29		91.7	91	0.7	●	1	B6KDD0560	5.6	56		124.7	123	1.7	●	1
B6KDD0250	2.5	29		91.8	91	0.8	●	1	B6KDD0570	5.7	56		124.7	123	1.7	●	1
B6KDD0260	2.6	29		94.8	94	0.8	●	1	B6KDD0580	5.8	56		124.7	123	1.7	●	1
B6KDD0270	2.7	32		94.8	94	0.8	●	1	B6KDD0590	5.9	56		124.8	123	1.8	●	1
B6KDD0280	2.8	32		97.8	97	0.8	●	1	B6KDD0600	6.0	56		128.8	127	1.8	●	1
B6KDD0290	2.9	32		98.9	98	0.9	●	1	B6KDD0610	6.1	56		128.8	127	1.8	●	1
B6KDD0300	3.0	32		98.9	98	0.9	●	1	B6KDD0620	6.2	56		128.9	127	1.9	●	1
B6KDD0310	3.1	35		98.9	98	0.9	●	1	B6KDD0630	6.3	56		128.9	127	1.9	●	1
B6KDD0320	3.2	35		99.0	98	1.0	●	1	B6KDD0640	6.4	62		131.9	130	1.9	●	1
B6KDD0330	3.3	35		101.0	100	1.0	●	1	B6KDD0650	6.5	62		132.0	130	2.0	●	1
B6KDD0340	3.4	38		101.0	100	1.0	●	1	B6KDD0700	7.0	70		117.1	115	2.1	●	1
B6KDD0350	3.5	38		101.1	100	1.1	●	1	B6KDD0750	7.5	70		117.3	115	2.3	●	1
B6KDD0360	3.6	38		104.1	103	1.1	●	1	B6KDD0800	8.0	70		117.4	115	2.4	●	1
B6KDD0370	3.7	38		104.1	103	1.1	●	1	B6KDD0850	8.5	70		117.6	115	2.6	●	1
B6KDD0380	3.8	42		104.1	103	1.1	●	1	B6KDD0900	9.0	70		117.7	115	2.7	●	1
B6KDD0390	3.9	42		107.2	106	1.2	●	1	B6KDD0950	9.5	70		117.9	115	2.9	●	1
B6KDD0400	4.0	42		109.2	108	1.2	●	1	B6KDD1000	10.0	70		118.0	115	3.0	●	1
B6KDD0410	4.1	42		109.2	108	1.2	●	1	B6KDD1050	10.5	70		118.2	115	3.2	●	1
B6KDD0420	4.2	42		109.3	108	1.3	●	1	B6KDD1100	11.0	70		118.3	115	3.3	●	1
B6KDD0430	4.3	46		109.3	108	1.3	●	1	B6KDD1150	11.5	70		118.5	115	3.5	●	1
B6KDD0440	4.4	46		112.3	111	1.3	●	1	B6KDD1200	12.0	70		118.6	115	3.6	●	1
B6KDD0450	4.5	46		112.4	111	1.4	●	1	B6KDD1250	12.5	70		118.8	115	3.8	●	1
B6KDD0460	4.6	46		112.4	111	1.4	●	1	B6KDD1300	13.0	70		118.9	115	3.9	●	1