


# JIS B2401-1 V番 (真空フランジ用)

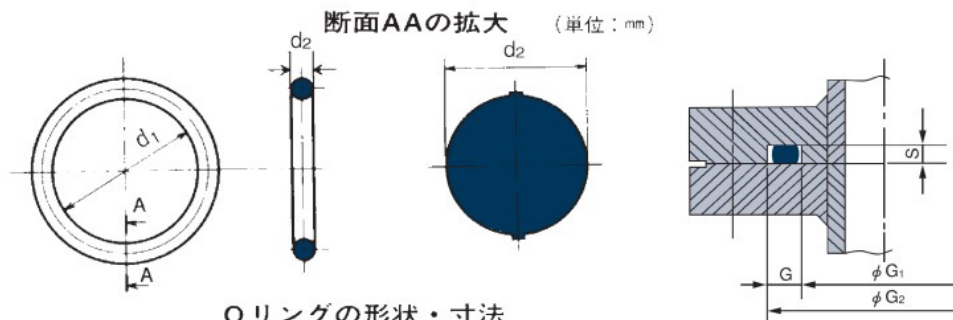

Oリングの形状・寸法

材質群①: NBR-70-1, NBR-90, NBR-70-2  
 材質群②: FKM-70, HNBR-70, HNBR-90  
 材質群③: VMQ, ACM, EPDM, FKM-90, その他

部品番号	JIS 呼び番号	Oリング寸法					フランジみぞ部の寸法 (JIS B2290)								
		太さ $d_2$	内径			呼び径	$G_1$	$G_2$	G	S					
			$d_1$	材質群①	材質群②						材質群③				
30003	※ V3	4.0 ± 0.12	2.5	± 0.20	± 0.24	± 0.30		3	+1.0 0						
30004	※ V4		3.5	± 0.20	± 0.24	± 0.30		4							
30005	※ V5		4.5	± 0.20	± 0.24	± 0.30		5							
30006	※ V6		5.5	± 0.20	± 0.24	± 0.30		6							
30007	※ V7		6.5	± 0.20	± 0.24	± 0.30		7							
30008	※ V8		7.5	± 0.20	± 0.24	± 0.30		8							
30009	※ V9		8.5	± 0.20	± 0.24	± 0.30		9							
30010	※ V10		4.0 ± 0.1	9.5	± 0.20	± 0.24	± 0.30			10					
30011	※ V11			10.5	± 0.20	± 0.24	± 0.30			11					
30012	※ V12	11.5		± 0.20	± 0.24	± 0.30		12							
30014	※ V14	13.5		± 0.20	± 0.24	± 0.30		14							
30015	V15	14.5		± 0.20	± 0.24	± 0.30		15			25				
30016	※ V16	15.5		± 0.24	± 0.29	± 0.36		16							
30018	※ V18	17.5		± 0.24	± 0.29	± 0.36		18							
30020	※ V20	19.5		± 0.24	± 0.29	± 0.36		20							
30021	※ V21	20.5		± 0.24	± 0.29	± 0.36		21							
30022	※ V22	21.5		± 0.24	± 0.29	± 0.36		22							
30024	V24	23.5		± 0.24	± 0.29	± 0.36	10	24			34				
30025	※ V25	24.5		± 0.33	± 0.40	± 0.50		25							
30026	※ V26	25.5		± 0.33	± 0.40	± 0.50		26							
30028	※ V28	27.5		± 0.33	± 0.40	± 0.50		28							
30030	※ V30	29.5		± 0.33	± 0.40	± 0.50		30							
30032	※ V32	31.5		± 0.33	± 0.40	± 0.50		32							
30034	V34	33.5		± 0.33	± 0.40	± 0.50	20	34			44	5.0	3.0		
30035	※ V35	34.5		± 0.37	± 0.45	± 0.56		35							
30036	※ V36	35.5		± 0.37	± 0.45	± 0.56		36							
30038	※ V38	37.5		± 0.37	± 0.45	± 0.56		38	+1.0						
30040	V40	39.5		± 0.37	± 0.45	± 0.56	25	40	0		50				
30042	※ V42	41.5		± 0.49	± 0.59	± 0.74		42							
30044	※ V44	43.5		± 0.49	± 0.59	± 0.74		44							
30045	※ V45	44.5		± 0.49	± 0.59	± 0.74		45							
30046	※ V46	45.5		± 0.49	± 0.59	± 0.74		46							
30048	※ V48	47.5		± 0.49	± 0.59	± 0.74		48							
30050	※ V50	49.5		± 0.49	± 0.59	± 0.74		50							
30053	※ V53	52.5		± 0.49	± 0.59	± 0.74		53							
30055	V55	54.5		± 0.49	± 0.59	± 0.74	40	55			65				
30056	※ V56	55.5		± 0.61	± 0.74	± 0.92		56							
30058	※ V58	57.5	± 0.61	± 0.74	± 0.92		58								
30060	※ V60	59.5	± 0.61	± 0.74	± 0.92		60								
30063	※ V63	62.5	± 0.61	± 0.74	± 0.92		63								
30065	※ V65	64.5	± 0.61	± 0.74	± 0.92		65								
30067	※ V67	66.5	± 0.61	± 0.74	± 0.92		67								
30070	V70	69.0	± 0.61	± 0.74	± 0.92	50	70			80					
30075	※ V75	74.0	± 0.72	± 0.87	± 1.08		75								
30080	※ V80	79.0	± 0.72	± 0.87	± 1.08		80								
30085	V85	84.0	± 0.72	± 0.87	± 1.08	65	85			95					
30090	※ V90	89.0	± 0.83	± 1.00	± 1.25		90								

注意: 材質によって、製造不可の場合もございます。