


HIGH TORQUE TIMING BELTS -P2M-P3M-P5M-P8M-

ハイトルクタイミングベルト (P2M・P3M・P5M・P8M)

■ハイトルクタイミングベルトはハイトルクタイミングプーリ ㊦ P1495~P1500と適合します。

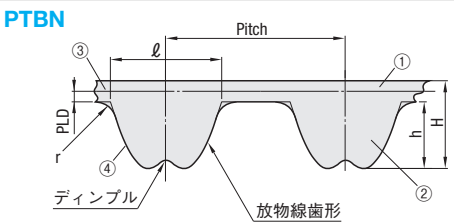

PTBN

Type	材質									
PTBN	①背ゴム	クロロプレンゴム								
	②歯ゴム	クロロプレンゴム								
	③心線	ガラス繊維								
	④歯布	ナイロン帆布								

種類	Pitch	ℓ	H	h	PLD	r	単位質量 g/m(幅10mm)
P2M	2	1.30	1.3	0.73	0.254	0.2	14.0
P3M	3	1.95	2.1	1.09	0.381	0.3	22.0
P5M	5	3.25	3.6	1.81	0.571	0.5	41.0
P8M	8	5.20	5.5	2.90	0.686	0.8	56.0

♡使用温度 -25~80℃ (参考値)
 ♡ベルト周長は心線の長さです。
 ♡特長・注意事項 ㊦ P1463
 ♡選択方法 ㊦ P2462

■種類 P2M (Pitch : 2mm)

型式			歯数	ベルト 周長 (mm)	¥基準単価
Type	ベルトNo.	呼び幅			
PTBN	80 P2M	060 (6mm)	40	80	1,040
	84 P2M		42	84	1,040
	88 P2M		44	88	1,040
	98 P2M		49	98	1,040
	100 P2M		50	100	1,040
	112 P2M		56	112	1,040
	116 P2M		58	116	1,040
	118 P2M		59	118	1,040
	124 P2M		62	124	1,060
	126 P2M		63	126	1,060
	132 P2M		66	132	1,060
	134 P2M		67	134	1,060
	136 P2M		68	136	1,060
	140 P2M		70	140	1,060
	142 P2M		71	142	1,060
	144 P2M		72	144	1,090
	146 P2M		73	146	1,090
	152 P2M		76	152	1,090
	154 P2M		77	154	1,090
	160 P2M		80	160	1,090
	162 P2M		81	162	1,090
	166 P2M		83	166	1,090
	170 P2M		85	170	1,090
	172 P2M		86	172	1,090
	176 P2M		88	176	1,110
	180 P2M		90	180	1,110
	186 P2M		93	186	1,110
	190 P2M		95	190	1,110
	196 P2M		98	196	1,110
	200 P2M		100	200	1,110
	204 P2M		102	204	1,140
	208 P2M		104	208	1,140
	212 P2M		106	212	1,140
	214 P2M		107	214	1,140
	216 P2M		108	216	1,140
	220 P2M		110	220	1,140
	224 P2M		112	224	1,140
	230 P2M		115	230	1,170
PTBN	234 P2M	060 (6mm)	117	234	1,170
	236 P2M		118	236	1,170
	240 P2M		120	240	1,170
	244 P2M		122	244	1,190
	246 P2M		123	246	1,190
	250 P2M		125	250	1,190
	258 P2M		129	258	1,220
	262 P2M		131	262	1,220
	266 P2M		133	266	1,220
	270 P2M		135	270	1,220
	274 P2M		137	274	1,240
	280 P2M		140	280	1,240
	284 P2M		142	284	1,240
	290 P2M		145	290	1,270
	300 P2M		150	300	1,270
	302 P2M		151	302	1,270
	310 P2M		155	310	1,300
	318 P2M		159	318	1,300
	320 P2M		160	320	1,300
	324 P2M		162	324	1,300
	328 P2M		164	328	1,300
	330 P2M		165	330	1,300
	334 P2M		167	334	1,300
	340 P2M		170	340	1,300
	348 P2M		174	348	1,300
	354 P2M		177	354	1,300
	360 P2M		180	360	1,300
	370 P2M		185	370	1,320
	378 P2M		189	378	1,350
	380 P2M		190	380	1,350
	390 P2M		195	390	1,350
	400 P2M		200	400	1,350
	408 P2M		204	408	1,370
	416 P2M		208	416	1,370
	420 P2M		210	420	1,400
	424 P2M		212	424	1,400
	426 P2M		213	426	1,430
	434 P2M		217	434	1,430
PTBN	440 P2M	060 (6mm)	220	440	1,430
	448 P2M		224	448	1,450
	464 P2M		232	464	1,480
	488 P2M		244	488	1,530
	490 P2M		245	490	1,530
	500 P2M		250	500	1,530
	516 P2M		258	516	1,530
	520 P2M		260	520	1,530
	530 P2M		265	530	1,560
	560 P2M		280	560	1,560
	576 P2M		288	576	1,570
	590 P2M		295	590	1,570
	600 P2M		300	600	1,570
	630 P2M		315	630	1,580
	638 P2M		319	638	1,580
	656 P2M		328	656	1,590
	676 P2M		338	676	1,600
	680 P2M		340	680	1,600
	704 P2M		352	704	1,620
	710 P2M		355	710	1,630
	754 P2M		377	754	1,640
	764 P2M		382	764	1,640
	774 P2M		387	774	1,640
	788 P2M		394	788	1,650
	800 P2M		400	800	1,650
	808 P2M		404	808	1,650
	824 P2M		412	824	1,650
	846 P2M		423	846	1,650
	866 P2M		433	866	1,650
	898 P2M		449	898	1,660
	900 P2M		450	900	1,660
	940 P2M		470	940	1,700
	956 P2M		478	956	1,700
	992 P2M		496	992	1,700
	1040 P2M		520	1,040	1,710
	1242 P2M		641	1,242	1,800

Order
注文例

型式

Type

ベルトNo.

ベルト呼び幅

PTBN 200 P2M - 060

Delivery
出荷日

3

日日出荷