




DOWEL PINS -MINUS TOLERANCE- / GENERAL PINS

# ノックピン/汎用ピン

-マイナス公差-

■ノックピン ストレート(h7)

RoHS 10

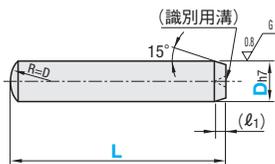

Type	材質	硬度
MSH	SUS440Cまたは13Crステンレス	45~50HRC
MSHS	SUS304	-

- ① 識別用溝はMSHの一部サイズのみ適用となります。
- ② φ1.6以下は識別用溝はございません。
- ③ φ1寸法は外径の研磨工程でカタログ値より大きくなることがあります。

φ1	Dh7	型式		L												¥基準単価			¥スライド単価					
		Type	D													1~9本	10~49	50~500						
0.4	0 -0.01	MSH	1	4 5 6 8 10 12													150	59	57					
			1.2	4 5 6 8																				
			1.5	4 5 6 8 10 12 15 16																				
			1.6	4 5 6 8 12																				
0.6	0 -0.01	MSH	2	4 5 6 8 10 12 14 15 16 18 20	25	30												150	68	67				
			2.5	6 8 10 12 15 20	25	30																		
			3	5 6 8 10 12 14 15 16 18 20	25	30	32 35 40 45 50																	
1	0 -0.012	MSH	4	6 8 10 12 14 15 16 18 20 22	25	30	35 40 45 50	60											150	95	93			
			5	6 8 10 12 14 15 16 18 20	24 25 28 30	35 40 45 50	60																	
1.5	0 -0.012	MSH	6	8 10 12 14 15 16 18 20 22	25	30	35 40 45 50 55 60													150	108	104		
			8	10 12 14 15 16 18 20	25	30	35 40 45 50 60 80																	
			10	15 18 20	25	30	35 40 50 60																	
2	0 -0.015	MSH	10	15 18 20	25	30	35 40 50 60														150	117	114	
			15	18 20	25	30	35 40 50 60																	
2.5	0 -0.015	MSH	15	18 20	25	30	35 40 50 60															150	130	125
			20	25 30	35 40 50 60																			

④ 表示数量超えはWOSIにてご確認ください。


φ1	Dh7	型式		L												¥基準単価			¥スライド単価		
		Type	D													1~9本	10~49	50~100			
0.3	0 -0.01	MSHS	0.9	5 6 8 10													170	120	100		
			1	5 6 8 10 12																	
0.4	0 -0.01		1.5	5 6 8 10 12																	
			2	5 6 8 10 12 15 18 20																	
0.6	0 -0.01		2.5	6 8 10 12 15																	
			3	6 8 10 12 15 18 20																	
			4	8 10 12 15 18 20 25																	
1	0 -0.012		5	8 10 12 15 18 20 25																180	130
		6	10 12 15 18 20 25																		
1.5	0 -0.012	8	15 18 20 25																		
		10	18 20 25																		

④ 表示数量超えはWOSIにてご確認ください。

■ノックピン C面取タイプ

RoHS 10

Type	材質	硬度
MSHHM	SUS440C	58HRC~
MSHSM	SUS304	-

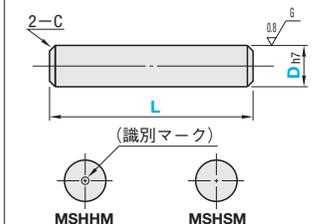

C	Dh7	型式		L						¥基準単価			¥スライド単価		
		Type	D							1~19本	20~29	30~100			
0.3以下	0 -0.01	MSHHM	2	6 8 10 12 15							190	168	152		
			3	6 8 10 12 15 20											
0.5	0 -0.012		4	8 10 12 15 20											
			5	8 10 12 15 20											
0.5	0 -0.012		6	10 12 15 20											
			8	15 20											
			15	20											

④ 表示数量超えはWOSIにてご確認ください。

C	Dh7	型式		L						¥基準単価			¥スライド単価		
		Type	D							1~19本	20~29	30~100			
0.3以下	0 -0.01	MSHSM	2	6 8 10 12 15							180	158	142		
			3	6 8 10 12 15 20											
0.5	0 -0.012		4	8 10 12 15 20											
			5	8 10 12 15 20											
0.5	0 -0.012		6	10 12 15 20											
			8	15 20											
			15	20											

④ 表示数量超えはWOSIにてご確認ください。