 

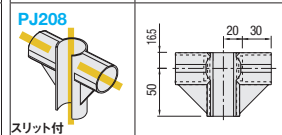
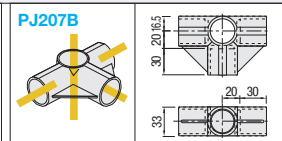
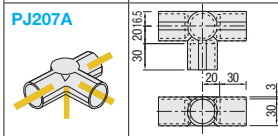
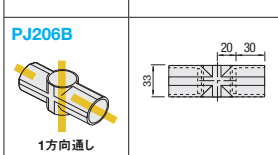
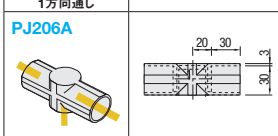
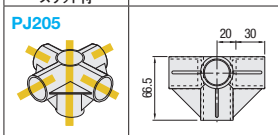
 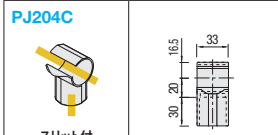

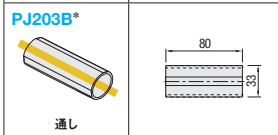
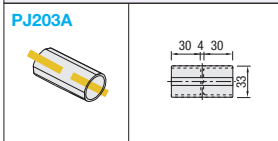
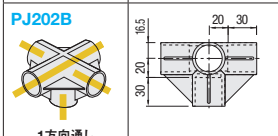
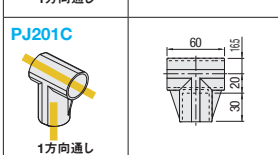
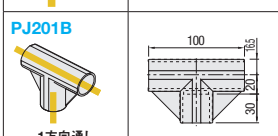
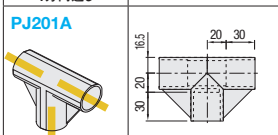
 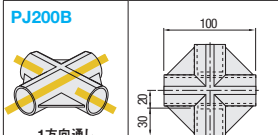

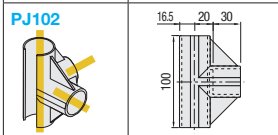
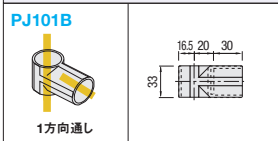
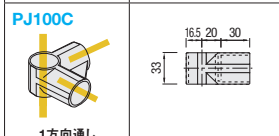
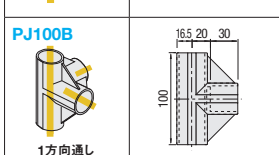
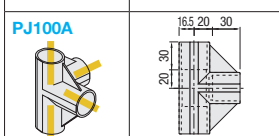
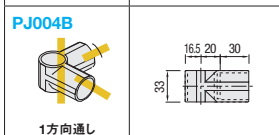
 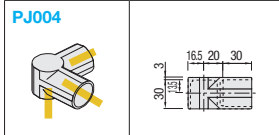

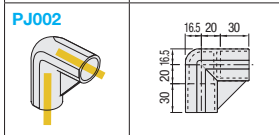


 
PLASTIC JOINTS

プラスチック・ジョイント

-PJ001~209-

CADデータフォルダ名: 43_Pipe_Frames

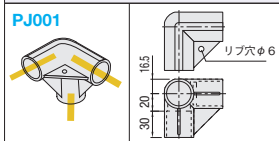

*PJ203Bは次の場合に使用します。
 ●パイプの接続

 (強度がかかる場所での使用はさけてください。)

型式	色	質量 (g)	¥基準単価				¥スライド単価			
			1~19	20~49	50~99	100~300	1~19	20~49	50~99	100~300
PJ001	W (白) S (グレー)	46	200	160	100	80				
PJ002		33	145	116	72	58				
PJ003		25	130	104	65	52				
PJ004		37	150	120	75	60				
PJ004B		37	150	120	75	60				
PJ100A		58	260	208	130	104				
PJ100B		57	260	208	130	104				
PJ100C		33	150	120	75	60				

型式	色	質量 (g)	¥基準単価				¥スライド単価			
			1~19	20~49	50~99	100~300	1~19	20~49	50~99	100~300
PJ101B	W (白) S (グレー)	21	130	104	65	52				
PJ102		28	230	184	115	92				
PJ103		37	230	184	115	92				
PJ200B		55	250	200	125	100				
PJ201A		48	200	160	100	80				
PJ201B		44	200	160	100	80				
PJ201C		32	160	128	80	64				
PJ202B		74	260	208	130	104				

型式	色	質量 (g)	¥基準単価				¥スライド単価			
			1~19	20~49	50~99	100~300	1~19	20~49	50~99	100~300
PJ203A	W (白) S (グレー)	27	120	96	60	48				
PJ203B		23	120	96	60	48				
PJ204A		37	180	144	90	72				
PJ204C		19	100	80	50	40				
PJ205		73	360	288	180	144				
PJ206A		35	150	120	75	60				
PJ206B		33	150	120	75	60				
PJ207A		47	200	160	100	80				
PJ207B		44	200	160	100	80				
PJ208		40	250	200	125	100				
PJ209	58	250	200	125	100					

Order 注文例

型式 PJ001 色 S

Delivery 出荷日

在庫品 翌日出荷 数量 P133

ご希望によりPM6:00迄、当日出荷受付致します。

数量区分	標準対応	個別対応
小口	1~300	301~
大口	通常	お見積り

表示数量超入はWOSにて確認ください。

43
パイプフレーム