



STAINLESS PIPES COUPLINGS FOR STAINLESS PIPES

ステンレス管/ステンレス管用継手




☐:値下げ価格

CADデータフォルダ名: 51_Pipes_Fitting_Valves



Type	材質	規格	焼鈍し	光沢
SKHR SKH	SUS304	JIS G3459	大気焼鈍	無
SKER SKE	SUS316		大気焼鈍	無
			光輝焼鈍(BA管)	有
			光輝焼鈍(BA管)	有

☑本品はシームレス管になります。

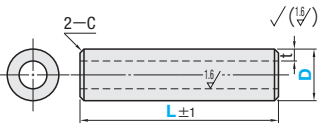

☑SKEの寸法は()内の数値となります。

D	t
4	1
6	1
6.35 (1/4インチ)	1
8	1 (1.2)
9.53 (3/8インチ)	1
10	1 (1.5)
12	1 (1.5)
12.7 (1/2インチ)	1
16	1

型式		L 指定mm単位	¥基準単価																			
Type	D		SKHR									SKH										
SKHR SKH	4	20~1000	L20~100	L101~200	L201~300	L301~400	L401~500	L501~600	L601~700	L701~800	L801~900	L901~1000	L20~100	L101~200	L201~300	L301~400	L401~500	L501~600	L601~700	L701~800	L801~900	L901~1000
	6		500	600	710	830	970	1,210	1,530	1,980	2,480	2,990	570	770	980	1,220	1,490	1,960	2,630	3,430	4,310	5,220
	6.35 (1/4インチ)		510	610	730	860	1,010	1,240	1,560	1,990	2,490	3,000	610	830	1,090	1,380	1,700	2,180	2,860	3,730	4,700	5,690
	8		540	620	740	870	1,020	1,270	1,530	1,930	2,450	3,070	620	840	1,100	1,390	1,720	2,260	2,960	3,860	4,850	5,870
	9.53 (3/8インチ)		580	700	830	970	1,140	1,410	1,720	2,240	2,810	3,400	680	910	1,180	1,480	1,810	2,340	3,050	3,980	5,000	6,060
	10		600	730	880	1,060	1,260	1,600	1,990	2,540	3,140	3,740	690	940	1,230	1,550	1,910	2,500	3,270	4,270	5,200	6,310
	12		610	740	890	1,070	1,260	1,600	1,990	2,540	3,140	3,740	700	960	1,260	1,600	1,980	2,600	3,340	4,300	5,330	6,370
12.7 (1/2インチ)	670	820	980	1,180	1,400	1,760	2,190	2,810	3,470	4,140	780	1,070	1,400	1,780	2,200	2,870	3,680	4,730	5,870	7,020		
16	680	830	990	1,190	1,420	1,800	2,230	2,860	3,530	4,210	790	1,080	1,410	1,790	2,210	2,890	3,710	4,770	5,920	7,080		
	950	1,200	1,450	1,780	2,080	2,620	3,220	4,140	5,130	6,140	1,250	1,660	2,380	3,040	3,680	4,700	5,840	7,570	9,460	11,380		

型式		L 指定mm単位	¥基準単価																			
Type	D		SKER									SKE										
SKER SKE	4	20~1000	L20~100	L101~200	L201~300	L301~400	L401~500	L501~600	L601~700	L701~800	L801~900	L901~1000	L20~100	L101~200	L201~300	L301~400	L401~500	L501~600	L601~700	L701~800	L801~900	L901~1000
	6		530	660	810	980	1,170	1,490	1,900	2,480	3,110	3,750	570	910	1,250	1,590	1,870	2,360	3,000	3,890	4,860	5,860
	6.35 (1/4インチ)		540	680	840	1,010	1,210	1,570	2,020	2,620	3,290	3,980	630	1,020	1,420	1,810	2,140	2,750	3,500	4,540	5,670	6,830
	8		540	690	850	1,030	1,230	1,570	2,020	2,640	3,310	4,000	680	1,080	1,480	1,970	2,230	2,880	3,650	4,730	5,900	7,090
	9.53 (3/8インチ)		610	770	940	1,140	1,360	1,720	2,200	2,870	3,610	4,370	690	1,140	1,590	2,100	2,410	3,110	4,020	5,220	6,520	7,850
	10		640	820	1,030	1,260	1,520	1,960	2,520	3,290	4,130	5,000	730	1,190	1,640	2,160	2,580	3,240	4,070	5,290	6,630	8,000
	12		640	820	1,030	1,260	1,520	1,960	2,520	3,290	4,130	5,000	750	1,270	1,830	2,340	2,720	3,500	4,430	5,640	6,930	8,220
12.7 (1/2インチ)	710	910	1,150	1,410	1,700	2,180	2,750	3,530	4,370	5,220	820	1,390	2,070	2,620	3,030	3,880	4,880	6,220	7,640	9,060		
16	720	930	1,170	1,430	1,730	2,180	2,750	3,530	4,370	5,220	890	1,420	2,180	2,760	3,160	4,000	4,980	6,450	8,050	9,680		
	1,130	1,370	1,810	2,330	2,820	3,550	4,360	5,620	6,980	8,360	1,470	2,080	2,880	3,760	4,540	5,680	7,030	9,140	11,450	13,800		

Order 注文例: 型式 SKE10 - L 300

Delivery 出荷日: 2 日日出荷

Price 価格: ストックA早割 当日出荷 加納/明細付 PM 3:00迄

数量スライド価格 (¥1円未満切り捨て) P133

数量区分	標準対価	個別対応
数量	1~9	10~29
値引率	基準準備	5%
		10%
		お見積り

☑継手部の締め付け手順および構造・適用管の仕様はP.1356をご参照ください。

ステンレス管用継手 - コネクター SKTGK

☑フェルール含む (SKFPK参照) M 材質 SUS316

ステンレス管用継手 - エルボース SKTGLK

☑フェルール含む (SKFPK参照) M 材質 SUS316

型式		R (PT) T 選択	R (PT) T 選択	L	E	F	ℓ	対辺		¥標準単価		¥スライド単価	
Type	D							本体H	ナットH	1~90	10~990	100~490	500以上
SKTGK	3.18 (1/8)	1	1/8	32.9	2.5	13.4	26	12	12	1,190	952	941	929
		2	1/4	34.9	2.5	13.4	28	14	12	1,210	956	944	932
	4	1	1/8	35.8	3.5	15.3	28.5	14	14	980	735	716	686
		2	1/4	37.8	3.5	15.3	30.5	14	14	1,150	863	851	840
	6	1	1/8	35.9	5	15.4	28.5	14	14	950	709	693	665
		2	1/4	37.9	5	15.4	30.5	14	14	970	728	709	679
	6.35 (1/4)	3	3/8	38.9	5	15.4	31.5	17	14	1,120	839	818	784
		4	1/2	44.4	5	15.4	37	22	14	1,690	1,268	1,234	1,183
	8	1	1/8	35.9	5	15.4	28.5	14	14	950	709	694	665
		2	1/4	37.9	5	15.4	30.5	14	14	970	728	709	679
	8	3	3/8	38.9	5	15.4	31.5	17	14	1,060	795	774	753
		4	1/2	44.4	5	15.4	37	22	14	1,590	1,268	1,234	1,183
	9.53 (3/8)	1	1/8	36.8	6	16.8	31	14	15.9	1,180	885	862	826
		2	1/4	38.8	6	16.8	33	17	15.9	1,180	885	862	838
10	1	1/8	40.8	7.5	17.8	33	17	19	1,140	981	935	878	
	2	1/4	42.8	7.5	17.8	35.5	22	19	1,440	1,253	1,196	1,124	
12	1	1/8	40.8	7.5	17.8	33	17	19	1,310	970	957	917	
	2	1/4	42.8	7.5	17.8	35.5	22	19	1,310	970	957	944	
12.7 (1/2)	1	1/8	46.3	8	17.8	33	17	19	1,610	1,192	1,176	1,160	
	2	1/4	48.3	8	17.8	35.5	22	23	1,940	1,455	1,417	1,358	
12	3	3/8	43.8	9	22.8	33	22	23	1,760	1,320	1,303	1,285	
	4	1/2	49.3	10	22.8	38.5	22	23	1,980	1,466	1,446	1,426	
12.7 (1/2)	1	1/8	42.8	7	22.8	32	22	23	1,530	1,377	1,301	1,224	
	2	1/4	44.8	7	22.8	34	22	23	1,580	1,422	1,343	1,264	
12.7 (1/2)	3	3/8	43.8	9	22.8	33	22	23	1,580	1,422	1,343	1,264	
	4	1/2	49.3	10	22.8	38.5	22	23	1,580	1,422	1,343	1,264	

型式		R (PT) T 選択	R (PT) T 選択	L	L1	E	E1	F	ℓ	対辺		¥標準単価		¥スライド単価	
Type	D									本体H	ナットH	1~90	10~990	100~490	500以上
SKTGLK	3.18 (1/8)	1	1/8	24.9	22	2.5	5	13.4	18	12	12	1,790	1,415	1,397	1,361
		2	1/4	25.9	24	2.5	5	13.4	19	14	12	1,790	1,415	1,397	1,361
	4	1	1/8	27.8	22	3.5	5	15.3	20.5	14	14	1,600	1,199	1,120	1,040
		2	1/4	27.8	24	3.5	5	15.3	20.5	14	14	1,780	1,329	1,300	1,246
	6	1	1/8	27.9	22	5	5	15.4	20.5	14	14	1,650	1,221	1,155	1,106
		2	1/4	27.9	24	5	5	15.4	20.5	14	14	1,770	1,310	1,239	1,169
	6.35 (1/4)	3	3/8	28.9	27	5	5	15.4	21.5	17	14	2,600	1,924	1,872	1,794
		4	1/2	30.9	35	5	5	15.4	23.5	22	14	2,980	2,230	2,200	2,086
	8	1	1/8	27.9	22	5	5	15.4	20.5	14	14	1,350	1,067	1,040	1,013
		2	1/4	27.9	24	5	5	15.4	20.5	14	14	1,450	1,160	1,131	1,102
	8	3	3/8	28.9	27	5	5	15.4	21.5	17	14	2,380	1,904	1,857	1,821
		4	1/2	28.8	22	5	5	16.8	21	14	15.9	1,810	1,340	1,267	1,177
	9.53 (3/8)	1	1/8	28.8	24	6	6	16.8	21	14	15.9	1,840	1,361	1,288	1,196
		2	1/4	28.8	27	6	6	16.8	22	17	15.9	2,470	1,828	1,779	1,692
10	1	1/8	31.8	35	6	6	16.8	24	22	15.9	3,280	2,428	2,362	2,231	
	2	1/4	30.8	27	7										