

BRACKETS FOR AIR CYLINDERS


薄型シリンダ用取付金具

● CADデータフォルダ名: 55_Cylinders

■ フート形取付金具




Type	材質	S表面処理
CFKPB CFKPM	SPCC	四三酸化鉄皮膜 無電解ニッケルメッキ

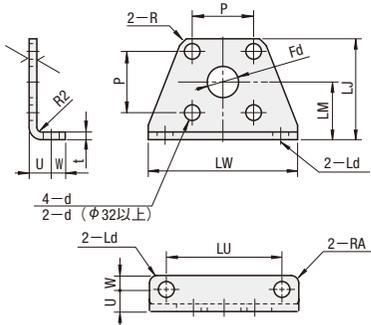


25 (✓)

シリンダ取付時の寸法

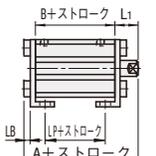

φ32以上

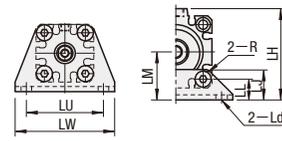

RoHS10

● LBは低頭六角穴付ボルト使用時の寸法です。





Type	型式 チューブ内径 (mm)	*A	B	d	Fd	*L1	Ld	LB	LP	t	LU	LJ	LM	LW	P	R	RA	U	W	LH	LL	¥基準単価	
																						CFKPB	CFKPM
CFKPB CFKPM	12	50.8(30.3)	22	4.5	10	24(3.5)	4.5	2.8	10	2	34	29.5	17	44	15.5	16	2	8	4.5	—	—	1,480	1,560
	16	52.3(30.3)	22	4.5	12	25.5(3.5)	4.5	2.8	10	2	38	33.5	19	48	20	19	2	8	5	—	—	1,510	1,620
	20	65.2(41.2)	29.5	6.5	14	28.5(4.5)	6.6	4	17.5	3.2	48	42	24	62	25.5	23.5	3.2	9.2	5.8	—	—	1,560	1,690
	25	72.2(44.7)	32.5	6.5	16	32.5(5)	6.6	4	17.5	3.2	52	46	26	66	28	26	3.2	10.7	5.8	—	—	1,600	1,760
	32	78.7(47.2)	33	6.5	—	38.5(7)	6.6	4	17	3.2	57	19	30	71	34	3.2	3.2	11.2	5.8	57	13	1,390	1,510
	40	85.2(53.7)	39.5	6.6	—	38.5(7)	6.6	4	23.5	3.2	64	18.5	33	78	40	3.2	3.2	11.2	7	64	13	1,530	1,660
	50	92.2(56.7)	40.5	9	—	43.5(8)	9	5	17.5	3.2	79	21	39	95	50	3.2	3.2	14.7	8	78	14	1,810	1,960

*MSCCN (固定ストロークタイプ) に取付金具を付けた場合は () 内寸法になります。

■ 二山クレス形取付金具




Type	材質	S表面処理	A付属品
CTKB CTKM	S45C	四三酸化鉄皮膜 無電解ニッケルメッキ	ピン1コ (S45C無電解ニッケルメッキ40~45HRC) 止め軸2コ (ばね用鋼)

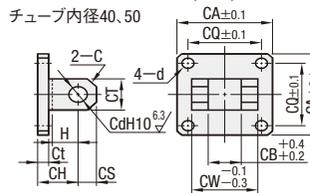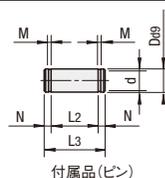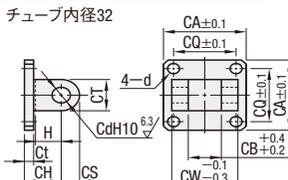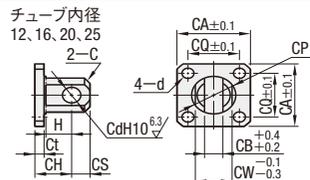

注) 面取りCの大きさは
チューブ内径40:C5, 50:C8

シリンダ取付時の寸法

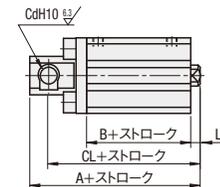

RoHS10

Type	型式 チューブ内径 (mm)	*A	B	*CL	*L1	Cd	CH	CS	H	Ct	CA	CQ	CB	CW	CT	CP	C	d	¥基準単価		
																			CTKB	CTKM	
CTKB CTKM	12	56(45.5)	22	50.0(39.5)	14(3.5)	5	14	6	7	4	25	15.5	5	10	—	12	C2	4.5	2,480	2,710	
	16	58.5(46.5)	22	52.5(40.5)	15.5(3.5)	5	15	6	10	4	29	20	6.5	12	—	14	C2	4.5	2,660	2,950	
	20	75(61)	29.5	66.0(52.0)	18.5(4.5)	8	18	9	12	5	36	25.5	8	16	—	20	C3	6.5	2,880	3,180	
	25	85(67.5)	32.5	75.0(57.5)	22.5(5)	10	20	10	14	5	40	28	10	20	—	24	C3	6.5	3,080	3,380	
	32	91.5(70)	33	81.5(60.0)	28.5(7)	10	20	10	14	5	45	34	18	36	20	—	—	C5	6.5	4,310	4,750
	40	100(78.5)	39.5	90(68.5)	28.5(7)	10	22	10	14	6	52	40	18	36	20	—	—	C5	6.5	5,220	5,550
	50	116(90.5)	40.5	102(76.5)	33.5(8)	14	28	14	20	7	64	50	22	44	28	—	C8	8.5	5,860	6,420	

*MSCCN (固定ストロークタイプ) に取付金具を付けた場合は () 内寸法になります。



Order 型式
注文例
CFKPB32
CTKB20



Delivery 在庫品 翌日出荷 P.133
出荷日
●ご希望によりPM6:00迄、当日出荷受付致します。



Price 数量スライド価格 (◎1円未満切り捨て) P.133
価格
●表示数量超えは
WOSIにてご確認ください。

数量区分	標準対応	個別対応
数量	1~4	5~10
値引率	基準単価	5%
		お見積り

■ 二山クレス形取付金具付属品

No.	D9	d	L2	L3	N	M	使用する止め輪
12	5	4.8	10.2	14.6	2.2	0.7	軸用C形 5
16			12.2	16.6			
20	8	7.6	16.2	21	2.4	0.9	軸用C形 8
25			20.2	25.6			
32	10	9.6	36.2	41.6	2.7	1.15	軸用C形 10
40							
50	14	13.4	44.2	50.6	3.2		軸用C形 14