


カムボトムガイドプレート RoHS10

CBGL

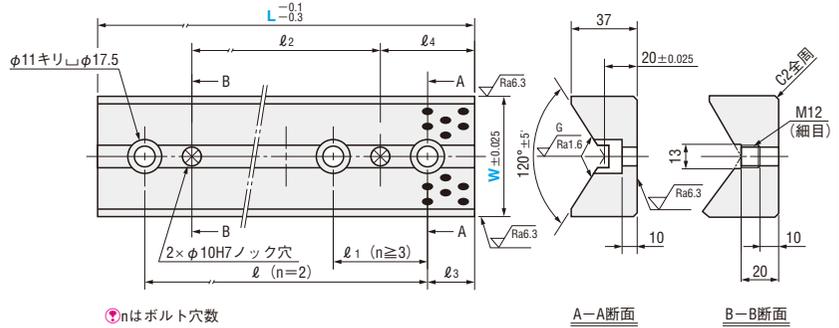

●nはボルト穴数

スライド方向



材質 銅合金
特殊固体潤滑剤(埋設)

ℓ	ℓ ₁	ℓ ₂	ℓ ₃	ℓ ₄	ボルト穴数n	型式	W	L
60	-	20	20	40	2	CBGL	65	100
75		25	25	50				125
100		50						150
-	75	100	25	50	3			200
	100	150						250
	125	200						300



Order
注文例

型式 W - L
CBGL 65 - 150




Delivery
出荷日

在庫品

カムボトムスライドプレート


RoHS10

CBPL

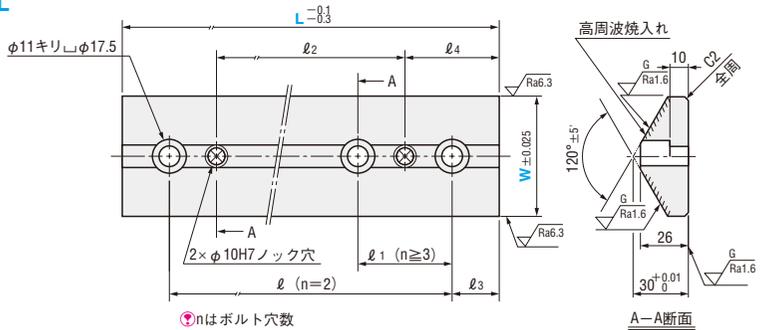

●nはボルト穴数

 CBGLとCBPLの組み合わせ h=50



材質 S45C
硬度 HRC55~
(高周波焼入れ)

ℓ	ℓ ₁	ℓ ₂	ℓ ₃	ℓ ₄	ボルト穴数n	型式	W	L
60	-	20	20	40	2	CBPL	65	100
75		25	25	50				125
100		50						150
-	75	100	25	50	3			200
	100	150						250
	125	200						300



Order
注文例

型式 W - L
CBPL 65 - 150



Delivery
出荷日

在庫品