


■外観寸法図

- アクセサリ(オプション)
 ●リミット針(2個セット): No.21AZB195
 ●外枠クランプ: No.21AZB148

単位:mm

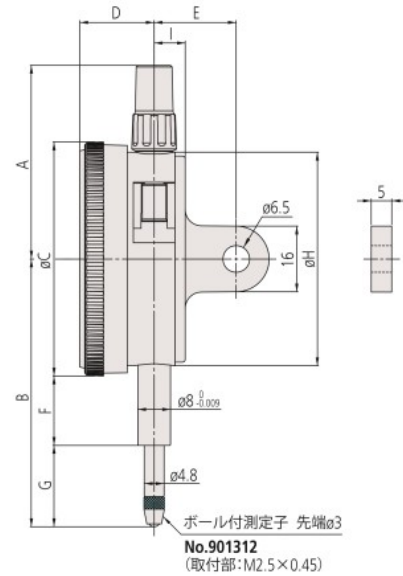

コードNo.	A	B	C	D	E	F	G	H	I	本体質量(g)	
										耳金付裏ぶた付	平裏ぶた付
2046A	47.2	65.2	57	18.1	20	16.9	19.8	52	7.6	144	135
2046A-09	47.2	65.2	57	18.1	20	16.9	19.8	52	7.6	146	137
2047A	47.2	65.2	57	18.1	20	16.9	19.8	52	7.6	144	135
2902A	47.2	65.2	57	18.1	20	16.9	19.8	52	7.6	144	135
2310A-10	47.2	65.2	57	18.1	20	16.9	19.8	52	7.6	146	137
2044A	47.2	65.2	57	18.1	20	16.9	19.8	52	7.6	145	136
2044A-09	47.2	65.2	57	18.1	20	16.9	19.8	52	7.6	147	138
2045A	47.2	65.2	57	18.1	20	16.9	19.8	52	7.6	145	136

※測定子詳細は、F-49～F-53ページを参照ください。

■仕様

仕様																	仕様																
コードNo. (耳金付裏ぶた)	コードNo. (平裏ぶた)	目量 (mm)	測定 範囲 (mm)	目盛 仕様	長針 1回転 (mm)	指示誤差 (MPE)			全測定 範囲 指示 誤差 (μm)	戻り 誤差 (μm)	繰り返し 精密度 (μm)	測定力 (N)	連続目盛	バックス目盛	逆目盛	1回転未満	倍目盛幅	シグナル	防水(防)	防水(防)	防塵・防滴	上死点ダンパ	下死点ダンパ	宝石入	露点指示	置針式	中2針	低測定力	バックリフター	指針調整式			
						1/10回転 (μm)	1/2回転 (μm)	1回転 (μm)																									
2046A	2046AB	0.01	10	±0-100	1	5	9	10	13	3	3	1.4以下																					
2046A-09	2046AB-09	0.01	10	±0-100	1	5	9	10	15	3	3	1.4以下																					
2047A	2047AB	0.01	10	0-50-0	1	5	9	10	13	3	3	1.4以下																					
2902A	2902AB	0.01	10	100-0	1	5	9	10	13	3	3	1.4以下																					
2310A-10	2310AB-10	0.01	10	±0-100	1	5	9	10	15	3	3	1.4以下																					
2044A	2044AB	0.01	5	±0-100	1	5	9	10	12	3	3	1.4以下																					
2044A-09	2044AB-09	0.01	5	±0-100	1	5	9	10	12	3	3	1.4以下																					
2045A	2045AB	0.01	5	0-50-0	1	5	9	10	12	3	3	1.4以下																					

※完成品検査は縦姿勢(測定子下向き姿勢)で行い精度保証をしています。

(仕様、価格、デザイン(外観)ならびにサービス内容などは、予告なしに変更することがあります。あらかじめご了承ください。)