


アイボルト (鋳造製)
Eye Bolt

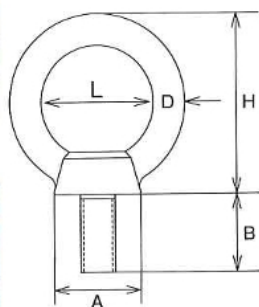


〈ミリネジ〉 Metric Thread 材質：ステンレス SUS304 (価格改定日 H28.1) (mm)


品番	D	L	H	B	A	捻径	weight (g)	参考使用荷重		価格(円)/個	入数	コード No.
								(kgf)	(kN)			
IB-2M	2	8	13	10	8	M-2	2	10	0.10	600	50	896
IB-3M	3	9	16	11.5	9	M-3	4	15	0.15	600	50	897
IB-4M	4	10	20	12	10	M-4	7	20	0.20	620	30	535
IB-5M	5	13	25	13	11	M-5	13	30	0.29	650	20	536
IB-6M	5.5	16	27	14	13	M-6	18	50	0.49	760	20	304
IB-8M	7	19	34	15	16	M-8	29	80	0.78	850	20	305
IB-10M	8	25	42	18	19	M-10	59	150	1.47	980	20	306
IB-12M	10	29	52	22	24	M-12	115	220	2.16	1,390	10	307
IB-14M	13	34	60	27	30	M-14	204	330	3.23	2,310	10	1001
IB-16M	13	34	61	27	30	M-16	220	450	4.41	2,730	10	308

〈ブネジ〉 Inch Thread 材質：ステンレス SUS304 (mm)

品番	D	L	H	B	A	捻径	weight (g)	参考使用荷重		価格(円)/個	入数	コード No.
								(kgf)	(kN)			
IB-6W	5.5	16	27	14	13	W-1/4	16	50	0.49	760	20	309
IB-8W	7	19	34	15	16	W-5/16	29	80	0.78	850	20	310
IB-10W	8	25	42	18	19	W-3/8	59	150	1.47	980	20	311
IB-12W	10	29	52	22	24	W-1/2	115	220	2.16	1,390	10	312
IB-16W	13	34	61	27	30	W-5/8	220	450	4.41	2,730	10	313

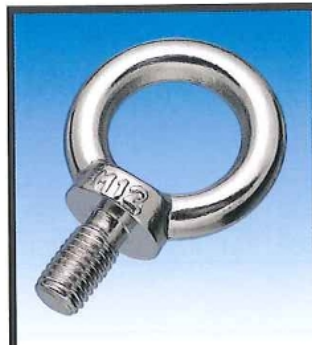

アイボルト (鍛造製)
Eye Bolt, Forged

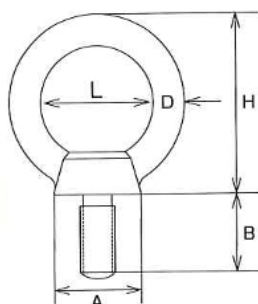

〈ミリネジ〉 Metric Thread 材質：ステンレス SUS304 (価格改定日 H28.1) (mm)

品番	D	L	H	B	A	捻径	weight (g)	参考使用荷重		価格(円)/個	入数	コード No.
								(kgf)	(kN)			
IBF-6M	5	15	26.5	14	13	M-6	18	50	0.49	880	20	2427
IBF-8M	6.3	20	33.3	15	16	M-8	33	80	0.78	970	20	1377
IBF-10M	8	25	41.5	18	20	M-10	70	150	1.47	1,100	20	1378
IBF-12M	10	30	51	22	25	M-12	125	220	2.16	1,560	10	1379
IBF-16M	12.5	35	60	27	30	M-16	200	450	4.41	3,110	10	1380
IBF-20M	16	40	71	30	35	M-20	380	630	6.18	4,200	5	1381
IBF-24M	20	50	90	38	45	M-24	760	950	9.31	6,550	5	1382

※サイズ24以上もご照会下さい。



アイボルト