


MOR フレキシブルカップリング - オルダムタイプ - セットスクリュータイプ

WEB 選定ナビ WEB CAD Download 高トルク 電気絶縁性 許容ミスアライメント大 偏心反力小

MOR

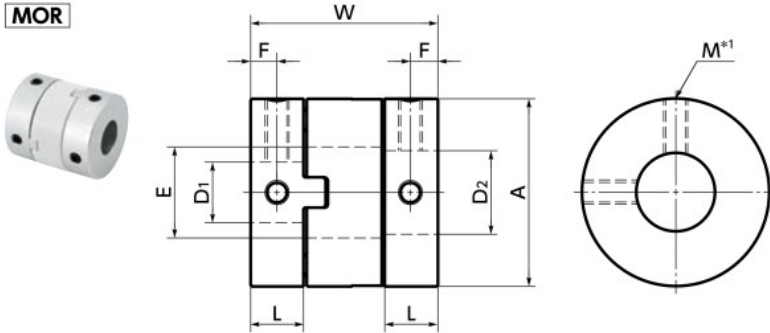

*1: 軸穴径がφ4以下の場合止めねじは1カ所です。

寸法・価格

単位: mm

| 品番 | 価格(円) | | A | L | W | E | F | M | ねじ締めつけトルク (N・m) |
|--------|-------|-------|----|------|------|------|-----|-----|-----------------|
| | 1組 | スペーサ | | | | | | | |
| MOR-6 | 810 | 160 | 6 | 2.5 | 8.4 | 2.1 | 1.3 | M2 | 0.3 |
| MOR-8 | 870 | 180 | 8 | 2.5 | 9.6 | 3.1 | 1.3 | M2 | 0.3 |
| MOR-10 | 940 | 200 | 10 | 2.9 | 10.4 | 4.1 | 1.4 | M2 | 0.3 |
| MOR-12 | 1,030 | 220 | 12 | 3.9 | 14.4 | 5.2 | 2 | M3 | 0.7 |
| MOR-15 | 1,090 | 220 | 15 | 4.4 | 16 | 8.2 | 2.2 | M3 | 0.7 |
| MOR-17 | 1,120 | 220 | 17 | 4.9 | 19.7 | 8.2 | 2.5 | M3 | 0.7 |
| MOR-20 | 1,250 | 250 | 20 | 5.8 | 21.6 | 12.2 | 2.9 | M4 | 1.7 |
| MOR-26 | 1,470 | 290 | 26 | 7.3 | 25.6 | 14.2 | 3.7 | M4 | 1.7 |
| MOR-30 | 1,630 | 330 | 30 | 10 | 32.6 | 16.2 | 5 | M4 | 1.7 |
| MOR-34 | 1,800 | 360 | 34 | 11.1 | 34 | 16.2 | 5.6 | M5 | 4 |
| MOR-38 | 3,050 | 600 | 38 | 12.1 | 40.1 | 20.3 | 6.1 | M5 | 4 |
| MOR-45 | 3,960 | 800 | 45 | 13.8 | 46 | 22.3 | 6.9 | M6 | 7 |
| MOR-55 | 4,840 | 950 | 55 | 18.7 | 57 | 26.5 | 9.4 | M8 | 15 |
| MOR-68 | 6,250 | 1,070 | 68 | 24 | 77 | 38.5 | 12 | M10 | 30 |

| 品番 | 標準軸穴径 D1・D2(寸法許容差H8) | | | | | | | | | | | | | | | | | | | | | | | |
|--------|-------------------------|-----|---|---|---|---|---|------|---|-------|----|----|----|----|----|----|----|----|----|----|----|----|----|---|
| | 1 | 1.5 | 2 | 3 | 4 | 5 | 6 | 6.35 | 8 | 9.525 | 10 | 12 | 14 | 15 | 16 | 18 | 20 | 22 | 25 | 28 | 30 | 35 | 38 | |
| MOR-6 | ● | ● | ● | | | | | | | | | | | | | | | | | | | | | |
| MOR-8 | ● | | ● | ● | | | | | | | | | | | | | | | | | | | | |
| MOR-10 | | | ● | ● | ● | | | | | | | | | | | | | | | | | | | |
| MOR-12 | | | | ● | ● | ● | | | | | | | | | | | | | | | | | | |
| MOR-15 | | | | ● | ● | ● | ● | ● | | | | | | | | | | | | | | | | |
| MOR-17 | | | | ● | ● | ● | ● | ● | | | | | | | | | | | | | | | | |
| MOR-20 | | | | ● | ● | ● | ● | ● | ● | ● | | | | | | | | | | | | | | |
| MOR-26 | | | | | ● | ● | ● | ● | ● | ● | ● | | | | | | | | | | | | | |
| MOR-30 | | | | | | ● | ● | ● | ● | ● | ● | ● | | | | | | | | | | | | |
| MOR-34 | | | | | | | ● | ● | ● | ● | ● | ● | ● | | | | | | | | | | | |
| MOR-38 | | | | | | | | ● | ● | ● | ● | ● | ● | ● | | | | | | | | | | |
| MOR-45 | | | | | | | | | ● | ● | ● | ● | ● | ● | ● | | | | | | | | | |
| MOR-55 | | | | | | | | | | ● | ● | ● | ● | ● | ● | ● | | | | | | | | |
| MOR-68 | | | | | | | | | | | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |

- 全商品に六角穴付き止めねじが付属しています。
- 適用軸径の推奨寸法許容差はh6およびh7です。
- ハブの一方がセットスクリュータイプ、他方がクランピングタイプその他の組み合わせのご注文にも応じます。

● 軸穴・キー溝追加加工 → P.xxxx
● クリーン洗浄・クリーン梱包 → P.xxxx
● SUS ステンレスねじ変更 → P.xxxx

対応可・別料金 お問い合わせください 対応可・別料金