


A-1



追加工サービス (P.6~P.9)

for use with A or AX belts

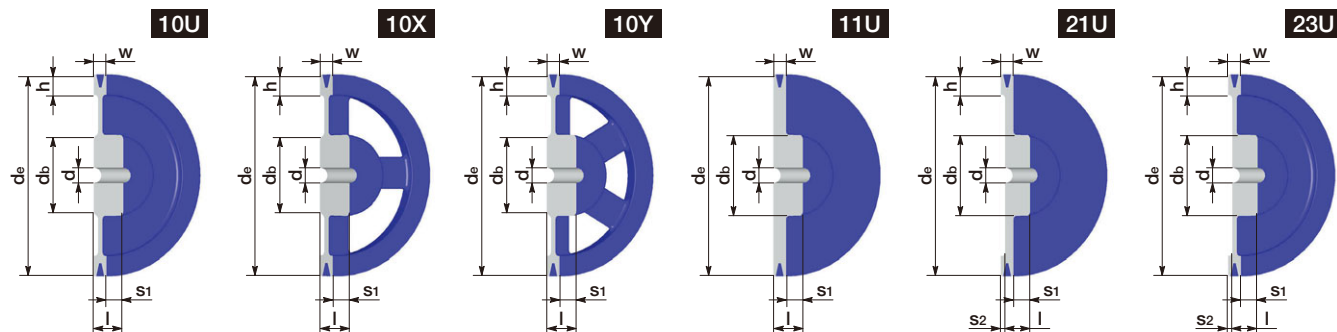

unit:mm

Catalog Number 品番	Price (Yen) 価格 (円)	dm 呼び径	de 外径	d Max. Bore 最大軸穴径	d Pilot Bore 下穴径	Type 形状図番	Hub ハブ				Rim リム		Moment of Inertia 慣性モーメント (kg・m ²)	Mass 質量 (kg)
							db	l	s1	s2	w	h ⁺² ₀		
50-A-1	580	50	59	22	—	11U	40	35	15	—	20	—	0.000134	0.44
56-A-1	680	56	65	22	—	11U	40	35	15	—	20	—	0.000190	0.51
63-A-1	800	63	72	25	—	11U	45	35	15	—	20	—	0.000297	0.64
67-A-1	820	67	76	25	—	11U	45	35	15	—	20	—	0.000363	0.70
71-A-1	850	71	80	25	—	21U	45	25	15	10	20	16	0.000403	0.63
75-A-1	870	75	84	25	—	21U	45	25	15	10	20	17	0.000489	0.69
80-A-1	900	80	89	25	—	21U	45	25	15	10	20	17	0.000606	0.75
83-A-1	950	83	92	25	—	21U	45	25	15	10	20	16	0.000674	0.77
85-A-1	960	85	94	25	—	21U	45	25	15	10	20	17	0.000744	0.81
88-A-1	1,020	88	97	25	—	21U	45	25	15	10	20	16	0.000823	0.83
90-A-1	1,030	90	99	25	—	21U	45	25	15	10	20	17	0.000906	0.87
93-A-1	1,140	93	102	25	—	21U	45	25	15	10	20	16	0.00100	0.90
95-A-1	1,160	95	104	25	—	21U	45	25	15	10	20	17	0.00109	0.94
98-A-1	1,290	98	107	28	—	21U	50	28	15	7	20	16	0.00129	1.11
100-A-1	1,310	100	109	28	—	21U	50	28	15	7	20	17	0.00140	1.15
103-A-1	1,510	103	112	28	—	21U	50	28	15	7	20	15.5	0.00153	1.19
106-A-1	1,530	106	115	28	—	21U	50	28	15	7	20	17	0.00173	1.26
109-A-1	1,620	109	118	28	—	21U	50	28	15	7	20	15.5	0.00188	1.29
112-A-1	1,630	112	121	28	—	21U	50	28	15	7	20	17	0.00212	1.37
118-A-1	1,640	118	127	28	—	23U	50	28	15	7	20	17	0.00216	1.20
125-A-1	1,680	125	134	28	—	23U	50	28	15	7	20	17	0.00262	1.28
132-A-1	1,860	132	141	28	—	23U	50	28	15	7	20	17	0.00315	1.36
140-A-1	2,020	140	149	28	—	23U	50	28	15	7	20	17	0.00385	1.46
150-A-1	2,370	150	159	32	—	10U	56	32	12	—	20	17	0.00496	1.75
160-A-1	2,650	160	169	32	—	10U	56	32	12	—	20	17	0.00617	1.88
170-A-1	2,700	170	179	32	—	10X	56	32	12	—	20	17	0.00670	1.76
180-A-1	2,800	180	189	32	—	10X	56	32	12	—	20	17	0.00804	1.85
190-A-1	3,010	190	199	32	—	10X	56	32	12	—	20	17	0.00953	1.94
200-A-1	3,100	200	209	32	—	10X	56	32	12	—	20	17	0.0112	2.03
212-A-1	3,340	212	221	32	—	10X	56	32	12	—	20	17	0.0135	2.14
224-A-1	3,470	224	233	32	—	10X	56	32	12	—	20	17	0.0164	2.34
236-A-1	3,800	236	245	32	—	10X	56	32	12	—	20	17	0.0193	2.45
250-A-1	4,020	250	259	35.5	—	10X	63	35	15	—	20	17	0.0241	2.92
280-A-1	4,600	280	289	35.5	—	10X	63	35	15	—	20	17	0.0343	3.23
300-A-1	5,100	300	309	35.5	—	10X	63	35	15	—	20	17	0.0435	3.56