


B-4 標準Vプーリー - B・BX適用

WEB 選定ナビ WEB CAD Download

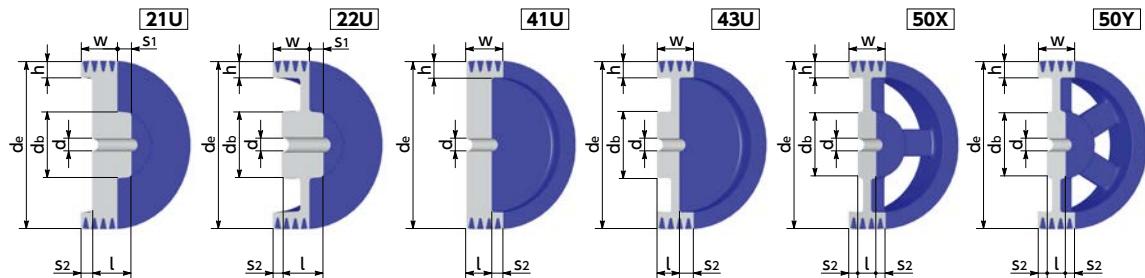

単位: mm

品番 1	価格 (円)	ピッチ円直径 d_p	外径 d_e	最大軸穴径 d	下穴径 d	形状図番	ハブ				リム		慣性モーメント ($kg \cdot m^2$)	質量 (kg)
							db	l	s1	s2	w	h^{+2}_0		
4-B-4	3,120	90.6	101.6	35	—	21U	63	46	19	57	84	18	0.00318	2.69
4-B-4F	3,360	90.6	101.6	36	—	41U	—	42	—	42	84	18	0.00317	2.63
4 1/2-B-4	3,810	103.3	114.3	35	—	21U	63	46	19	57	84	18	0.00497	3.23
4 1/2-B-4F	4,030	103.3	114.3	44	—	41U	—	42	—	42	84	18	0.00516	3.33
5-B-4	4,590	116	127	38	—	21U	69	48	22	58	84	18	0.00752	3.95
5-B-4F	4,940	116	127	51	—	41U	—	42	—	42	84	18	0.00796	4.11
5 1/2-B-4	5,240	128.7	139.7	38	—	21U	69	48	22	58	84	18	0.00108	4.58
6-B-4	5,900	141.4	152.4	38	—	22U	69	48	22	58	84	18	0.0131	4.43
6-B-4F	6,310	141.4	152.4	38	—	43U	69	46	—	38	84	18	0.013	4.37
6 1/2-B-4	6,390	154.1	165.1	38	—	22U	69	50	22	56	84	18	0.0173	4.92
7-B-4	6,710	166.8	177.8	46	—	50X	82	55	—	14.5	84	21	0.0221	5.69
8-B-4	7,600	192.2	203.2	46	—	50X	82	55	—	14.5	84	21	0.0339	6.38
9-B-4	8,260	217.6	228.6	46	—	50X	82	55	—	14.5	84	21	0.0498	7.08
10-B-4	9,400	243	254	49	—	50X	88	56	—	14	84	21	0.0705	8.1
11-B-4	10,300	268.4	279.4	49	—	50X	88	57	—	13.5	84	21	0.0959	8.88
12-B-4	12,400	293.8	304.8	49	—	50X	88	57	—	13.5	84	21	0.127	9.58
13-B-4	12,800	319.2	330.2	49	—	50X	88	57	—	13.5	84	21	0.163	10.3
14-B-4	14,400	344.6	355.6	52	—	50Y	94	57	—	13.5	84	21	0.21	11.6
15-B-4	15,100	370	381	52	—	50Y	94	58	—	13	84	21	0.267	12.7
16-B-4	17,200	395.4	406.4	52	—	50Y	94	58	—	13	84	21	0.327	13.5
18-B-4	21,100	446.2	457.2	53	—	50Y	95	58	—	13	84	18	0.475	15.2
20-B-4	23,900	497	508	53	—	50Y	95	58	—	13	84	18	0.663	16.9
22-B-4	29,200	547.8	558.8	54	—	50Y	97	62	—	11	84	21	1.14	23.4
24-B-4	33,400	598.6	609.6	57	—	50Y	102	62	—	11	84	21	1.51	25.9

追加工サービスをご利用ください。

Vプーリーに軸穴・キー溝・押しねじ穴の追加工をいたします。実働1日目出荷。

→ P.304



● 軸穴・キー溝・押しねじ追加工 → P.304
対応可・別料金

● 品番指定



直送



14時当日出荷



NBK



NBKネットショップ

20-B-4

1