


フリーSSプレート


PRECUT SS PLATES No.E-9793

RoHS対応

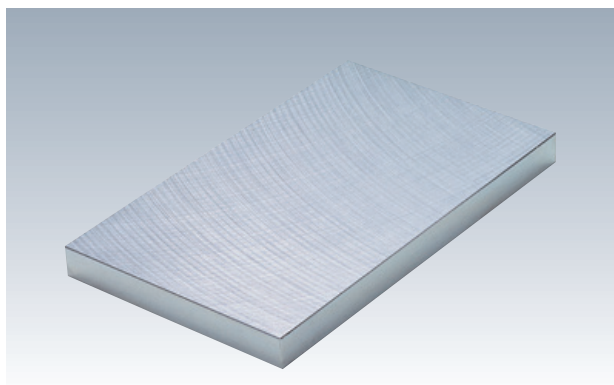

材 質 SS400

- A・B・C寸法は、各々1mm単位で製作いたします。
- C寸法の許容差は、FSAタイプ： $\begin{smallmatrix} +0.3 \\ +0.1 \end{smallmatrix}$
FSBタイプ： ± 0.1 があります。
- 同サイズであれば、FSA、FSBいずれも同価格です。
- ご注文例：[FSA-100-150-30](#)
タイプ A B C

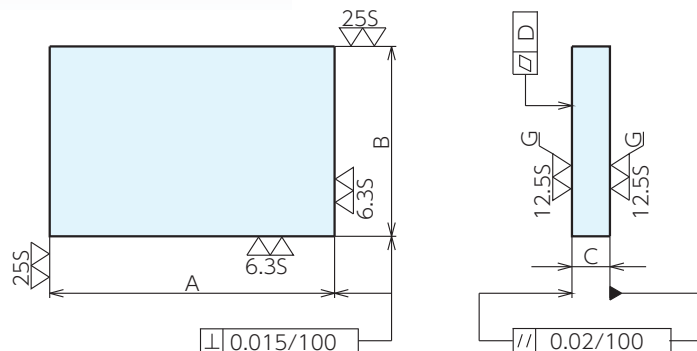

A・B	A・Bの許容差
99以下	± 0.2
100-250	± 0.25
251以上	± 0.4

タイプ	C
FSA	$\begin{smallmatrix} +0.3 \\ +0.1 \end{smallmatrix}$
FSB	± 0.1

C	D(平面度)
8-15	0.030/100
16-25	0.015/100
26以上	0.012/100

仕様・価格表

A	B	C											
		8~10	11~13	14~16	17~19	20~22	23~25	26~28	29~32	33~36	37~40	41~45	46~50
60~ 90	60~ 90	4,220	3,940	4,040	4,140	4,240	4,350	4,530	4,740	4,990	5,250	5,800	6,100
	91~120	4,630	4,350	4,480	4,600	4,740	4,870	5,100	5,350	5,650	6,000	6,650	7,000
	121~150	4,830	4,530	4,720	4,860	5,000	5,200	5,450	5,700	6,100	6,450	7,150	7,550
	151~180	5,050	4,720	4,880	5,050	5,200	5,350	5,600	5,900	6,200	6,600	7,300	7,750
	181~210	5,550	5,250	5,250	5,400	5,650	5,850	6,150	6,500	6,950	7,350	8,250	8,700
	211~240	6,550	6,000	6,350	6,550	6,800	7,050	7,450	7,800	8,300	8,800	9,800	10,300
	241~270	6,700	6,200	6,700	6,950	7,150	7,350	7,850	8,400	8,850	9,450	10,600	11,100
	271~300	6,950	6,450	6,900	7,100	7,350	7,650	8,200	8,700	9,300	9,900	11,100	11,700
	301~350	7,600	7,100	7,550	7,800	8,150	8,600	9,200	9,850	10,500	11,100	12,300	13,300
	351~400	8,300	7,700	8,200	8,550	8,850	9,550	10,200	10,900	11,600	12,200	13,800	14,600
	401~450	9,650	8,950	9,450	9,850	10,200	10,800	11,600	12,300	13,300	14,200	15,800	16,800
91~120	451~500	10,300	9,550	10,100	10,600	10,900	11,400	12,300	13,300	14,100	15,100	17,100	18,200
	91~120	4,870	4,590	4,760	4,930	5,100	5,250	5,450	5,700	6,050	6,450	7,150	7,550
	121~150	5,100	4,830	5,050	5,250	5,400	5,600	5,900	6,100	6,550	6,950	7,750	8,200
	151~180	5,350	5,100	5,350	5,550	5,800	6,000	6,350	6,600	7,050	7,500	8,350	8,850
	181~210	5,600	5,350	5,600	5,900	6,150	6,400	6,700	7,050	7,450	7,900	8,850	9,400
	211~240	7,000	6,500	6,800	7,150	7,450	7,750	8,300	8,850	9,450	10,100	11,200	11,900
	241~270	7,200	6,750	7,200	7,600	7,900	8,200	8,750	9,350	9,900	10,500	11,700	12,300
	271~300	7,450	7,000	7,350	7,750	8,100	8,450	9,100	9,750	10,300	10,900	12,200	12,900
	301~350	7,800	7,450	7,850	8,350	8,700	9,150	9,850	10,600	11,200	11,900	13,400	14,200
	351~400	9,750	8,950	9,500	9,950	10,300	10,800	11,700	12,500	13,400	14,100	16,000	17,100
	401~450	10,700	10,000	10,600	11,100	11,600	12,100	13,100	14,000	14,900	15,700	17,700	18,800
	451~500	11,100	10,500	11,100	11,800	12,200	12,800	13,900	14,900	15,800	16,600	18,800	20,000