

ロケーティングピンB型

LOCATING PINS (TYPE B) No.E-9601


RoHS対応



材質 BS.970 Gr.080M15 熱処理 焼入 HRC60

表面処理 黒染め

- 外径A及びBはユーザー様にて許容差に合せて加工して下さい。(セルフカット品)
- 外径A及びB研削仕上(仕上品)

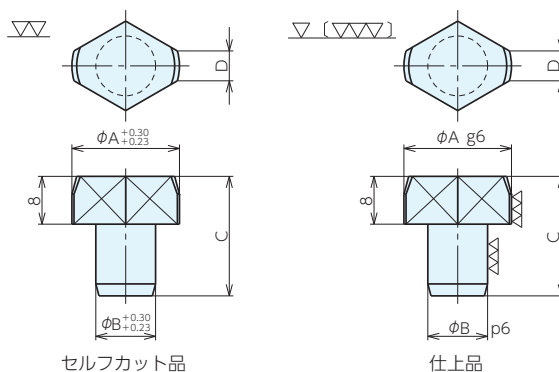

仕様・価格表(セルフカット品)

* 標準在庫品

オーダーNo.	No.	A _{+0.30/+0.23}	B _{+0.30/+0.23}	C	D	質量g	価格
* 914800	LP201B	8	6	16	2	6	2,290
* 914801	LP202B	10	6	16	3	7	2,290
* 914802	LP203B	12	8	18	3	11	2,330
* 914803	LP204B	14	8	18	4	11	2,460
* 914804	LP205B	15	10	20	4	18	2,560
* 914805	LP206B	16	10	20	4	21	2,760
* 914806	LP207B	18	10	20	5	21	2,780
* 914807	LP208B	20	12	24	5	28	2,850
* 914808	LP209B	22	12	24	6	34	3,080
* 914809	LP210B	24	12	24	6	34	3,390
* 914810	LP211B	25	12	24	6	40	3,410

仕様・価格表(仕上品)

* 標準在庫品

オーダーNo.	No.	A _{g6}	Aの許容差	B _{p6}	Bの許容差	C	D	質量g	価格
* 914811	LP251	8	-0.005 -0.014	6	+0.020 +0.012	16	2	6	5,000
* 914812	LP252	10	-0.005 -0.014	6	+0.020 +0.012	16	3	7	5,000
* 914813	LP253	12	-0.006 -0.017	8	+0.024 +0.015	18	3	11	5,500
* 914814	LP254	14	-0.006 -0.017	8	+0.024 +0.015	18	4	11	5,500
* 914815	LP255	15	-0.006 -0.017	10	+0.024 +0.015	20	4	18	5,750
* 914816	LP256	16	-0.006 -0.017	10	+0.024 +0.015	20	4	21	5,850
* 914817	LP257	18	-0.006 -0.017	10	+0.024 +0.015	20	5	21	5,850
* 914818	LP258	20	-0.007 -0.020	12	+0.029 +0.018	24	5	28	5,850
* 914819	LP259	22	-0.007 -0.020	12	+0.029 +0.018	24	6	34	6,200
* 914821	LP261	25	-0.007 -0.020	12	+0.029 +0.018	24	6	40	6,750

使用例

