
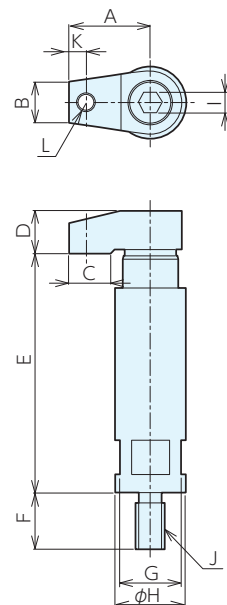


外形寸法

SS-04035A
SS-06XXXA
SS-08XXXA

SS-12XXXA
SS-12XXXB
SS-16XXXB

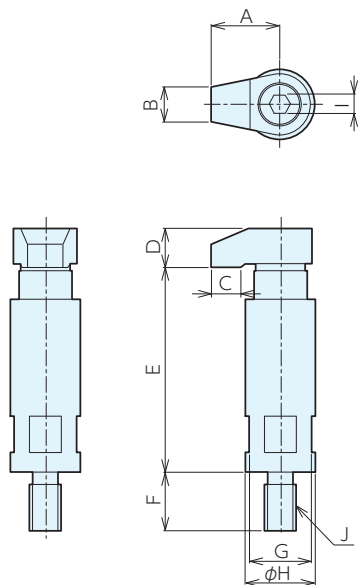

No.	A	B	C	D	E	F	G	H	I	J(並目)	K	L(並目)
SS-04035A	16	7	7	7	35- 42	13	13	15	3	M 6×1.0	-	-
SS-06045A	18	9	8	10	45- 53	15	16	18	5	M 8×1.25	-	-
SS-06050A	18	9	8	10	53- 61	15	16	18	5	M 8×1.25	-	-
SS-08050A	20	12	7	12	50- 60	15	17	21	6	M 8×1.25	-	-
SS-08060A	20	12	7	12	60- 70	15	17	21	6	M 8×1.25	-	-
SS-08070A	20	12	7	12	70- 80	15	17	21	6	M 8×1.25	-	-
SS-12090A	36	18	15	19	93-105	25	27	32	10	M12×1.75	7.5	M8×1.25
SS-12105A	36	18	15	19	108-120	25	27	32	10	M12×1.75	7.5	M8×1.25
SS-12120A	36	18	15	19	123-135	25	27	32	10	M12×1.75	7.5	M8×1.25
SS-12135A	36	18	15	19	138-150	25	27	32	10	M12×1.75	7.5	M8×1.25
SS-12150A	36	18	15	19	153-165	25	27	32	10	M12×1.75	7.5	M8×1.25
SS-12090B	36	18	15	19	93-105	25	27	32	10	M16×2	7.5	M8×1.25
SS-12105B	36	18	15	19	108-120	25	27	32	10	M16×2	7.5	M8×1.25
SS-12120B	36	18	15	19	123-135	25	27	32	10	M16×2	7.5	M8×1.25
SS-12135B	36	18	15	19	138-150	25	27	32	10	M16×2	7.5	M8×1.25
SS-12150B	36	18	15	19	153-165	25	27	32	10	M16×2	7.5	M8×1.25
SS-16090B	50	20	15	27	93-105	25	36	40	14	M16×2	7.5	M8×1.25
SS-16105B	50	20	15	27	108-120	25	36	40	14	M16×2	7.5	M8×1.25
SS-16120B	50	20	15	27	123-135	25	36	40	14	M16×2	7.5	M8×1.25
SS-16135B	50	20	15	27	138-150	25	36	40	14	M16×2	7.5	M8×1.25
SS-16150B	50	20	15	27	153-165	25	36	40	14	M16×2	7.5	M8×1.25

治具段取システム
(Q-ロック)

治具ベース

ロケータイング
エレメント

クランプユニット

クランプングパーツ

メカニカルパーツ

マシンバイス

定盤・測定機器

作業工具