


ステップクランプ

RoHS対応



STEP CLAMPS No.E-9413

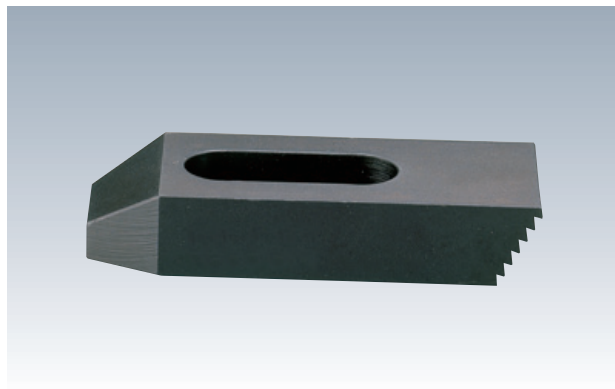

材質 S45C 熱処理 焼入HRC30±5

表面処理 黒染め

●ステップブロックとペアで使います。

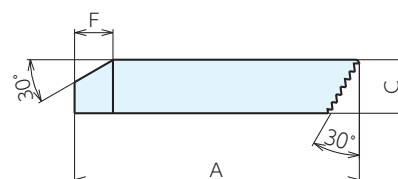
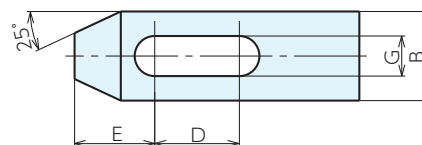


仕様・価格表

* 標準在庫品 1個価格

オーダーNo.	No.	適合ボルト	A	B	C	D	E	F	G	質量kg	価格
* 901106	STC0101	M 8	60	25	12	21	20	11	9	0.10	2,140
* 901993	STC0102	M 8	100	25	16	38	23	14	9	0.23	2,770
* 901994	STC0103	M 8	150	25	19	73	27	17	9	0.40	3,430
* 901995	STC0201	M10	60	25	12	19	22	11	11	0.09	2,140
* 901996	STC0202	M10	100	25	16	38	25	14	11	0.22	2,770
* 901997	STC0203	M10	150	25	19	56	28	17	11	0.40	3,430
* 901998	STC0301	M12	60	25	12	18	23	11	13	0.09	2,300
* 901999	STC0302	M12	100	32	19	32	28	17	13	0.33	2,970
* 902000	STC0303	M12	150	32	22	51	33	19	13	0.61	3,470
* 902001	STC0401	M16	60	32	16	10	27	14	18	0.15	2,370
* 902002	STC0402	M16	100	38	19	31	31	17	18	0.38	3,280
* 902003	STC0403	M16	150	38	22	48	33	19	18	0.70	3,860
* 902004	STC0501	M20	100	38	19	27	31	17	22	0.35	3,430
* 902005	STC0502	M20	150	38	25	48	38	22	22	0.71	3,910
* 902006	STC0503	M20	200	50	30	80	41	25	22	1.63	5,500
* 902007	STC0601	M22	150	50	32	42	44	27	24	1.29	6,250
* 902008	STC0602	M22	200	50	32	70	47	30	24	1.69	9,100
* 902009	STC0603	M22	250	50	38	102	52	33	24	2.60	10,300
* 902010	STC0701	M24	150	50	32	42	46	27	26	1.29	6,250
* 902011	STC0702	M24	200	50	32	70	49	30	26	1.86	9,100
* 902012	STC0703	M24	250	50	38	102	52	33	26	2.46	10,300

使用例

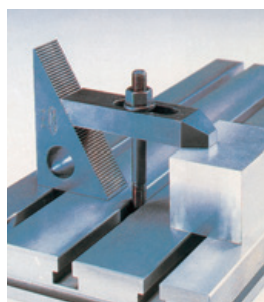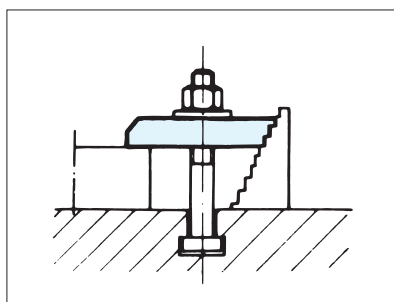

参照ページ

