

インサートノズルPM-ST型

INSERT NOZZLES No.E-9991


RoHS対応



材質 本体:B-1STタイプ/真鍮 B-2STタイプ/SUS416
ノズル・ボール:SUS303

最大圧力 10MPa 耐熱温度 70℃

●10MPaの高圧タイプです。

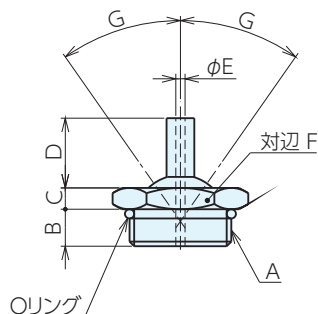


仕様・価格表

* 標準在庫品

オーダーNo.	No.	A	B	C	D	E	F	G	質量g	単品価格	
										1~9個	10個以上
* 972929	PM1B-1ST	7/16-20UNJF	4	2.3	6.4	1	12.7	37°	5	3,900	3,480
* 972930	PM1B-2ST	7/16-20UNJF	4	2.3	6.4	1	12.7	37°	5	4,590	4,170
* 972931	PM2B-1ST	7/16-20UNJF	4	2.3	6.4	1.6	12.7	37°	5	3,900	3,480
* 972932	PM2B-2ST	7/16-20UNJF	4	2.3	6.4	1.6	12.7	37°	5	4,590	4,170
* 972933	PM3B-1ST	7/16-20UNJF	4	2.3	6.4	2.2	12.7	37°	5	3,900	3,480
* 972934	PM3B-2ST	7/16-20UNJF	4	2.3	6.4	2.2	12.7	37°	5	4,590	4,170
* 972935	PM4B-1ST	7/16-20UNJF	4	2.3	0	3	12.7	41°	5	3,900	3,480
* 972936	PM4B-2ST	7/16-20UNJF	4	2.3	0	3	12.7	41°	5	4,590	4,170
* 972937	PM5B-1ST	7/16-20UNJF	4	2.3	6.4	3	12.7	30°	5	3,900	3,480
* 972938	PM5B-2ST	7/16-20UNJF	4	2.3	6.4	3	12.7	30°	5	4,590	4,170
* 115885	PM1C-1ST2	M8X1	4.1	2	6.4	1	9.5	34°	2	4,760	4,280
* 115886	PM2C-1ST2	M8X1	4.1	2	6.4	1.6	9.5	34°	2	4,920	4,440
* 115887	PM3C-1ST1	M8X1	4.1	2	0	2.2	9.5	36°	2	4,760	4,280
* 115888	PM3C-1ST2	M8X1	4.1	2	6.4	2.2	9.5	26°	2	4,920	4,440
* 115889	PM1D-1ST2	M10X1	4.2	1.9	6.4	1	12.7	31°	4	4,760	4,280
* 115890	PM2D-1ST2	M10X1	4.2	1.9	6.4	1.6	12.7	31°	4	4,920	4,440
* 115891	PM3D-1ST2	M10X1	4.2	1.9	6.4	2.2	12.7	31°	4	4,740	4,270
* 115892	PM5D-1ST1	M10X1	4.2	1.9	0	M3.5	12.7	26°	4	4,660	4,200
* 115893	PM2E-1ST2	M12X1	4.3	2.3	6.4	1.6	14.3	37°	6	5,600	5,000
* 115894	PM2E-1ST4	M12X1	4.3	2.3	31.8	1.6	14.3	26°	8	6,550	5,900
* 115895	PM3E-1ST2	M12X1	4.3	2.3	6.4	2.2	14.3	37°	6	5,600	5,000
* 115896	PM3E-1ST4	M12X1	4.3	2.3	31.8	2.2	14.3	26°	8	6,550	5,900
* 115897	PM4E-1ST2	M12X1	4.3	2.3	6.4	3	14.3	30°	6	5,600	5,050
* 115898	PM4E-1ST3	M12X1	4.3	2.3	12.8	3	14.3	30°	7	5,850	5,300
* 115899	PM4E-1ST4	M12X1	4.3	2.3	31.8	3	14.3	26°	8	6,550	5,900
* 115900	PM6E-1ST1	M12X1	4.3	2.3	0	M4	14.3	30°	6	5,500	4,950

取付穴推奨寸法 PM-ST型

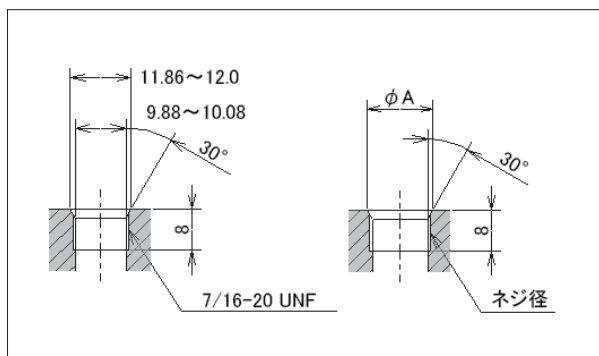

使用例

