


AQRVDOH3D

超硬 REVO D h7 140° 26°~30° h6 3.0-16.0
工具材料 コーティング 直径許容差 先端角 ねじれ角 シャンク許容差 直径範囲

レボ
アクアREVOドリルオイルホール 3D
 AquaREVO Drills Oil-Hole 3D

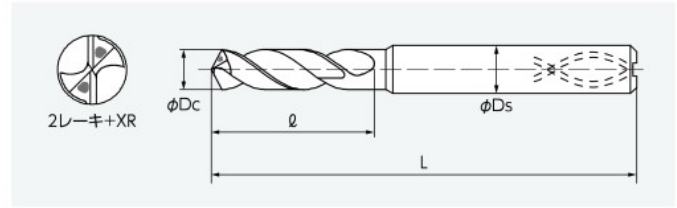

LIST9864 オーダ方法 Order 商品記号 Code

単位 (Unit):mm

商品記号	直径	溝長	全長	シャンク径	在庫	参考価格(円)			
Code	Dc	ℓ	L	Ds	Stock	Price(¥)			
AQRVDOH3D0300	3.0	19	68	3		10,200			
AQRVDOH3D0310	3.1	21	72	4		10,900			
AQRVDOH3D0320	3.2					10,900			
AQRVDOH3D0330	3.3					10,900			
AQRVDOH3D0340	3.4					10,900			
AQRVDOH3D0350	3.5					10,900			
AQRVDOH3D0360	3.6					11,400			
AQRVDOH3D0370	3.7	23	72	4		11,400			
AQRVDOH3D0380	3.8					11,400			
AQRVDOH3D0390	3.9					11,400			
AQRVDOH3D0400	4.0					11,400			
AQRVDOH3D0410	4.1	26	80	5		12,000			
AQRVDOH3D0420	4.2					12,000			
AQRVDOH3D0430	4.3					12,000			
AQRVDOH3D0440	4.4					12,000			
AQRVDOH3D0450	4.5					12,000			
AQRVDOH3D0460	4.6					12,900			
AQRVDOH3D0470	4.7					12,900			
AQRVDOH3D0480	4.8					12,900			
AQRVDOH3D0490	4.9	29	80	5		12,900			
AQRVDOH3D0500	5.0					12,900			
AQRVDOH3D0510	5.1					13,600			
AQRVDOH3D0520	5.2					13,600			
AQRVDOH3D0530	5.3					13,600			
AQRVDOH3D0540	5.4					13,600			
AQRVDOH3D0550	5.5					13,600			
AQRVDOH3D0560	5.6				32	82	6		14,200
AQRVDOH3D0570	5.7		14,200						
AQRVDOH3D0580	5.8		14,200						
AQRVDOH3D0590	5.9		14,200						
AQRVDOH3D0600	6.0		14,200						
AQRVDOH3D0610	6.1	34	88	7					14,200
AQRVDOH3D0620	6.2					14,200			
AQRVDOH3D0630	6.3					14,200			
AQRVDOH3D0640	6.4					14,200			
AQRVDOH3D0650	6.5					14,200			
AQRVDOH3D0660	6.6				37	88	7		15,100
AQRVDOH3D0670	6.7								15,100
AQRVDOH3D0680	6.8								15,100
AQRVDOH3D0690	6.9		15,100						

商品記号	直径	溝長	全長	シャンク径	在庫	参考価格(円)			
Code	Dc	ℓ	L	Ds	Stock	Price(¥)			
AQRVDOH3D0700	7.0	37	88	7		15,100			
AQRVDOH3D0710	7.1	39	94	8		15,900			
AQRVDOH3D0720	7.2					15,900			
AQRVDOH3D0730	7.3					15,900			
AQRVDOH3D0740	7.4					15,900			
AQRVDOH3D0750	7.5					15,900			
AQRVDOH3D0760	7.6					16,900			
AQRVDOH3D0770	7.7	42	94	8		16,900			
AQRVDOH3D0780	7.8					16,900			
AQRVDOH3D0790	7.9					16,900			
AQRVDOH3D0800	8.0					16,900			
AQRVDOH3D0810	8.1	44	100	9		18,400			
AQRVDOH3D0820	8.2					18,400			
AQRVDOH3D0830	8.3					18,400			
AQRVDOH3D0840	8.4					18,400			
AQRVDOH3D0850	8.5					18,400			
AQRVDOH3D0860	8.6				47	100	9		19,200
AQRVDOH3D0870	8.7								19,200
AQRVDOH3D0880	8.8								19,200
AQRVDOH3D0890	8.9		19,200						
AQRVDOH3D0900	9.0	49	106	10		19,200			
AQRVDOH3D0910	9.1					20,200			
AQRVDOH3D0920	9.2					20,200			
AQRVDOH3D0930	9.3					20,200			
AQRVDOH3D0940	9.4					20,200			
AQRVDOH3D0950	9.5					20,200			
AQRVDOH3D0960	9.6				52	106	10		20,700
AQRVDOH3D0970	9.7								20,700
AQRVDOH3D0980	9.8		20,700						
AQRVDOH3D0990	9.9		20,700						
AQRVDOH3D1000	10.0	54	116	11		20,700			
AQRVDOH3D1010	10.1					21,600			
AQRVDOH3D1020	10.2					21,600			
AQRVDOH3D1030	10.3					21,600			
AQRVDOH3D1040	10.4					21,600			
AQRVDOH3D1050	10.5				57	116	11		21,600
AQRVDOH3D1060	10.6								22,200
AQRVDOH3D1070	10.7								22,200
AQRVDOH3D1080	10.8		22,200						
AQRVDOH3D1090	10.9		22,200						