


●鋼、鋳鉄の高効率加工ができます。穴深さ 5D までノンステップ加工ができます。

Able to handle drilling in steel and cast iron efficiently. Can handle non-step drilling up to 5 diameters.

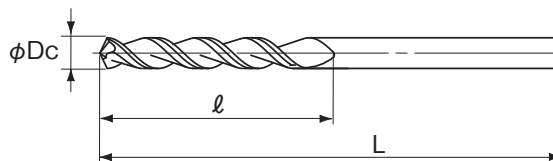

LIST 6536

オーダ方法 商品記号

単位 (Unit) : mm

商品記号 Code	直径 Dc	溝長 ℓ	全長 L	在庫 Stock	参考価格(円) Price (¥)
AGPSD1.0	1.0	12	34		922
AGPSD1.1	1.1	14	36		1,080
AGPSD1.2	1.2				1,020
AGPSD1.3	1.3	16	38		1,080
AGPSD1.4	1.4				1,080
AGPSD1.5	1.5	18	40		912
AGPSD1.6	1.6				976
AGPSD1.7	1.7	20	43		1,080
AGPSD1.8	1.8				1,020
AGPSD1.9	1.9	22	46		1,020
AGPSD2.0	2.0				837
AGPSD2.1	2.1	24	49		1,230
AGPSD2.2	2.2				1,230
AGPSD2.3	2.3	27	53		1,120
AGPSD2.4	2.4				1,230
AGPSD2.5	2.5	30	57		1,120
AGPSD2.6	2.6				1,120
AGPSD2.7	2.7				1,120
AGPSD2.8	2.8				1,180
AGPSD2.9	2.9	33	61		1,120
AGPSD3.0	3.0				1,120
AGPSD3.1	3.1				1,330
AGPSD3.2	3.2	36	65		1,330
AGPSD3.3	3.3				1,330
AGPSD3.4	3.4				1,330
AGPSD3.5	3.5	39	70		1,470
AGPSD3.6	3.6				1,470
AGPSD3.7	3.7				1,470
AGPSD3.8	3.8				1,470
AGPSD3.9	3.9				1,470
AGPSD4.0	4.0	43	75	●	1,470
AGPSD4.1	4.1				1,650
AGPSD4.2	4.2				1,650
AGPSD4.3	4.3				1,650
AGPSD4.4	4.4				1,650
AGPSD4.5	4.5	47	80		1,650
AGPSD4.6	4.6				1,860
AGPSD4.7	4.7				1,860
AGPSD4.8	4.8				1,860
AGPSD4.9	4.9				1,860
AGPSD5.0	5.0				1,860
AGPSD5.1	5.1	52	86		2,410
AGPSD5.2	5.2				2,410
AGPSD5.3	5.3				2,410
AGPSD5.4	5.4				2,410
AGPSD5.5	5.5				2,410
AGPSD5.6	5.6				2,430
AGPSD5.7	5.7	57	93		2,430
AGPSD5.8	5.8				2,430
AGPSD5.9	5.9				2,430
AGPSD6.0	6.0				2,430
AGPSD6.1	6.1				2,610
AGPSD6.2	6.2				2,610
AGPSD6.3	6.3				2,610
AGPSD6.4	6.4	63	101		2,610
AGPSD6.5	6.5				2,610
AGPSD6.6	6.6				2,700
AGPSD6.7	6.7				2,700
AGPSD6.8	6.8				2,700
AGPSD6.9	6.9				2,700
AGPSD7.0	7.0	69	109		2,700
AGPSD7.1	7.1				2,880

商品記号 Code	直径 Dc	溝長 ℓ	全長 L	在庫 Stock	参考価格(円) Price (¥)
AGPSD7.2	7.2				2,880
AGPSD7.3	7.3				2,880
AGPSD7.4	7.4	69	109		2,880
AGPSD7.5	7.5				2,880
AGPSD7.6	7.6				3,060
AGPSD7.7	7.7				3,060
AGPSD7.8	7.8				3,060
AGPSD7.9	7.9				3,060
AGPSD8.0	8.0				3,060
AGPSD8.1	8.1	75	117		3,390
AGPSD8.2	8.2				3,390
AGPSD8.3	8.3				3,390
AGPSD8.4	8.4				3,390
AGPSD8.5	8.5				3,390
AGPSD8.6	8.6				3,550
AGPSD8.7	8.7				3,550
AGPSD8.8	8.8				3,550
AGPSD8.9	8.9				3,550
AGPSD9.0	9.0				3,550
AGPSD9.1	9.1	81	125		4,110
AGPSD9.2	9.2				4,110
AGPSD9.3	9.3				4,110
AGPSD9.4	9.4				4,110
AGPSD9.5	9.5				4,110
AGPSD9.6	9.6				4,580
AGPSD9.7	9.7				4,580
AGPSD9.8	9.8				4,580
AGPSD9.9	9.9				5,040
AGPSD10.0	10.0				4,580
AGPSD10.1	10.1	87	133	●	5,650
AGPSD10.2	10.2				5,400
AGPSD10.3	10.3				5,400
AGPSD10.4	10.4				5,650
AGPSD10.5	10.5				5,400
AGPSD10.6	10.6				6,290
AGPSD10.7	10.7				6,290
AGPSD10.8	10.8				6,290
AGPSD10.9	10.9				6,290
AGPSD11.0	11.0				5,720
AGPSD11.1	11.1				6,940
AGPSD11.2	11.2				6,940
AGPSD11.3	11.3	94	142		6,940
AGPSD11.4	11.4				6,940
AGPSD11.5	11.5				6,320
AGPSD11.6	11.6				7,540
AGPSD11.7	11.7				7,540
AGPSD11.8	11.8				7,540
AGPSD11.9	11.9				7,540
AGPSD12.0	12.0				6,850
AGPSD12.1	12.1				9,760
AGPSD12.2	12.2				9,760
AGPSD12.3	12.3				9,760
AGPSD12.4	12.4				9,760
AGPSD12.5	12.5	101	151		8,890
AGPSD12.6	12.6				10,600
AGPSD12.7	12.7				10,600
AGPSD12.8	12.8				10,600
AGPSD12.9	12.9				10,600
AGPSD13.0	13.0				9,500

※ 1 本包装 (2.0mm 未満は 10 本包装)  
 参考価格は 1 本あたりの価格です。  
 ※ Sold one per package (10 per package if below 2.0mm)  
 Price is for one drill bit.

新商品

超硬ドリル

ハイスドリル

タップ

超硬  
エンドミル

ハイス  
エンドミル

切断工具

バック・  
セット商品  
その他

精密工具

技術資料  
索引