


PP/BT

ポリプロピレン／六角ボルト
Polypropylene / Hexagon head bolt

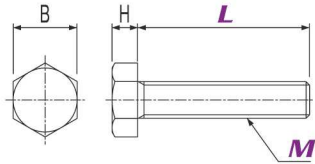


品番 Part number		PP/BT [Ⓜ] -L							
M		M4	M5	M6	M8	M10	M12		
ピッチ / Pitch		0.7	0.8	1	1.25	1.5	1.75		
B×H		7×2.8	8×3.5	10×4	13×5.5	17×7	19×8		
L		100	100	100	100	—	—		
12		100	100	100	100	—	—		
15		100	100	100	100	—	—		
20		100	100	100	100	100	50		
25		100	100	100	100	100	50		
30		—	100	100	100	50	50		
35		—	—	—	—	50	50		
40		—	—	—	100	50	50		
50		—	—	—	—	50	—		
70		—	—	—	—	—	25		

表中の赤字部分は半ネジとなります。M10-50(S=25)
Red font in the table indicates partially threaded screw.

販売単位 Quantity

PP/NT


ポリプロピレン／六角ナット
Polypropylene / Hexagon nut

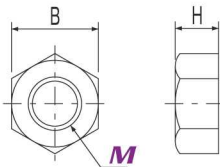

品番 Part number		PP/NT [Ⓜ]							
M		M4	M5	M6	M8	M10	M12		
ピッチ / Pitch		0.7	0.8	1	1.25	1.5	1.75		
B×H		7×3.2	8×4	10×5	13×6.5	17×8	19×10		
販売単位 Quantity		100	100	100	100	100	100		

PP/W

ポリプロピレン／ワッシャー
Polypropylene / Washer

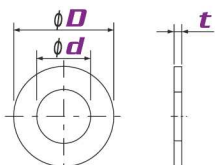

品番 Part number		PP/W [Ⓧ] - [Ⓧ] - [Ⓧ]							
呼び径 / Nominal diameter		4	5	6	8	10	12		
d×D		4.3×9	5.3×10	6.4×12.5	8.4×17	10.5×21	13×24		
t		0.8	1	1.6	1.6	2	2.5		
販売単位 Quantity		100	100	100	100	100	100		