



製品型式・寸法表

プラグ PH型 (チューブ取付用)

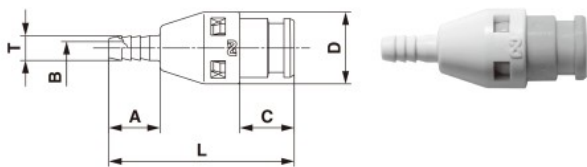


色	製品型式	相手側 チューブサイズ (mm)	内蔵 バルブ	質量 (g)	寸法 (mm)					
					L	A	C	φD	φT	φB
アイボリー	SPC-04PH-IVR	内径φ4	○	3.1	(36)	10	(10.5)	14	4.8	2.5
	SPC-04PH-VL-IVR	内径φ4	—	2.6	(36)	10	(10.5)	14	4.8	2.5
	SPC-06PH-IVR	内径φ6	○	3.4	(40)	15	(10.5)	14	7	3.6
	SPC-06PH-VL-IVR	内径φ6	—	2.9	(40)	15	(10.5)	14	7	3.6
青	SPC-04PH-BLU	内径φ4	○	3.1	(36)	10	(10.5)	14	4.8	2.5
	SPC-04PH-VL-BLU	内径φ4	—	2.6	(36)	10	(10.5)	14	4.8	2.5
	SPC-06PH-BLU	内径φ6	○	3.4	(40)	15	(10.5)	14	7	3.6
	SPC-06PH-VL-BLU	内径φ6	—	2.9	(40)	15	(10.5)	14	7	3.6
黄	SPC-04PH-YEL	内径φ4	○	3.1	(36)	10	(10.5)	14	4.8	2.5
	SPC-04PH-VL-YEL	内径φ4	—	2.6	(36)	10	(10.5)	14	4.8	2.5
	SPC-06PH-YEL	内径φ6	○	3.4	(40)	15	(10.5)	14	7	3.6
	SPC-06PH-VL-YEL	内径φ6	—	2.9	(40)	15	(10.5)	14	7	3.6
ホワイト	SPC-04PH-PNK	内径φ4	○	3.1	(36)	10	(10.5)	14	4.8	2.5
	SPC-04PH-VL-PNK	内径φ4	—	2.6	(36)	10	(10.5)	14	4.8	2.5
	SPC-06PH-PNK	内径φ6	○	3.4	(40)	15	(10.5)	14	7	3.6
	SPC-06PH-VL-PNK	内径φ6	—	2.9	(40)	15	(10.5)	14	7	3.6
緑	SPC-04PH-GRN	内径φ4	○	3.1	(36)	10	(10.5)	14	4.8	2.5
	SPC-04PH-VL-GRN	内径φ4	—	2.6	(36)	10	(10.5)	14	4.8	2.5
	SPC-06PH-GRN	内径φ6	○	3.4	(40)	15	(10.5)	14	7	3.6
	SPC-06PH-VL-GRN	内径φ6	—	2.9	(40)	15	(10.5)	14	7	3.6

ソケット SH型 (チューブ取付用)

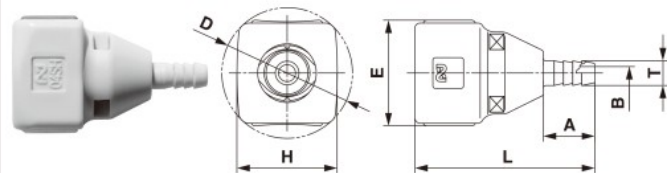


色	製品型式	相手側 チューブサイズ (mm)	内蔵 バルブ	質量 (g)	寸法 (mm)						
					L	A	E	φT	φB	H	φD
アイボリー	SPC-04SH-IVR	内径φ4	○	6.5	35	10	(20.3)	4.8	2.5	19.5	(25.5)
	SPC-04SH-VL-IVR	内径φ4	—	6.1	35	10	(20.3)	4.8	2.5	19.5	(25.5)
	SPC-06SH-IVR	内径φ6	○	7.0	40	15	(20.3)	7	3.6	19.5	(25.5)
	SPC-06SH-VL-IVR	内径φ6	—	6.6	40	15	(20.3)	7	3.6	19.5	(25.5)
青	SPC-04SH-BLU	内径φ4	○	6.5	35	10	(20.3)	4.8	2.5	19.5	(25.5)
	SPC-04SH-VL-BLU	内径φ4	—	6.1	35	10	(20.3)	4.8	2.5	19.5	(25.5)
	SPC-06SH-BLU	内径φ6	○	7.0	40	15	(20.3)	7	3.6	19.5	(25.5)
	SPC-06SH-VL-BLU	内径φ6	—	6.6	40	15	(20.3)	7	3.6	19.5	(25.5)
黄	SPC-04SH-YEL	内径φ4	○	6.5	35	10	(20.3)	4.8	2.5	19.5	(25.5)
	SPC-04SH-VL-YEL	内径φ4	—	6.1	35	10	(20.3)	4.8	2.5	19.5	(25.5)
	SPC-06SH-YEL	内径φ6	○	7.0	40	15	(20.3)	7	3.6	19.5	(25.5)
	SPC-06SH-VL-YEL	内径φ6	—	6.6	40	15	(20.3)	7	3.6	19.5	(25.5)
ホワイト	SPC-04SH-PNK	内径φ4	○	6.5	35	10	(20.3)	4.8	2.5	19.5	(25.5)
	SPC-04SH-VL-PNK	内径φ4	—	6.1	35	10	(20.3)	4.8	2.5	19.5	(25.5)
	SPC-06SH-PNK	内径φ6	○	7.0	40	15	(20.3)	7	3.6	19.5	(25.5)
	SPC-06SH-VL-PNK	内径φ6	—	6.6	40	15	(20.3)	7	3.6	19.5	(25.5)
緑	SPC-04SH-GRN	内径φ4	○	6.5	35	10	(20.3)	4.8	2.5	19.5	(25.5)
	SPC-04SH-VL-GRN	内径φ4	—	6.1	35	10	(20.3)	4.8	2.5	19.5	(25.5)
	SPC-06SH-GRN	内径φ6	○	7.0	40	15	(20.3)	7	3.6	19.5	(25.5)
	SPC-06SH-VL-GRN	内径φ6	—	6.6	40	15	(20.3)	7	3.6	19.5	(25.5)

プラグ PM型 (めねじ取付用)

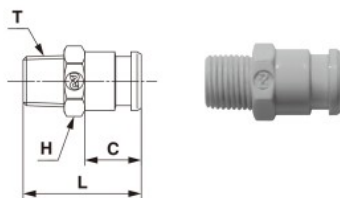

色	製品型式	相手側取付 ねじサイズ	内蔵 バルブ	質量 (g)	寸法 (mm)			
					L	C	H	T
アイボリー	SPC-10PM-IVR	Rc 1/8	○	2.0	23	11	六角12	R 1/8
	SPC-10PM-VL-IVR	Rc 1/8	—	1.5	23	11	六角12	R 1/8
	SPC-10PM-BLU	Rc 1/8	○	2.0	23	11	六角12	R 1/8
	SPC-10PM-VL-BLU	Rc 1/8	—	1.5	23	11	六角12	R 1/8
青	SPC-10PM-YEL	Rc 1/8	○	2.0	23	11	六角12	R 1/8
	SPC-10PM-VL-YEL	Rc 1/8	—	1.5	23	11	六角12	R 1/8
	SPC-10PM-PNK	Rc 1/8	○	2.0	23	11	六角12	R 1/8
	SPC-10PM-VL-PNK	Rc 1/8	—	1.5	23	11	六角12	R 1/8
ホワイト	SPC-10PM-GRN	Rc 1/8	○	2.0	23	11	六角12	R 1/8
	SPC-10PM-VL-GRN	Rc 1/8	—	1.5	23	11	六角12	R 1/8

ソケット SM型 (めねじ取付用)

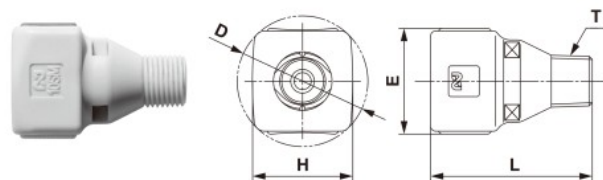

色	製品型式	相手側取付 ねじサイズ	内蔵 バルブ	質量 (g)	寸法 (mm)				
					L	E	T	H	φD
アイボリー	SPC-10SM-IVR	Rc 1/8	○	6.8	31.5	(20.3)	R 1/8	19.5	(25.5)
	SPC-10SM-VL-IVR	Rc 1/8	—	6.4	31.5	(20.3)	R 1/8	19.5	(25.5)
	SPC-10SM-BLU	Rc 1/8	○	6.8	31.5	(20.3)	R 1/8	19.5	(25.5)
	SPC-10SM-VL-BLU	Rc 1/8	—	6.4	31.5	(20.3)	R 1/8	19.5	(25.5)
青	SPC-10SM-YEL	Rc 1/8	○	6.8	31.5	(20.3)	R 1/8	19.5	(25.5)
	SPC-10SM-VL-YEL	Rc 1/8	—	6.4	31.5	(20.3)	R 1/8	19.5	(25.5)
	SPC-10SM-PNK	Rc 1/8	○	6.8	31.5	(20.3)	R 1/8	19.5	(25.5)
	SPC-10SM-VL-PNK	Rc 1/8	—	6.4	31.5	(20.3)	R 1/8	19.5	(25.5)
ホワイト	SPC-10SM-GRN	Rc 1/8	○	6.8	31.5	(20.3)	R 1/8	19.5	(25.5)
	SPC-10SM-VL-GRN	Rc 1/8	—	6.4	31.5	(20.3)	R 1/8	19.5	(25.5)