



製品型式・寸法表

プラグ LE型 (ホース取付用)

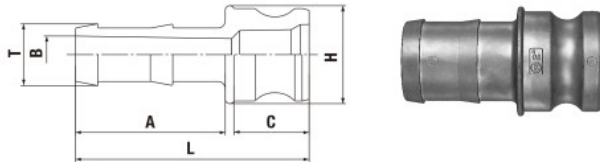

材質	製品型式	相手側 ホース サイズ	質量 (g)	寸法 (mm)					
				L	A	C	φH	φT	φB
アルミニウム合金	LE-6TPH	3/4	65	81	52	26	34	21.4	11
	LE-8TPH	1	100	95	58	34	40	27.4	17.5
	LE-10TPH	1 1/4	140	102	58	40	48	34.1	23.5
	LE-12TPH	1 1/2	190	107	61	42	58	40.5	29
	LE-16TPH	2	290	122	70	48	69	53.2	40
	LE-20TPH	2 1/2	390	134.5	80	50	81	66.7	50
	LE-24TPH	3	545	167	101	49.4	97	79	68
	LE-32TPH	4	850	176	106	51.8	133	105	93
	LE-6TPH	3/4	215	90.5	52.5	26	39	21.5	12.5
	LE-8TPH	1	305	107	60	34.5	41	27.5	20
銅合金	LE-10TPH	1 1/4	507	119	66	42	47	34.4	26.7
	LE-12TPH	1 1/2	600	114	61	42	60	41.2	33
	LE-16TPH	2	865	131	73	44	70.5	53.5	44.5
	LE-20TPH	2 1/2	1,180	149	84	48	91	67	57
	LE-24TPH	3	1,800	171	104	50	102	79	70
	LE-32TPH	4	3,500	176	109	52	129	105	93
ステンレス鋼	LE-6TPH	3/4	170	90	52	27	35	21	15
	LE-8TPH	1	265	107	60	35	42	27	20
	LE-10TPH	1 1/4	430	111	61	40	48	34	25.5
	LE-12TPH	1 1/2	530	114	61	40	60	40	33
	LE-16TPH	2	790	131	73	45	70	53	44
	LE-20TPH	2 1/2	1,195	137	80.5	42.7	83	67	56
	LE-24TPH	3	1,755	162	99.5	49.2	102	78	68
	LE-32TPH	4	2,595	174	109	50	130	105	94


プラグ LA型 (おねじ取付用)

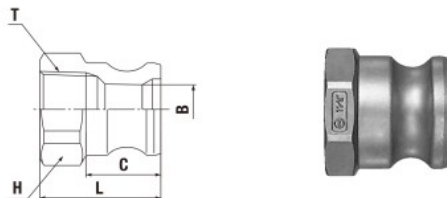

材質	製品型式	相手側 取付ねじ サイズ	質量 (g)	寸法 (mm)				
				L	C	H	φB	T
アルミニウム合金	LA-6TPF	R 3/4	45	42	26	六角36	17	Rc 3/4
	LA-8TPF	R 1	65	52	34	六角41	22.5	Rc 1
	LA-10TPF	R 1 1/4	110	59	40	六角50	27.5	Rc 1 1/4
	LA-12TPF	R 1 1/2	130	58	42	八角60	34.5	Rc 1 1/2
	LA-16TPF	R 2	170	63.5	48	八角70	44.5	Rc 2
	LA-20TPF	R 2 1/2	320	85	50	八角85	55.5	Rc 2 1/2
	LA-24TPF	R 3	370	79	52.5	十二角99	73.5	Rc 3
	LA-32TPF	R 4	640	82	54	十二角130	100	Rc 4
	LA-6TPF	R 3/4	145	42	27	八角34	20	Rc 3/4
	LA-8TPF	R 1	190	46	32	八角41	24	Rc 1
銅合金	LA-10TPF	R 1 1/4	390	59	40	六角50	28	Rc 1 1/4
	LA-12TPF	R 1 1/2	420	58	42	八角60	36	Rc 1 1/2
	LA-16TPF	R 2	560	63.5	48	八角70	45	Rc 2
	LA-20TPF	R 2 1/2	950	79	50	十二角84	56	Rc 2 1/2
	LA-24TPF	R 3	1,210	71	50	十二角101	70	Rc 3
	LA-32TPF	R 4	1,620	79	53	十二角127	101	Rc 4
ステンレス鋼	LA-6TPF	R 3/4	120	39	27	八角33	19	Rc 3/4
	LA-8TPF	R 1	170	47	33	八角41	24	Rc 1
	LA-10TPF	R 1 1/4	270	53.5	41	八角50	28	Rc 1 1/4
	LA-12TPF	R 1 1/2	375	55	40	八角58	35.5	Rc 1 1/2
	LA-16TPF	R 2	505	62	47	八角69	45	Rc 2
	LA-20TPF	R 2 1/2	825	77	49	十二角83	56	Rc 2 1/2
	LA-24TPF	R 3	875	72	51	十二角96	73	Rc 3
	LA-32TPF	R 4	1,470	79	53	十二角124	100	Rc 4

ソケット LC型 (ホース取付用)


アルミニウム合金と銅合金のLC-6TSH型はリングなし

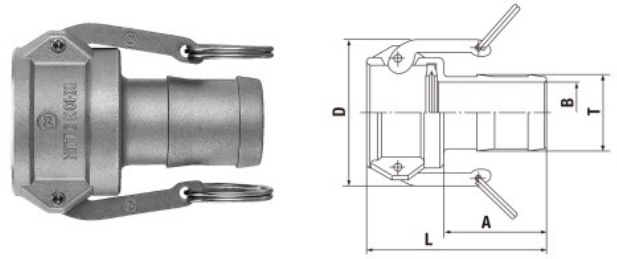

材質	製品型式	相手側 ホース サイズ	質量 (g)	寸法 (mm)				
				L	A	D	φT	φB
アルミニウム合金	LC-6TSH	3/4	140	85	52	(60.5)	21.4	(11)
	LC-8TSH	1	190	99	58	(61)	27.4	(17)
	LC-10TSH	1 1/4	320	104	58	(82)	34.1	(23)
	LC-12TSH	1 1/2	350	108.5	61	(90)	40.5	(29)
	LC-16TSH	2	430	122.5	70	(100)	53.2	(41.5)
	LC-20TSH	2 1/2	560	136.5	80	(112)	66.7	(54)
	LC-24TSH	3	915	175	100	(139)	79	68
	LC-32TSH	4	1,190	180	104	(165)	104	93
	LC-6TSH	3/4	276	86	53	(53)	21.8	13
	LC-8TSH	1	410	101	60	(62)	27.4	20
銅合金	LC-10TSH	1 1/4	700	104	58	(82)	34.1	25.5
	LC-12TSH	1 1/2	720	110	62	(91)	41	33
	LC-16TSH	2	870	121	70	(100)	53	44
	LC-20TSH	2 1/2	1,530	137	83	(113)	67	57
	LC-24TSH	3	1,795	160	105	(139)	79	68
	LC-32TSH	4	3,100	163	107	(168)	104	92
ステンレス鋼	LC-6TSH	3/4	230	86	52	(55)	21	15
	LC-8TSH	1	340	99	60	(63)	27	20
	LC-10TSH	1 1/4	615	107	61	(85)	34	25.5
	LC-12TSH	1 1/2	645	108	61	(91)	40	33
	LC-16TSH	2	1,000	129	73	(101)	53	44
	LC-20TSH	2 1/2	1,270	134	81	(113)	67	57
	LC-24TSH	3	2,065	158	100	(139)	79	67
	LC-32TSH	4	3,020	165	107	(167)	105	94

ソケット LD型 (おねじ取付用)

アルミニウム合金と銅合金のLD-6TSF型はリングなし

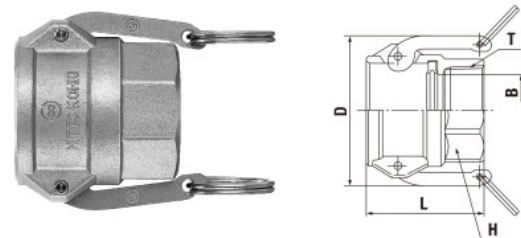

材質	製品型式	相手側 取付ねじ サイズ	質量 (g)	寸法 (mm)				
				L	D	H	φB	T
アルミニウム合金	LD-6TSF	R 3/4	130	53	(62.4)	六角36	21	Rc 3/4
	LD-8TSF	R 1	190	64.5	(61)	六角41	26	Rc 1
	LD-10TSF	R 1 1/4	330	72.5	(82)	六角50	34	Rc 1 1/4
	LD-12TSF	R 1 1/2	360	70.5	(90)	八角60	39	Rc 1 1/2
	LD-16TSF	R 2	420	79.5	(100)	八角70	49	Rc 2
	LD-20TSF	R 2 1/2	550	88.5	(112)	八角85	59	Rc 2 1/2
	LD-24TSF	R 3	800	89	(140)	十二角99	75	Rc 3
	LD-32TSF	R 4	1,140	93	(165)	十二角131	94	Rc 4
	LD-6TSF	R 3/4	310	53	(60.5)	六角36	21	Rc 3/4
	LD-8TSF	R 1	430	64.5	(61)	六角41	26	Rc 1
銅合金	LD-10TSF	R 1 1/4	730	72.5	(82)	六角50	34	Rc 1 1/4
	LD-12TSF	R 1 1/2	770	70.5	(90)	八角60	39	Rc 1 1/2
	LD-16TSF	R 2	990	79.5	(100)	八角70	49	Rc 2
	LD-20TSF	R 2 1/2	1,290	81.5	(113)	八角84	61	Rc 2 1/2
	LD-24TSF	R 3	1,560	87	(139)	八角96	77	Rc 3
	LD-32TSF	R 4	3,590	91	(165)	八角126	96	Rc 4
ステンレス鋼	LD-6TSF	R 3/4	225	52	(55)	八角32	19	Rc 3/4
	LD-8TSF	R 1	350	60	(63)	八角41	24	Rc 1
	LD-10TSF	R 1 1/4	600	68	(85)	八角50	30	Rc 1 1/4
	LD-12TSF	R 1 1/2	715	72	(87)	八角58	37.5	Rc 1 1/2
	LD-16TSF	R 2	940	78.5	(100)	八角69	50	Rc 2
	LD-20TSF	R 2 1/2	1,050	82	(113)	十二角83	61	Rc 2 1/2
	LD-24TSF	R 3	1,605	84	(140)	十二角97	77	Rc 3
	LD-32TSF	R 4	2,575	94	(167)	十二角125	97	Rc 4