



**RMSS**

超硬ラジカルミルリーマ (ストレートシャंक)

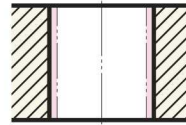

Code No.の説明(例)  
**RMSS - 12.0**  
 ● リーマの径寸法  
 ● ラジカルミルリーマシリーズ  
 RMSS: ストレートシャंक  
 通り穴

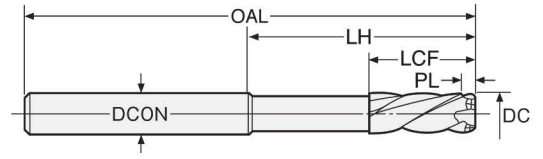

エンド刃付 (End刃付) ●  
 左ネジレ 30-35° (Left Flute 30-35°) ●  
 TiCN2 コート (TiCN2 Coating) ●  
 切削条件 P.133 (Cutting Conditions P.133) ●  
 ※アイコンの説明は P4をご覧ください。

製作区分の説明: ●=標準品 □=流通標準品 △=受注生産品

Code No.	製作区分	加工径 DC H7	全長 OAL	シャंक径 DCON	食付長 PL	刃長 LCF	シャंक下 LH
RMSS- 2.97	□	2.97	60	3	4.0	16	35
- 2.98	□	2.98					
- 2.99	□	2.99					
- 3.0	●	3.0					
- 3.01	□	3.01	60	3	4.0	16	35
- 3.02	□	3.02					
- 3.03	□	3.03					
- 3.04	□	3.04					
- 3.05	□	3.05	60	4	4.4	18	35
- 3.1	□	3.1					
- 3.2	□	3.2					
- 3.3	□	3.3					
- 3.4	□	3.4	60	4	4.8	18	35
- 3.5	●	3.5					
- 3.6	□	3.6					
- 3.7	□	3.7					
- 3.8	□	3.8	70	5	4.8	22	40
- 3.9	□	3.9					
- 3.97	□	3.97					
- 3.98	□	3.98					
- 3.99	□	3.99	70	5	4.8	22	40
- 4.0	●	4.0					
- 4.01	□	4.01					
- 4.02	□	4.02					
- 4.03	□	4.03	70	5	4.8	22	40
- 4.04	□	4.04					
- 4.05	□	4.05					
- 4.1	□	4.1					
- 4.2	□	4.2	85	6	5.1	25	50
- 4.3	□	4.3					
- 4.4	□	4.4					
- 4.5	●	4.5					
- 4.6	□	4.6	85	6	5.4	25	50
- 4.7	□	4.7					
- 4.8	□	4.8					
- 4.9	□	4.9					
- 4.97	□	4.97	85	6	5.4	25	50
- 4.98	□	4.98					
- 4.99	□	4.99					
- 5.0	●	5.0					
- 5.01	□	5.01	85	6	5.4	25	50
- 5.02	□	5.02					
- 5.03	□	5.03					
- 5.04	□	5.04					
- 5.05	□	5.05	85	6	5.4	25	50
- 5.1	□	5.1					
- 5.2	□	5.2					
- 5.3	□	5.3					
- 5.4	□	5.4	85	6	5.4	25	50
- 5.5	●	5.5					
- 5.6	□	5.6					
- 5.7	□	5.7					
- 5.8	□	5.8	85	6	5.4	25	50
- 5.9	□	5.9					
- 5.97	□	5.97					
- 5.98	□	5.98					
- 5.99	□	5.99	85	6	5.4	25	50
- 6.0	●	6.0					

Code No.	製作区分	加工径 DC H7	全長 OAL	シャंक径 DCON	食付長 PL	刃長 LCF	シャंक下 LH
RMSS- 6.01	□	6.01	85	6	5.4	25	50
- 6.02	□	6.02					
- 6.03	□	6.03					
- 6.04	□	6.04					
- 6.05	□	6.05	90	8	5.6	25	50
- 6.1	□	6.1					
- 6.2	□	6.2					
- 6.3	□	6.3					
- 6.4	□	6.4	90	8	6.0	25	50
- 6.5	●	6.5					
- 6.6	□	6.6					
- 6.7	□	6.7					
- 6.8	□	6.8	90	8	6.0	25	50
- 6.9	□	6.9					
- 6.97	□	6.97					
- 6.98	□	6.98					
- 6.99	□	6.99	90	8	6.0	25	50
- 7.0	●	7.0					
- 7.01	□	7.01					
- 7.02	□	7.02					
- 7.03	□	7.03	90	8	6.0	25	50
- 7.04	□	7.04					
- 7.05	□	7.05					
- 7.1	□	7.1					
- 7.2	□	7.2	100	8	6.4	25	60
- 7.3	□	7.3					
- 7.4	□	7.4					
- 7.5	●	7.5					
- 7.6	□	7.6	100	8	6.6	25	60
- 7.7	□	7.7					
- 7.8	□	7.8					
- 7.9	□	7.9					
- 7.97	□	7.97	100	8	6.6	25	60
- 7.98	□	7.98					
- 7.99	□	7.99					
- 8.0	●	8.0					
- 8.01	□	8.01	100	8	6.6	25	60
- 8.02	□	8.02					
- 8.03	□	8.03					
- 8.04	□	8.04					
- 8.05	□	8.05	105	10	6.8	25	60
- 8.1	□	8.1					
- 8.2	□	8.2					
- 8.3	□	8.3					
- 8.4	□	8.4	105	10	7.0	25	60
- 8.5	●	8.5					
- 8.6	□	8.6					
- 8.7	□	8.7					
- 8.8	□	8.8	105	10	7.0	25	60
- 8.9	□	8.9					
- 8.97	□	8.97					
- 8.98	□	8.98					
- 8.99	□	8.99	105	10	7.0	25	60
- 9.0	●	9.0					
- 9.01	□	9.01					
- 9.02	□	9.02					
- 9.03	□	9.03	105	10	7.0	25	60
- 9.04	□	9.04					