



RMSS-DLC 超硬ラジカルミルリーマ (DLCコーティング)

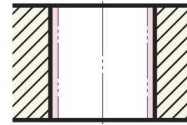

Code No.の説明(例)
RMSS - **10.0** - **DLC**
 ● DLCコーティング
 リーマの意
 ● リーマの径寸法
 ● ラジカルミルリーマシリーズ
 RMSS: ストレートシャンク通り穴用

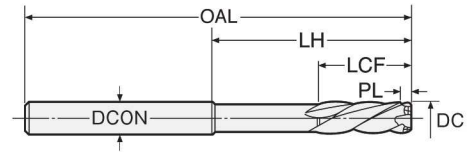

エンド刃付
左ネジレ 30-35°
DLCコート
切削条件 P.134
 ※アイコンの説明は P4をご覧ください。

製作区分の説明: ●=標準品 □=流通標準品 △=受注生産品

Code No.	製作区分	加工径 DC H7	全長 OAL	シャンク径 DCON	食付長 PL	刃長 LCF	シャンク下 LH
RMSS-2.97-DLC	□	2.97	60	3	4.0	16	35
-2.98-DLC	□	2.98					
-2.99-DLC	□	2.99					
-3.0 -DLC	□	3.0					
-3.01-DLC	□	3.01	60	3	4.0	16	35
-3.02-DLC	□	3.02					
-3.03-DLC	□	3.03					
-3.04-DLC	□	3.04					
-3.05-DLC	□	3.05	60	4	4.4	18	35
-3.1 -DLC	□	3.1					
-3.2 -DLC	□	3.2					
-3.3 -DLC	□	3.3					
-3.4 -DLC	□	3.4	60	4	4.4	18	35
-3.5 -DLC	□	3.5					
-3.6 -DLC	□	3.6					
-3.7 -DLC	□	3.7					
-3.8 -DLC	□	3.8	60	4	4.8	18	35
-3.9 -DLC	□	3.9					
-3.97-DLC	□	3.97					
-3.98-DLC	□	3.98					
-3.99-DLC	□	3.99	60	4	4.8	18	35
-4.0 -DLC	□	4.0					
-4.01-DLC	□	4.01					
-4.02-DLC	□	4.02					
-4.03-DLC	□	4.03	60	4	4.8	18	35
-4.04-DLC	□	4.04					
-4.05-DLC	□	4.05					
-4.1 -DLC	□	4.1					
-4.2 -DLC	□	4.2	70	5	4.8	22	40
-4.3 -DLC	□	4.3					
-4.4 -DLC	□	4.4					
-4.5 -DLC	□	4.5					
-4.6 -DLC	□	4.6	70	5	4.8	22	40
-4.7 -DLC	□	4.7					
-4.8 -DLC	□	4.8					
-4.9 -DLC	□	4.9					
-4.97-DLC	□	4.97	70	5	4.8	22	40
-4.98-DLC	□	4.98					
-4.99-DLC	□	4.99					
-5.0 -DLC	□	5.0					
-5.01-DLC	□	5.01	70	5	4.8	22	40
-5.02-DLC	□	5.02					
-5.03-DLC	□	5.03					
5.04-DLC	□	5.04					
-5.05-DLC	□	5.05	70	5	4.8	22	40
-5.1 -DLC	□	5.1					
-5.2 -DLC	□	5.2					
-5.3 -DLC	□	5.3					
-5.4 -DLC	□	5.4	85	6	5.1	25	50
-5.5 -DLC	□	5.5					
-5.6 -DLC	□	5.6					
-5.7 -DLC	□	5.7					
-5.8 -DLC	□	5.8	85	6	5.1	25	50
-5.9 -DLC	□	5.9					
-5.97-DLC	□	5.97					
-5.98-DLC	□	5.98					
-5.99-DLC	□	5.99	85	6	5.4	25	50
-6.0 -DLC	□	6.0					

Code No.	製作区分	加工径 DC H7	全長 OAL	シャンク径 DCON	食付長 PL	刃長 LCF	シャンク下 LH
RMSS-6.01-DLC	□	6.01	85	6	5.4	25	50
-6.02-DLC	□	6.02					
-6.03-DLC	□	6.03					
-6.04-DLC	□	6.04					
-6.05-DLC	□	6.05	90	8	5.6	25	50
-6.1 -DLC	□	6.1					
-6.2 -DLC	□	6.2					
-6.3 -DLC	□	6.3					
-6.4 -DLC	□	6.4	90	8	6.0	25	50
-6.5 -DLC	□	6.5					
-6.6 -DLC	□	6.6					
-6.7 -DLC	□	6.7					
-6.8 -DLC	□	6.8	90	8	6.0	25	50
-6.9 -DLC	□	6.9					
-6.97-DLC	□	6.97					
-6.98-DLC	□	6.98					
-6.99-DLC	□	6.99	90	8	6.0	25	50
-7.0 -DLC	□	7.0					
-7.01-DLC	□	7.01					
-7.02-DLC	□	7.02					
-7.03-DLC	□	7.03	90	8	6.0	25	50
-7.04-DLC	□	7.04					
-7.05-DLC	□	7.05					
-7.1 -DLC	□	7.1					
-7.2 -DLC	□	7.2	100	8	6.4	25	60
-7.3 -DLC	□	7.3					
-7.4 -DLC	□	7.4					
-7.5 -DLC	□	7.5					
-7.6 -DLC	□	7.6	100	8	6.6	25	60
-7.7 -DLC	□	7.7					
-7.8 -DLC	□	7.8					
-7.9 -DLC	□	7.9					
-7.97-DLC	□	7.97	100	8	6.6	25	60
-7.98-DLC	□	7.98					
-7.99-DLC	□	7.99					
-8.0 -DLC	□	8.0					
-8.01-DLC	□	8.01	100	8	6.6	25	60
-8.02-DLC	□	8.02					
-8.03-DLC	□	8.03					
-8.04-DLC	□	8.04					
-8.05-DLC	□	8.05	105	10	6.8	25	60
-8.1 -DLC	□	8.1					
-8.2 -DLC	□	8.2					
-8.3 -DLC	□	8.3					
-8.4 -DLC	□	8.4	105	10	7.0	25	60
-8.5 -DLC	□	8.5					
-8.6 -DLC	□	8.6					
-8.7 -DLC	□	8.7					
-8.8 -DLC	□	8.8	105	10	7.0	25	60
-8.9 -DLC	□	8.9					
-8.97-DLC	□	8.97					
-8.98-DLC	□	8.98					
-8.99-DLC	□	8.99	105	10	7.0	25	60
-9.0 -DLC	□	9.0					
-9.01-DLC	□	9.01					
-9.02-DLC	□	9.02					
-9.03-DLC	□	9.03	105	10	7.0	25	60
-9.04-DLC	□	9.04					

