



ラジアル深溝玉軸受 メトリックサイズ:基本形(ステンレス鋼)

R-シリーズ
L-シリーズ
内径:1mm~5mm

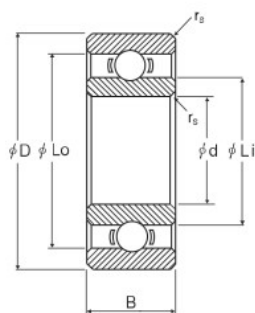

開放形
Radial Open Ball Bearings

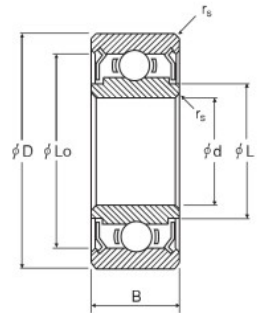

シールド付
Radial Shielded Ball Bearings

(単位:mm)

呼び記号	内径 d	外径 D	幅 B	面取り r _s min.	肩径		玉		基本定格荷重(N)		参考 JIS呼び
					外輪 Lo	内輪 Li	寸法	個数 (個)	動荷重 Cr	静荷重 Cor	
DDL-310	1	3	1	0.05	2.41	1.60	0.5000	7	80	23	681
DDR-410	1	4	1.6	0.1	3.16	2.05	0.7938	6	158	44	691
DDR-410XZZ	1	4	2	0.1	3.49	2.26	0.6350	7	125	38	—
DDR-412	1.2	4	1.8	0.1	3.16	2.05	0.7938	6	158	44	—
DDL-415	1.5	4	1.2	0.05	3.25	2.26	0.6350	7	125	38	68/1.5
DDL-415ZZ	1.5	4	2	0.05	3.49	2.26	0.6350	7	125	38	—
DDR-515	1.5	5	2	0.15	3.73	2.60	0.7938	7	184	57	69/1.5
DDR-515ZZ	1.5	5	2.6	0.15	4.03	2.60	0.7938	7	184	57	—
DDR-615	1.5	6	2.5	0.15	4.73	2.90	1.1906	6	324	97	60/1.5
DDR-615ZZ	1.5	6	3	0.15	5.06	2.90	1.1906	6	324	97	—
DDL-420	2	4	1.2	0.05	3.44	2.57	0.6000	8	125	41	672
DDL-520	2	5	1.5	0.08	4.00	2.90	0.7938	7	187	59	682
DDL-520ZZ	2	5	2.3	0.08	4.28	2.90	0.7938	7	187	59	—
DDL-520W52	2	5	2.5	0.08	4.00	2.90	0.7938	7	187	59	—
DDL-520ZZW52	2	5	2.5	0.08	4.28	2.90	0.7938	7	187	59	—
DDR-620	2	6	2.3	0.15	4.78	3.16	1.0000	7	279	89	692
DDR-620ZZY32	2	6	2.3	0.15	5.23	3.16	1.0000	7	279	89	692ZZ
DDR-620W52	2	6	2.5	0.15	4.93	3.10	1.1906	6	330	99	—
DDR-620ZZY52	2	6	2.5	0.15	5.23	3.10	1.1906	6	330	99	—
DDR-620ZZ	2	6	3	0.15	5.23	3.10	1.1906	6	330	99	—
DDR-720	2	7	2.8	0.15	5.52	3.80	1.1906	7	380	126	602
DDR-720ZZ	2	7	3.5	0.15	5.93	3.80	1.1906	7	380	126	—
DDR-720ZZY03	2	7	3	0.15	5.93	3.80	1.1906	7	380	126	—
DDL-625	2.5	6	1.8	0.08	4.93	3.80	0.7938	8	206	73	68/2.5
DDL-625ZZ	2.5	6	2.6	0.08	5.23	3.80	0.7938	8	206	73	—
DDR-725	2.5	7	2.5	0.15	5.52	3.80	1.1906	7	380	126	69/2.5
DDR-725ZZ	2.5	7	3.5	0.15	5.93	3.80	1.1906	7	380	126	—
DDR-825	2.5	8	2.8	0.15	6.53	4.10	1.5875	6	553	176	60/2.5
DDR-825ZZ	2.5	8	4	0.15	7.19	4.10	1.5875	6	553	176	—
DDL-630	3	6	2	0.08	4.93	3.80	0.7938	8	206	73	673
DDL-630ZZ	3	6	2.5	0.08	5.23	3.80	0.7938	8	206	73	—