


5. 継手の形状・寸法

(3) 同心レジューサ, 偏心レジューサ

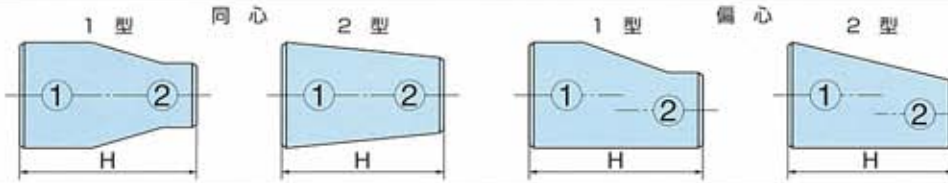

単位:mm

径の呼び ①×②		端面から端面 までの距離 H
A	B	
20 × 15	¾ × ½	38.1
25 × 20	1 × ¾	50.8
25 × 15	1 × ½	
32 × 25	1¼ × 1	
32 × 20	1¼ × ¾	50.8
32 × 15	1¼ × ½	63.5
40 × 32	1½ × 1¼	
40 × 25	1½ × 1	
40 × 20	1½ × ¾	
40 × 15	1½ × ½	
50 × 40	2 × 1½	
50 × 32	2 × 1¼	
50 × 25	2 × 1	
50 × 20	2 × ¾	
65 × 50	2½ × 2	88.9
65 × 40	2½ × 1½	
65 × 32	2½ × 1¼	
65 × 25	2½ × 1	88.9
80 × 65	3 × 2½	
80 × 50	3 × 2	
80 × 40	3 × 1½	
80 × 32	3 × 1¼	101.6
90 × 80	3½ × 3	
90 × 65	3½ × 2½	
90 × 50	3½ × 2	
90 × 40	3½ × 1½	
90 × 32	3½ × 1¼	

単位:mm

径の呼び ①×②		端面から端面 までの距離 H
A	B	
100 × 90	4 × 3½	101.6
100 × 80	4 × 3	
100 × 65	4 × 2½	
100 × 50	4 × 2	
100 × 40	4 × 1½	
125 × 100	5 × 4	127.0
125 × 90	5 × 3½	
125 × 80	5 × 3	
125 × 65	5 × 2½	
125 × 50	5 × 2	
150 × 125	6 × 5	139.7
150 × 100	6 × 4	
150 × 90	6 × 3½	
150 × 80	6 × 3	
150 × 65	6 × 2½	
200 × 150	8 × 6	152.4
200 × 125	8 × 5	
200 × 100	8 × 4	
200 × 90	8 × 3½	177.8
250 × 200	10 × 8	
250 × 150	10 × 6	
250 × 125	10 × 5	
250 × 100	10 × 4	
300 × 250	12 × 10	203.2
300 × 200	12 × 8	
300 × 150	12 × 6	
300 × 125	12 × 5	