


レジャーサ

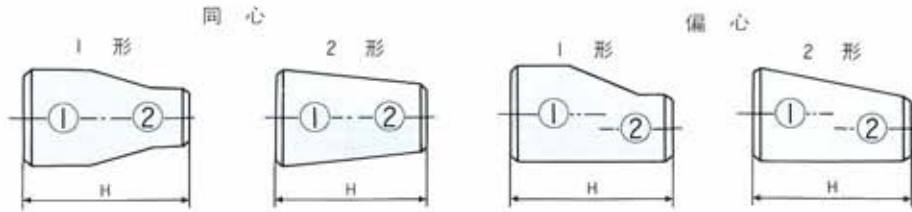

単位：mm

径の呼び ① × ②		端面から 端面まで の距離H
A	B	
20 × 15	3/4 × 1/2	38.1
25 × 20	1 × 3/4	50.8
25 × 15	1 × 1/2	
32 × 25	1 1/4 × 1	50.8
32 × 20	1 1/4 × 3/4	
32 × 15	1 1/4 × 1/2	63.5
40 × 32	1 1/2 × 1 1/4	
40 × 25	1 1/2 × 1	
40 × 20	1 1/2 × 3/4	
40 × 15	1 1/2 × 1/2	76.2
50 × 40	2 × 1 1/2	
50 × 32	2 × 1 1/4	
50 × 25	2 × 1	
50 × 20	2 × 3/4	88.9
65 × 50	2 1/2 × 2	
65 × 40	2 1/2 × 1 1/2	
65 × 32	2 1/2 × 1 1/4	
65 × 25	2 1/2 × 1	88.9
80 × 65	3 × 2 1/2	
80 × 50	3 × 2	
80 × 40	3 × 1 1/2	
80 × 32	3 × 1 1/4	101.6
90 × 80	3 1/2 × 3	
90 × 65	3 1/2 × 2 1/2	
90 × 50	3 1/2 × 2	
90 × 40	3 1/2 × 1 1/2	101.6
90 × 32	3 1/2 × 1 1/4	
100 × 90	4 × 3 1/2	
100 × 80	4 × 3	
100 × 65	4 × 2 1/2	101.6
100 × 50	4 × 2	
100 × 40	4 × 1 1/2	
125 × 100	5 × 4	
125 × 90	5 × 3 1/2	
125 × 80	5 × 3	
125 × 65	5 × 2 1/2	
125 × 50	5 × 2	139.7
150 × 125	6 × 5	
150 × 100	6 × 4	
150 × 90	6 × 3 1/2	
150 × 80	6 × 3	609.6
150 × 65	6 × 2 1/2	

径の呼び ① × ②		端面から 端面まで の距離H
A	B	
200 × 150	8 × 6	152.4
200 × 125	8 × 5	
200 × 100	8 × 4	
200 × 90	8 × 3 1/2	
250 × 200	10 × 8	177.8
250 × 150	10 × 6	
250 × 125	10 × 5	
250 × 100	10 × 4	
300 × 250	12 × 10	203.2
300 × 200	12 × 8	
300 × 150	12 × 6	
300 × 125	12 × 5	
350 × 300	14 × 12	330.2
350 × 250	14 × 10	
350 × 200	14 × 8	
350 × 150	14 × 6	
400 × 350	16 × 14	355.6
400 × 300	16 × 12	
400 × 250	16 × 10	
400 × 200	16 × 8	
450 × 400	18 × 16	381.0
450 × 350	18 × 14	
450 × 300	18 × 12	
450 × 250	18 × 10	
500 × 450	20 × 18	508.0
500 × 400	20 × 16	
500 × 350	20 × 14	
500 × 300	20 × 12	
550 × 500	22 × 20	508.0
550 × 450	22 × 18	
550 × 400	22 × 16	
550 × 350	22 × 14	
600 × 550	24 × 22	508.0
600 × 500	24 × 20	
600 × 450	24 × 18	
600 × 400	24 × 16	
650 × 600	26 × 24	609.6
650 × 550	26 × 22	
650 × 500	26 × 20	
650 × 450	26 × 18	
700 × 650	28 × 26	609.6
700 × 600	28 × 24	

径の呼び ① × ②		端面から 端面まで の距離H
A	B	
700 × 550	28 × 22	609.6
700 × 500	28 × 20	
750 × 700	30 × 28	609.6
750 × 650	30 × 26	
750 × 600	30 × 24	
750 × 550	30 × 22	
800 × 750	32 × 30	609.6
800 × 700	32 × 28	
800 × 650	32 × 26	
800 × 600	32 × 24	
850 × 800	34 × 32	609.6
850 × 750	34 × 30	
850 × 700	34 × 28	
850 × 650	34 × 26	
900 × 850	36 × 34	609.6
900 × 800	36 × 32	
900 × 750	36 × 30	
900 × 700	36 × 28	
950 × 900	38 × 36	609.6
950 × 850	38 × 34	
950 × 800	38 × 32	
950 × 750	38 × 30	
1000 × 950	40 × 38	609.6
1000 × 900	40 × 36	
1000 × 850	40 × 34	
1000 × 800	40 × 32	
1050 × 1000	42 × 40	609.6
1050 × 950	42 × 38	
1050 × 900	42 × 36	
1050 × 850	42 × 34	
1100 × 1050	44 × 42	609.6
1100 × 1000	44 × 40	
1100 × 950	44 × 38	
1100 × 900	44 × 36	
1150 × 1100	46 × 44	711.2
1150 × 1050	46 × 42	
1150 × 1000	46 × 40	
1150 × 950	46 × 38	
1200 × 1150	48 × 46	711.2
1200 × 1100	48 × 44	
1200 × 1050	48 × 42	
1200 × 1000	48 × 40	

(注) レジャーサ2形はJIS B2311、JIS B2313のみに適用いたします。