


HDC・A

高精度コレットホルダ

High-Precision Collet Holder

- ドリル加工、リーマ加工、仕上エンドミル加工に最適。
Suitable for drilling, reaming and finish endmilling.

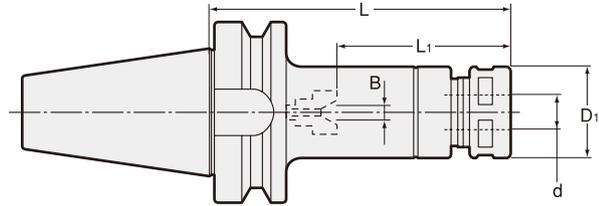

商品コード Code	型式 Model	d	L	B	L1	D1	キャップ Nut	kg	—	コレット Collet	スパナ Spanner
2540 10107045	BT30 -HDC07A -45	0.5 ~ 7.0	45	0 ~ 4	22 ~ 43	23	HDP-07A	0.5	28,600	FDC-07	S-0
2540 10107060	-60	0.5 ~ 7.0	60	0 ~ 4	22 ~ 45	23	HDP-07A	0.5	29,700		
2540 10107075	-75	0.5 ~ 7.0	75	0 ~ 4	22 ~ 45	23	HDP-07A	0.5	30,800		
2540 10107090	-90	0.5 ~ 7.0	90	0 ~ 4	22 ~ 45	23	HDP-07A	0.6	31,350		
2540 10107105	-105	0.5 ~ 7.0	105	0 ~ 4	22 ~ 45	23	HDP-07A	0.6	31,900		
2540 10107120	-120	0.5 ~ 7.0	120	0 ~ 4	22 ~ 45	23	HDP-07A	0.7	33,000		
2540 10107135	-135	0.5 ~ 7.0	135	0 ~ 4	22 ~ 45	23	HDP-07A	0.7	34,100		
2540 10109045	-HDC09A -45	2.5 ~ 9.0	45	0 ~ 4	27 ~ 44	26	HDP-09	0.5	28,600	FDC-09	S-1L
2540 10109060	-60	2.5 ~ 9.0	60	0 ~ 4	27 ~ 54	26	HDP-09	0.5	29,150		
2540 10109075	-75	2.5 ~ 9.0	75	0 ~ 4	27 ~ 57	26	HDP-09	0.6	29,700		
2540 10109090	-90	2.5 ~ 9.0	90	0 ~ 4	27 ~ 57	26	HDP-09	0.6	30,800		
2540 10109105	-105	2.5 ~ 9.0	105	0 ~ 4	27 ~ 57	26	HDP-09	0.7	31,350		
2540 10109120	-120	2.5 ~ 9.0	120	0 ~ 4	27 ~ 57	26	HDP-09	0.7	32,450		
2540 10109135	-135	2.5 ~ 9.0	135	0 ~ 4	27 ~ 57	26	HDP-09	0.8	33,550		
2540 10112045	-HDC12A -45	2.5 ~ 12.0	45	0 ~ 5	33 ~ 51	32	HDP-12	0.5	30,800	FDC-12	S-3L
2540 10112060	-60	2.5 ~ 12.0	60	0 ~ 5	33 ~ 54	32	HDP-12	0.6	31,350		
2540 10112075	-75	2.5 ~ 12.0	75	0 ~ 5	33 ~ 69	32	HDP-12	0.6	31,900		
2540 10112090	-90	2.5 ~ 12.0	90	0 ~ 5	33 ~ 69	32	HDP-12	0.7	32,450		
2540 10112105	-105	2.5 ~ 12.0	105	0 ~ 5	33 ~ 69	32	HDP-12	0.8	33,000		
2540 10112120	-120	2.5 ~ 12.0	120	0 ~ 5	33 ~ 69	32	HDP-12	0.9	34,100		
2540 10112135	-135	2.5 ~ 12.0	135	0 ~ 5	33 ~ 69	32	HDP-12	1.0	35,200		
2540 10116045	-HDC16A -45	3.5 ~ 16.0	45	0 ~ 6	38 ~ 51	36	HDP-16	0.4	32,120	FDC-16	S-4L
2540 10116060	-60	3.5 ~ 16.0	60	0 ~ 6	38 ~ 54	36	HDP-16	0.6	32,670		
2540 10116075	-75	3.5 ~ 16.0	75	0 ~ 6	38 ~ 69	36	HDP-16	0.6	32,670		
2540 10116090	-90	3.5 ~ 16.0	90	0 ~ 6	38 ~ 82	36	HDP-16	0.7	33,220		
2540 10116105	-105	3.5 ~ 16.0	105	0 ~ 6	38 ~ 82	36	HDP-16	0.9	34,320		
2540 10116120	-120	3.5 ~ 16.0	120	0 ~ 6	38 ~ 82	36	HDP-16	1.0	34,870		
2540 10116135	-135	3.5 ~ 16.0	135	0 ~ 6	38 ~ 82	36	HDP-16	1.1	35,970		
2540 10122045	-HDC22A -45	3.5 ~ 22.0	45	—	52	46	HDP-22	0.4	34,760	FDC-22	S-5L
2540 10122060	-60	3.5 ~ 22.0	60	0 ~ 8	47 ~ 49	46	HDP-22	0.6	35,420		
2540 10122075	-75	3.5 ~ 22.0	75	0 ~ 8	47 ~ 64	46	HDP-22	0.7	36,190		
2540 10122090	-90	3.5 ~ 22.0	90	0 ~ 8	47 ~ 79	46	HDP-22	0.9	36,960		
2540 10122105	-105	3.5 ~ 22.0	105	0 ~ 8	47 ~ 94	46	HDP-22	1.0	37,620		
2540 10122120	-120	3.5 ~ 22.0	120	0 ~ 8	47 ~ 103	46	HDP-22	1.2	38,280		
2540 10122135	-135	3.5 ~ 22.0	135	0 ~ 8	47 ~ 103	46	HDP-22	1.3	38,940		
2540 10307060	BT40 -HDC07A -60	0.5 ~ 7.0	60	0 ~ 4	22 ~ 45	23	HDP-07A	1.1	34,400	FDC-07	S-0
2540 10307075	-75	0.5 ~ 7.0	75	0 ~ 4	22 ~ 45	23	HDP-07A	1.1	34,650		
2540 10307090	-90	0.5 ~ 7.0	90	0 ~ 4	22 ~ 45	23	HDP-07A	1.1	35,200		
2540 10307105	-105	0.5 ~ 7.0	105	0 ~ 4	22 ~ 45	23	HDP-07A	1.2	36,300		
2540 10307120	-120	0.5 ~ 7.0	120	0 ~ 4	22 ~ 45	23	HDP-07A	1.3	36,600		
2540 10309060	-HDC09A -60	2.5 ~ 9.0	60	0 ~ 4	27 ~ 57	26	HDP-09	1.1	34,400		
2540 10309090	-90	2.5 ~ 9.0	90	0 ~ 4	27 ~ 57	26	HDP-09	1.2	34,650	FDC-09	S-1L
2540 10309105	-105	2.5 ~ 9.0	105	0 ~ 4	27 ~ 57	26	HDP-09	1.2	35,200		
2540 10309120	-120	2.5 ~ 9.0	120	0 ~ 4	27 ~ 57	26	HDP-09	1.3	35,750		
2540 10309135	-135	2.5 ~ 9.0	135	0 ~ 4	27 ~ 57	26	HDP-09	1.3	36,300		
2540 10309165	-165	2.5 ~ 9.0	165	0 ~ 4	27 ~ 57	26	HDP-09	1.4	37,400		
2540 10312060	-HDC12A -60	2.5 ~ 12.0	60	0 ~ 5	33 ~ 61	32	HDP-12	1.2	35,700		
2540 10312090	-90	2.5 ~ 12.0	90	0 ~ 5	33 ~ 69	32	HDP-12	1.3	36,300	FDC-12	S-3L
2540 10312105	-105	2.5 ~ 12.0	105	0 ~ 5	33 ~ 69	32	HDP-12	1.3	36,850		
2540 10312120	-120	2.5 ~ 12.0	120	0 ~ 5	33 ~ 69	32	HDP-12	1.4	37,400		
2540 10312135	-135	2.5 ~ 12.0	135	0 ~ 5	33 ~ 69	32	HDP-12	1.5	37,950		
2540 10312165	-165	2.5 ~ 12.0	165	0 ~ 5	33 ~ 69	32	HDP-12	1.6	39,050		
2540 10312195	-195	2.5 ~ 12.0	195	0 ~ 5	33 ~ 69	32	HDP-12	1.8	40,150		