






K893 形
(スラスト保持器付き円筒ころ)

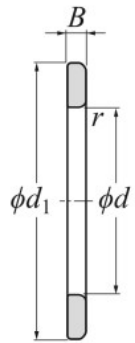

WS 形軌道輪
(内輪)

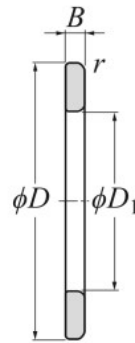

GS 形軌道輪
(外輪)

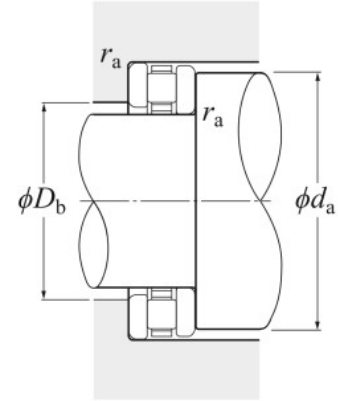

呼 び 番 号				参 考 寸 法		取 付 関 係 寸 法			質 量			
軸受	スラスト 保持器付き 円筒ころ	内輪	外輪	mm		mm			kg (参考)			
				E_b	E_a	d_a	D_b	r_{as}	811	K811	WS811	GS811
						最小	最大	最大	K812	WS812	GS812	
	K893	WS893	GS893									
81113T2	K81113T2	WS81113	GS81113	68.8	85.2	85	70	1	0.332	0.090	0.125	0.117
81213T2	K81213T2	WS81213	GS81213	69.9	93.3	93	71	1	0.772	0.215	0.285	0.272
89313	K89313	WS89313	GS89313	73.9	110.3	110	74	1	1.41	0.260	0.583	0.566
81114T2	K81114T2	WS81114	GS81114	73.7	90.1	90	74	1	0.355	0.097	0.134	0.124
81214T2	K81214T2	WS81214	GS81214	75	98.4	98	76	1	0.815	0.225	0.302	0.288
89314	K89314	WS89314	GS89314	79.8	120.2	120	80	1	1.91	0.340	0.793	0.772
81115T2	K81115T2	WS81115	GS81115	78.7	95.1	95	80	1	0.414	0.115	0.155	0.144
81215T2	K81215T2	WS81215	GS81215	80.1	103.7	103	81	1	0.864	0.240	0.319	0.304
89315	K89315	WS89315	GS89315	84.7	129.2	129	85	1.5	2.39	0.470	0.971	0.948
81116T2	K81116T2	WS81116	GS81116	83.7	100.1	100	85	1	0.435	0.119	0.164	0.152
81216T2	K81216T2	WS81216	GS81216	84.8	108.4	106	86	1	0.948	0.250	0.358	0.341
89316	K89316	WS89316	GS89316	89.8	134.2	134	90	1.5	2.50	0.490	1.02	0.992
81117T2	K81117T2	WS81117	GS81117	88.7	105.3	105	89	1	0.458	0.125	0.173	0.161
81217	K81217	WS81217	GS81217	92.2	116.9	116	92	1	1.25	0.300	0.492	0.462
89317	K89317	WS89317	GS89317	95.8	144.2	144	96	1.5	3.09	0.590	1.27	1.23
81118T2	K81118T2	WS81118	GS81118	94.7	114.3	114	95	1	0.660	0.170	0.252	0.238
81218J	K81218J	WS81218	GS81218	97.9	126.7	126	97	1	1.82	0.540	0.655	0.620
89318	K89318	WS89318	GS89318	100.8	149.2	149	101	1.5	3.23	0.620	1.33	1.28
81120T2	K81120T2	WS81120	GS81120	105.1	128.7	128	106	1	0.993	0.300	0.355	0.338
81220	K81220	WS81220	GS81220	109.2	140	139	109	1	2.35	0.620	0.886	0.843
89320	K89320	WS89320	GS89320	110.6	163	163	110	1.5	4.13	0.810	1.69	1.64
81122T2	K81122T2	WS81122	GS81122	115	138.8	138	116	1	1.08	0.325	0.385	0.366
81222	K81222	WS81222	GS81222	119.2	150	149	119	1	2.55	0.685	0.957	0.910
89322	K89322	WS89322	GS89322	122.5	183	183	122	2	5.96	1.15	2.44	2.37
81124T2	K81124T2	WS81124	GS81124	125	148.8	148	126	1	1.15	0.340	0.415	0.395
81224	K81224	WS81224	GS81224	129.2	160	159	129	1	2.82	0.730	1.07	1.02
81126	K81126	WS81126	GS81126	137.7	162.4	162	137	1	1.72	0.415	0.666	0.637
81226	K81226	WS81226	GS81226	140.1	179	178	140	1.5	4.06	1.14	1.45	1.48