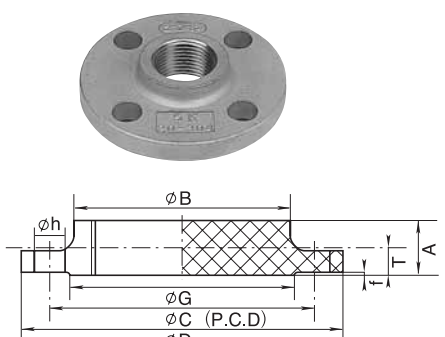
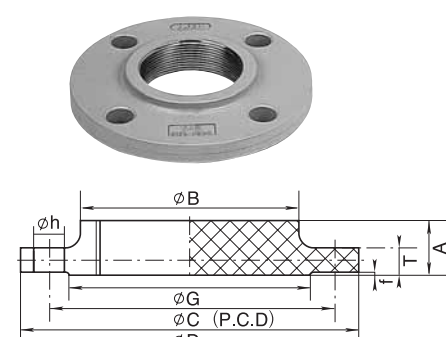
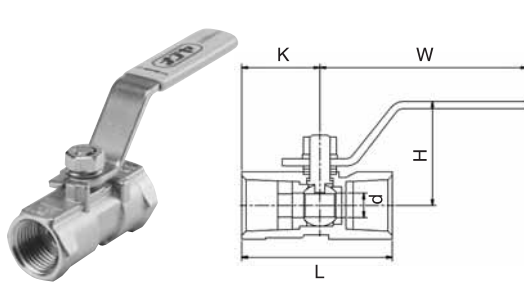
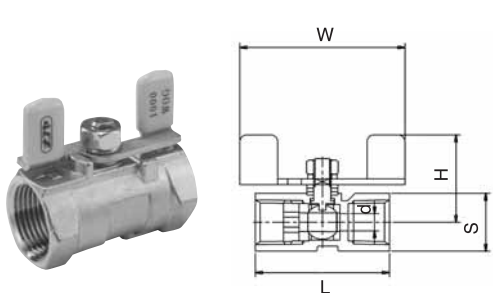


品名	5Kねじ込みフランジ (ロストワックス品)										10Kねじ込みフランジ (ロストワックス品)									
記号	5KFL										10KFL									
形状																				
	呼び径 (B)	D	T	G	f	ボルト穴			ボルトの呼び	A	B	D	T	G	f	ボルト穴			ボルトの呼び	A
					C	数	h								C	数	h			
1/2	80	9	44	1	60	4	12	M10	16	30	95	12	51	1	70	4	15	M12	16	30
3/4	85	10	49	1	65	4	12	M10	18	36	100	14	56	1	75	4	15	M12	18	36
1	95	10	59	1	75	4	12	M10	18	45	125	14	67	1	90	4	19	M16	18	45
1 1/4	115	12	70	2	90	4	15	M12	21	54	135	16	76	2	100	4	19	M16	21	54
1 1/2	120	12	75	2	95	4	15	M12	21	60	140	16	81	2	105	4	19	M16	21	60
2	130	14	85	2	105	4	15	M12	22	76	155	16	96	2	120	4	19	M16	22	76
2 1/2	155	14	110	2	130	4	15	M12	26	92	175	18	116	2	140	4	19	M16	26	94
3	180	14	121	2	145	4	19	M16	30	105	185	18	126	2	150	8	19	M16	30	108
4	200	16	141	2	165	8	19	M16	35	135	210	18	151	2	175	8	19	M16	35	136

単位：mm

品名	ボールバルブ (レバーハンドル)						ボールバルブ (蝶ハンドル)				
記号	RV						RVB				
形状											
	呼び径 (B)	D	L	H	W	S	K	D	L	H	W
1/4	5	39	34	66.5	17	19.5	5	39	25.5	48	17
3/8	7	44	38	75.5	21	23.1	7	44	27	52.2	21
1/2	9.2	57	43	93	25	29.25	9.2	57	32.3	54	25
3/4	12.5	60	45	93	32	28.55	12.5	60	34.3	54	32
1	16	72	51	107	38	35	16	71	49	70	38
1 1/4	20	78	55	107	48	38.2					
1 1/2	25	83	57	136.5	53	41.3					
2	32	100	63	136.5	66	48.8					

単位：mm