





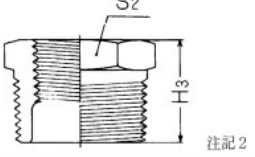
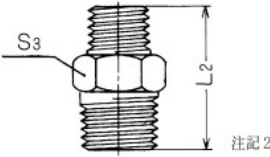
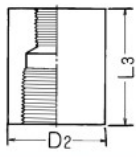
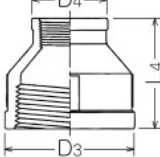
# 呼び圧力 10K

SCS13(SUS304)

SCS14(SUS316)

検査圧力(漏れ)0.6MPa(空圧)

単位:mm

品名	六角ブッシュ		6RN 径違いニップル		RS 径違いソケット		RS 径違いソケット		
形									
状									
呼び径(B)	H3	S2	L2	S3	L3	D2	L4	D3	D4
1/4 x 1/8	17	14	28	16	25	19	—	—	—
3/8 x 1/8	18	17	29	19	26	22	—	—	—
3/8 x 1/4	18	17	33	19	26	22	—	—	—
1/2 x 1/8	24	24	—	—	—	—	34	28	16.5
1/2 x 1/4	24	24	36	24	—	—	34	28	20
1/2 x 3/8	24	24	37	24	—	—	34	28	23.5
3/4 x 1/8	26	29	—	—	—	—	—	—	—
3/4 x 1/4	26	29	—	—	—	—	36	34	20
3/4 x 3/8	26	29	39	29	—	—	36	34	23.5
3/4 x 1/2	26	29	42	29	—	—	36	34	28
1 x 1/4	29	36	—	—	—	—	—	—	—
1 x 3/8	29	36	—	—	—	—	43	41	23.5
1 x 1/2	29	36	45	36	—	—	43	41	28
1 x 3/4	29	36	47	36	—	—	43	41	34
1 1/4 x 3/8	32	46	—	—	—	—	—	—	—
1 1/4 x 1/2	32	46	—	—	—	—	51	51	28
1 1/4 x 3/4	32	46	52	46	—	—	51	51	34
1 1/4 x 1	32	46	54	46	—	—	51	51	41
1 1/2 x 1/2	34	54	—	—	—	—	—	—	—
1 1/2 x 3/4	34	54	—	—	—	—	55	57.5	34
1 1/2 x 1	34	54	57	54	—	—	55	57.5	41
1 1/2 x 1 1/4	34	54	59	54	—	—	55	57.5	51
2 x 1/2	40	63	—	—	—	—	—	—	—
2 x 3/4	40	63	—	—	—	—	—	—	—
2 x 1	40	63	—	—	—	—	60	70	41
2 x 1 1/4	40	63	63	63	—	—	60	70	51
2 x 1 1/2	40	63	64	63	—	—	60	70	57.5
2 1/2 x 1	43	80	—	—	—	—	—	—	—
2 1/2 x 1 1/4	43	80	—	—	—	—	—	—	—
2 1/2 x 1 1/2	43	80	—	—	—	—	70	88.5	57.5
2 1/2 x 2	43	80	—	—	—	—	70	88.5	70
3 x 1	47	95	—	—	—	—	—	—	—
3 x 1 1/4	47	95	—	—	—	—	—	—	—
3 x 1 1/2	47	95	—	—	—	—	—	—	—
3 x 2	47	95	—	—	—	—	75	102	70
3 x 2 1/2	47	95	—	—	—	—	75	102	88.5
4 x 1 1/2	52.5	120	—	—	—	—	—	—	—
4 x 2	52.5	120	—	—	—	—	—	—	—
4 x 2 1/2	52.5	120	—	—	—	—	—	—	—
4 x 3	52.5	120	—	—	—	—	—	—	—

1. 内は引出品です。  
 2. S2, S3は六角部の二面幅です。