

③ サニタリー継手

ISOヘルールユニオン継手

ISO Ferrule Union Fittings

3Kクランプ/3Kクランプ(脱落防止仕様)/2Kクランプ/2Dクランプ


Clamp Type 3K/Clamp Type 3K(Dropout prevention)/Clamp Type 2K/Clamp Type 2D

3K クランプ

Clamp Type 3K

Type CP3K

※1.0^S~1.5^S 共用

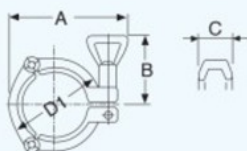


Nom.size	D1	A	B	C	Mass kg
※1.5 ^S	65.5	87.3	57	18	0.28
2.0 ^S	79	102	57	18	0.33
2.5 ^S	92.5	115.8	57	18	0.4
3.0 ^S	106	130.5	57	18	0.44
3.5 ^S	121	146	57	18	0.52
4.0 ^S	134	159.5	57	18	0.57
4.5 ^S	145	171	57	18	0.61
5.5 ^S	172	197.5	62	26	1
6.5 ^S	200	225.5	62	26	1.2
200A(8.5 ^S)	251	278	64	26	1.6

3K クランプ (脱落防止仕様)

Clamp Type 3K(Dropout prevention)

Type CP3KII

※1.0^S~1.5^S 共用

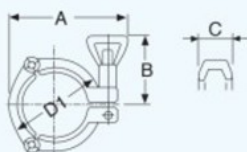


Nom.size	D1	A	B	C	Mass kg
※1.5 ^S	65.5	87.3	60	18	-
2.0 ^S	79	102	60	18	-
2.5 ^S	92.5	115.8	60	18	-
3.0 ^S	106	130.5	60	18	-
3.5 ^S	121	146	60	18	-
4.0 ^S	134	159.5	60	18	-
4.5 ^S	145	171	60	18	-

2K クランプ

Clamp Type 2K

Type CP2K

※8A~15A 共用 ※1.0^S~1.5^S 共用

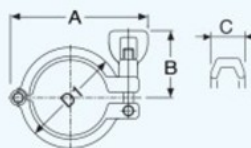


Nom.size	D1	A	B	C	Mass kg
※1.5 ^S	64	92	51.5	16	0.23
2.0 ^S	77.5	105.8	51.5	16	0.22
2.5 ^S	91	119.5	51.5	16	0.25
3.0 ^S	105	134	51.5	16	0.29
3.5 ^S	120.5	149.5	52.5	17	0.383
4.0 ^S	133.5	163	52.5	17	0.417
※15A	46	72.5	50	16	0.16

2D クランプ

Clamp Type 2D

Type CP2D

※8A~15A 共用 ※1.0^S~1.5^S 共用

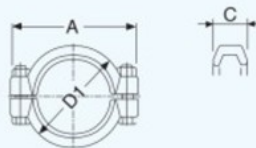

Nom.size	D1	A	C	Mass kg
※1.5 ^S	63	86	16	0.22
2.0 ^S	76.5	100	16	0.25
2.5 ^S	90	115	16	0.29
3.0 ^S	103.5	130	16	0.33
3.5 ^S	119	144	17	0.4
4.0 ^S	132	158	17	0.46
4.5 ^S	143	172	17	0.49
5.5 ^S	174	208	25	1.2
6.5 ^S	202	238	25	1.3
200A(8.5 ^S)	253	288	25	1.6
※15A	46	64	16	0.13

写真は3DCGです。Photo is 3DCG.