


ISOヘルールユニオン継手

ISO Ferrule Union Fittings

ヘルール管用ネジアダプタ
Taper Pipe Threads/Ferrule Adapter


ヘルール管用ネジアダプタ Type THAD-C

Taper Pipe Threads/Ferrule Adapter

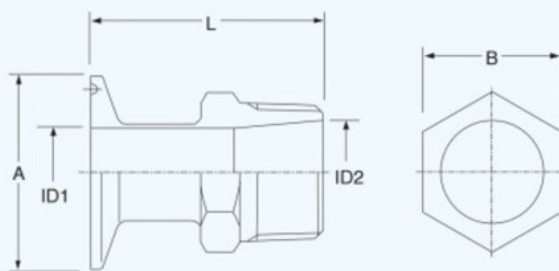

Nom.size	ID1	ID2	A	B	L	Mass kg
1.0 ^S ×R 3/4	23	21	50.5	29	60	0.139
1.0 ^S ×R1	23	26	50.5	36	60	0.195
1.25 ^S ×R 3/4	29.4	21	50.5	29	60	—
1.25 ^S ×R1	29.4	26	50.5	36	60	0.174
1.25 ^S ×R1 1/4	29.4	35.7	50.5	46	60	0.235
1.5 ^S ×R 3/4	35.7	21	50.5	29	60	—
1.5 ^S ×R1	35.7	26	50.5	36	64.5	0.169
1.5 ^S ×R1 1/4	35.7	35.7	50.5	46	65	0.187
1.5 ^S ×R1 1/2	35.7	40	50.5	51	65	0.277
2.0 ^S ×R1	47.8	26	64	36	64.5	—
2.0 ^S ×R1 1/4	47.8	35.7	64	46	65	0.219
2.0 ^S ×R1 1/2	47.8	40	64	51	65	0.253
2.0 ^S ×R2	47.8	51.5	64	61	70	0.401
2.5 ^S ×R2	59.5	51.5	77.5	65	75	0.441
2.5 ^S ×R2 1/2	59.5	67.3	77.5	76	75	0.620
3.0 ^S ×R2 1/2	72.3	67.3	91	76	75	0.483
* 8A×R 1/4	10.5	8.8	34	14	45	0.053
* 10A×R 3/8	14	12.3	34	19	45	0.059
* 15A×R 1/2	17.5	16.7	34	22	50	0.076

*SUS316Lのみ
Only SUS316L

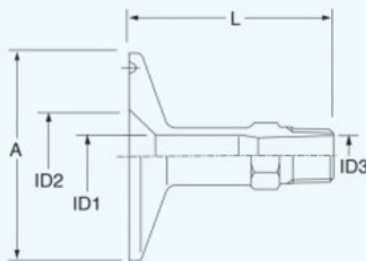

Nom.size	ID1	ID2	ID3	A	B	L	Mass kg
1.0 ^S ×R 1/4	10.5	23	8.8	50.5	14	49.5	0.104
1.0 ^S ×R 3/8	14	23	12.3	50.5	19	49.5	0.112
1.0 ^S ×R 1/2	17.5	23	16.7	50.5	22	54.5	0.122
1.5 ^S ×R 1/4	10.5	35.7	8.8	50.5	14	49.5	0.091
1.5 ^S ×R 3/8	14	35.7	12.3	50.5	19	49.5	0.098
1.5 ^S ×R 1/2	17.5	35.7	16.7	50.5	22	54.5	0.110

*すべて SUS316L
All SUS316L