



# A-XPF

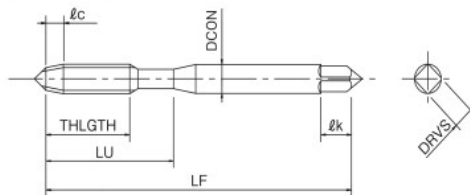

Type 1



Type 2

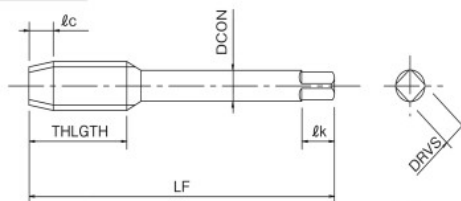

単位:mm Unit:mm

材質 Tool Material	表面処理 Surface Treatment
CPM	VI

## ねじの種類 : M

ツールNo. EDP No.	呼び Thread Size	精度表記 Grade	精度 TAP Limit	食付 $\ell_c$	全長 LF	ねじ部の長さ THLGTH	首下の長さ LU	シャンク径 DCON	形状 Type	突出しセンタ External Center	在庫 Stock	標準価格 (Yen)	
8327814	M 1 × 0.25	STD	RH4	2P	30	5.5	-	3	1	-	B	●	5,440
8327870		STD	RH4	1P								●	6,140
8327816	M 1.2 × 0.25	STD	RH4	2P	32	5.5	-	3	1	-	B	●	5,090
8327871		STD	RH4	1P								●	5,750
8327818	M 1.4 × 0.3	STD	RH4	2P	34	7	-	3	1	-	B	●	4,820
8327872		STD	RH4	1P								●	5,440
8327820	M 1.6 × 0.35	STD	RH4	2P	36	8	-	3	1	-	B	●	4,780
8327873		STD	RH4	1P								●	5,390
8327822	M 1.6 × 0.2	STD	RH4	2P	36	8	-	3	1	-	B	●	5,480
8327874		STD	RH4	1P								●	6,180
8327824	M 1.7 × 0.35	STD	RH4	2P	36	8	-	3	1	-	B	●	4,610
8327875		STD	RH4	1P								●	6,180
8327828	M 2 × 0.4	STD	RH4	2P	40	8	-	3	1	-	B	●	4,240
8327876		STD	RH4	1P								●	5,210
8327832	M 2.3 × 0.4	STD	RH4	2P	42	9.5	-	3	1	-	B	●	4,200
8327877		STD	RH4	1P								●	4,800
8327834	M 2.5 × 0.45	STD	RH4	2P	44	9.5	-	3	1	-	B	●	4,010
8327878		STD	RH4	1P								●	4,730
8327836	M 2.6 × 0.45	STD	RH4	2P	44	9.5	-	3	1	-	B	●	4,010
8327879		STD	RH4	1P								●	4,530
8327837	M 3 × 0.5	STD	RH5	4P	46	9	18	4	1	Yes	B	●	3,790
8327838		STD	RH5	2P						-		●	3,790
8327880		STD	RH5	1P						-		●	4,530
8327841	M 4 × 0.7	STD	RH6	4P	52	10	20	5	1	Yes	B	●	3,840
8327842		STD	RH6	2P						-		●	3,840
8327881		STD	RH6	1P						-		●	4,280
8327845	M 5 × 0.8	STD	RH6	4P	60	11	22	5.5	1	Yes	B	●	4,100
8327846		STD	RH6	2P						-		●	4,100
8327882		STD	RH6	1P						-		●	4,340
8327849	M 6 × 1	STD	RH7	4P	62	10	24	6	1	Yes	B	●	4,340
8327850		STD	RH7	2P						-		●	4,340
8327883		STD	RH7	1P						-		●	4,340
8327851	M 8 × 1.25	STD	RH7	4P	70	12	-	6.2	2	-	B	●	5,810
8327852		STD	RH7	2P								●	5,810
8327853	M 8 × 1	STD	RH7	4P	70	12	-	6.2	2	-	B	●	6,570
8327854		STD	RH7	2P								●	6,570
8327855	M 10 × 1.5	STD	RH7	4P	75	15	-	7	2	-	B	●	7,020
8327856		STD	RH7	2P								●	7,020
8327857	M 10 × 1.25	STD	RH7	4P	75	15	-	7	2	-	B	●	7,020
8327858		STD	RH7	2P								●	7,020
8327859	M 10 × 1	STD	RH7	2P	75	15	-	7	2	-	B	●	7,870

● = 標準在庫品 ● = Standard stock item