




G-LIST No | FL1065

丸駒カッタ ストレートシャンクタイプ

Radius Cutter with Straight Shank

PRC SS

切削条件 Cutting Conditions | P978~979

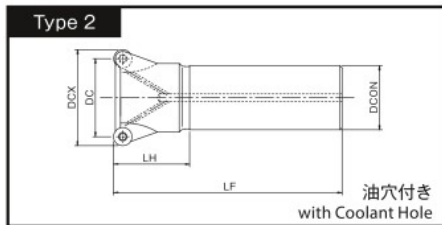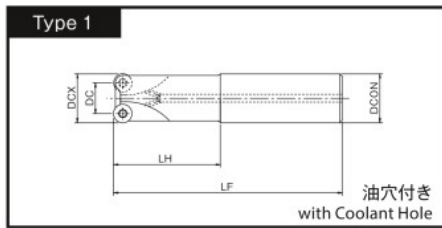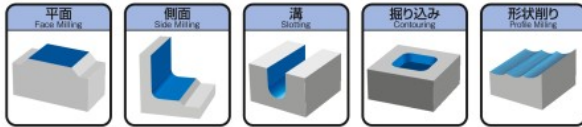

(単位:mm) (Unit:mm)

ツールNo. EDP No.	呼び Designation	カッタ 外径 DCX	外径 DC	刃数 ZEPF	シャンク径 DCON	全長 LF	首下長 LH	重量 (kg)	適用インサート Applicable Inserts	形状 タイプ Type	標準価格 (Yen)
7800300	PRC10R020SS20-2S	20	10	2	20	130	50	0.27	①	1	33,600
7800303	PRC10R020SS20-2L	20	10	2	20	180	80	0.38		1	35,300
7800301	PRC10R025SS25-3S	25	15	3	25	140	60	0.44		1	42,700
7800304	PRC10R025SS25-3L	25	15	3	25	200	120	0.62		1	45,000
7800302	PRC10R032SS32-4S	32	22	4	32	150	70	0.80		1	49,500
7800305	PRC10R032SS32-4L	32	22	4	32	200	120	1.05		1	52,500
7800322	PRC12R024SS25-2S	24	12	2	25	140	60	0.44	②	1	47,000
7800323	PRC12R024SS25-2L	24	12	2	25	180	100	0.56		1	51,400
7800318	PRC12R030SS32-2S	30	18	2	32	150	70	0.75		1	73,000
7800319	PRC12R030SS32-2L	30	18	2	32	200	120	0.96		1	78,700
7800306	PRC12R032SS32-2S	32	20	2	32	150	70	0.79		1	49,300
7800309	PRC12R032SS32-2L	32	20	2	32	200	120	1.04		1	53,400
7800320	PRC12R032SS32-3S	32	20	3	32	150	70	0.78		1	75,900
7800321	PRC12R032SS32-3L	32	20	3	32	200	120	1.02		1	81,000
7800307	PRC12R040SS32-3S	40	28	3	32	150	50	0.88		2	61,500
7800310	PRC12R040SS32-3L	40	28	3	32	250	50	1.49		2	65,500
7800308	PRC12R050SS42-4S	50	38	4	42	150	50	1.52	③	2	70,900
7800311	PRC12R050SS42-4L	50	38	4	42	250	50	2.58		2	75,400
7800324	PRC16R032SS32-2S	32	16	2	32	150	70	0.78		1	48,400
7800325	PRC16R032SS32-2L	32	16	2	32	200	120	1.05		1	52,700
7800312	PRC16R040SS32-2S	40	24	2	32	150	50	0.85		2	54,300
7800315	PRC16R040SS32-2L	40	24	2	32	250	50	1.46		2	64,500
7800313	PRC16R050SS42-3S	50	34	3	42	150	50	0.49		2	60,000
7800316	PRC16R050SS42-3L	50	34	3	42	250	50	2.55		2	77,600
7800314	PRC16R063SS42-4S	63	47	4	42	150	50	1.63		2	67,900
7800317	PRC16R063SS42-4L	63	47	4	42	250	50	2.69	2	84,300	

適用インサートと部品はp.900をご覧ください。
See p.900 for available inserts and parts.

在庫区分は全てC(標準在庫品)となります。 Stock are categorized as C (Standard stock item).