


ステンレス・軟鋼用スタブ形

STUB FOR STAINLESS STEELS

EX-SUS-GDS

切削条件 Cutting Conditions | P.420

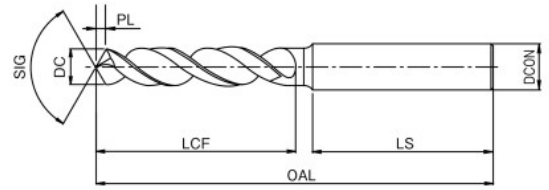

注1) 100分の5とびを除く、100分の1とびのドリル直径許容差は0 ~ -0.009mmです。
All drill diameters have limits from 0 ~ -0.009mm, except those with intervals of 0.05mm.

HSSE **TiN** h8 h7 約30° 35~40°

注1) ABOUT 30° 1 ≤ DC

単位:mm Unit:mm

ツールNo. EDP No.	直径 DC	溝長 LCF	全長 OAL	シャン径 DCON	シャン径 LS	先端 PL	先端角 SIG	在庫 Stock	重量 (g)	標準価格 (Yen)
61505	0.5	3			26	0.1	150°	D	4	1,950
8595051	0.51				26	0.1			4	2,140
8595052	0.52				26	0.1			4	2,140
8595053	0.53				26	0.1			3	2,140
8595054	0.54	3.5			26	0.1	150°	D	3	2,140
8595055	0.55				26	0.1			4	2,140
8595056	0.56				26	0.1			3	2,140
8595057	0.57				26	0.1			4	2,140
8595058	0.58				26	0.1			3	2,140
8595059	0.59				26	0.1			3	2,140
61506	0.6				26	0.1			4	1,790
8595061	0.61				26.5	0.1			4	1,970
8595062	0.62	26.5	0.1	4	1,970					
8595063	0.63	26.5	0.1	4	1,970					
8595064	0.64	4			26.5	0.1	150°	D	3	1,970
8595065	0.65				26.5	0.1			4	1,970
8595066	0.66				26.5	0.1			4	1,970
8595067	0.67				26.5	0.1			4	1,970
8595068	0.68				26.5	0.1			4	1,970
8595069	0.69				26.5	0.1			3	1,970
61507	0.7				26.5	0.1			4	1,620
8595071	0.71				26.5	0.1			3	1,780
8595072	0.72	26.5	0.1	4	1,780					
8595073	0.73	4.5			26.5	0.1	150°	D	3	1,780
8595074	0.74				26.5	0.1			3	1,780
8595075	0.75				26.5	0.1			4	1,780
8595076	0.76				26.5	0.1			4	1,780
8595077	0.77				26.5	0.1			4	1,780
8595078	0.78				26.5	0.1			4	1,780
8595079	0.79				26.5	0.1			4	1,780
61508	0.8				26.5	0.1			4	1,550
8595081	0.81	26.5	0.1	4	1,700					
8595082	0.82	26.5	0.1	4	1,700					
8595083	0.83	26.5	0.1	4	1,700					
8595084	0.84	26.5	0.1	3	1,700					
8595085	0.85	26.5	0.1	4	1,700					
8595086	0.86	5			26.7	0.1	150°	D	3	1,700
8595087	0.87				26.7	0.1			4	1,700
8595088	0.88				26.7	0.1			3	1,700
8595089	0.89				26.7	0.1			4	1,700
61509	0.9				26.7	0.1			4	1,500
8595091	0.91				26.7	0.1			4	1,640
8595092	0.92				26.7	0.1			4	1,640
8595093	0.93				26.7	0.1			4	1,640
8595094	0.94	26.7	0.1	4	1,640					
8595095	0.95	26.7	0.1	4	1,640					
8595096	0.96	6			26.7	0.1	150°	D	3	1,640
8595097	0.97				26.7	0.1			4	1,640
8595098	0.98				26.7	0.1			4	1,640
8595099	0.99				26.7	0.1			4	1,640
61510	1	26.8	0.2	4	914					
8595101	1.01	26.8	0.2	4	1,310					

ツールNo. EDP No.	直径 DC	溝長 LCF	全長 OAL	シャン径 DCON	シャン径 LS	先端 PL	先端角 SIG	在庫 Stock	重量 (g)	標準価格 (Yen)	
8595102	1.02	6	38		26.8	0.2	140°	D	4	1,310	
8595103	1.03				26.8	0.2			4	1,310	
8595104	1.04				26.8	0.2			4	1,310	
8595105	1.05				26.9	0.2			B	4	1,130
8595106	1.06	7	39		26.9	0.2	140°	D	4	1,310	
8595107	1.07				26.9	0.2			4	1,310	
8595108	1.08				26.9	0.2			4	1,310	
8595109	1.09				26.9	0.2			4	1,310	
61511	1.1				27	0.2			A	4	1,070
8595111	1.11				27	0.2			4	1,310	
8595112	1.12				27	0.2			D	4	1,310
8595113	1.13				27	0.2			4	1,310	
8595114	1.14	27	0.2	4	1,310						
8595115	1.15	27	0.2	B	4	1,130					
8595116	1.16	8	40		27.1	0.2	140°	D	3	1,310	
8595117	1.17				27.1	0.2			4	1,310	
8595118	1.18				27.1	0.2			4	1,310	
8595119	1.19				27.1	0.2			4	1,310	
61512	1.2				27.1	0.2			A	4	1,070
8595121	1.21				27.2	0.2			4	1,310	
8595122	1.22				27.2	0.2			D	4	1,310
8595123	1.23				27.2	0.2			4	1,310	
8595124	1.24	27.2	0.2	4	1,310						
8595125	1.25	27.2	0.2	B	4	1,130					
8595126	1.26	9	41		27.3	0.2	140°	D	4	1,310	
8595127	1.27				27.3	0.2			4	1,310	
8595128	1.28				27.3	0.2			4	1,310	
8595129	1.29				27.3	0.2			4	1,310	
61513	1.3				27.3	0.2			A	4	1,070
8595131	1.31				27.3	0.2			D	3	1,310
8595132	1.32				27.4	0.2			4	1,310	
8595133	1.33				27.4	0.2			4	1,310	
8595134	1.34	27.4	0.2	3	1,310						
8595135	1.35	27.4	0.2	B	4	1,130					
8595136	1.36	10	42		27.4	0.2	140°	D	4	1,310	
8595137	1.37				27.5	0.2			4	1,310	
8595138	1.38				27.5	0.3			4	1,310	
8595139	1.39				27.5	0.3			3	1,310	
61514	1.4				27.5	0.3			A	4	1,070
8595141	1.41				27.5	0.3			D	4	1,310
8595142	1.42				27.6	0.3			4	1,310	
8595143	1.43				27.6	0.3			4	1,310	
8595144	1.44	27.6	0.3	4	1,310						
8595145	1.45	27.6	0.3	B	4	1,130					
8595146	1.46	6			27.6	0.3	140°	D	4	1,310	
8595147	1.47				27.6	0.3			4	1,310	
8595148	1.48				27.7	0.3			4	1,310	
8595149	1.49				27.7	0.3			4	1,310	
61515	1.5	27.7	0.3	A	4	905					
8595151	1.51	27.7	0.3	D	4	1,310					
8595152	1.52	27.7	0.3	4	1,310						
8595153	1.53	27.8	0.3	4	1,310						

次ページへ
直径 DC 1.54 ~ 2.57 NEXT

A, B, C, D=標準在庫品 A, B, C, D=Standard stock item. □=特定代理店在庫品 □=Stocked by specific distributors. Contact us for price & availability.