




# LEVER COUPLINGS アルミニウム

## OZ-A メスネジ型アダプター

### ADAPTER FEMALE THREAD

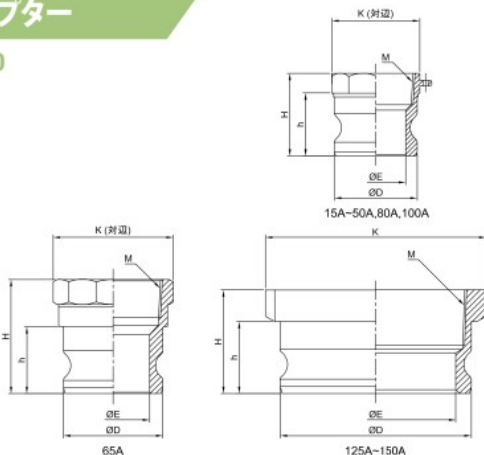


呼び径	mm	15	20	25	32	40	50	65	80	100	125	150
	inch	1/2	3/4	1	1 1/4	1 1/2	2	2 1/2	3	4	5	6
M(Rc)		1/2B	3/4B	1B	1 1/4B	1 1/2B	2B	2 1/2B	3B	4B	5B	6B
ΦD		32	32	37	45	53	63	76	92	120	146	176
ΦE		14	19	22	28	36	43	56	72	97	122	148
K		34	34	41	48	56	67	85	98	128	168	192
h		27	27	33	40	43	48	51	51	53	55	58
H		42	42	48	56	59	63	87	70	78	79	84

単位:mm

## OZ-F オスネジ型アダプター

### ADAPTER MALE THREAD

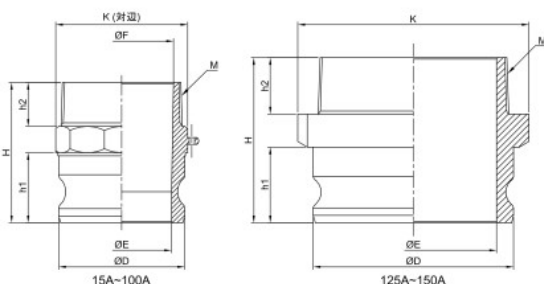


呼び径	mm	15	20	25	32	40	50	65	80	100	125	150
	inch	1/2	3/4	1	1 1/4	1 1/2	2	2 1/2	3	4	5	6
M(Rc)		1/2B	3/4B	1B	1 1/4B	1 1/2B	2B	2 1/2B	3B	4B	5B	6B
ΦD		32	32	37	45	53	63	76	92	120	146	176
ΦE		14	21	23	28	36	46	56	72	97	121	148
ΦF		12	19	21	26	33	43	59	75	94	↓	↓
K		34	34	41	48	56	65	85	96	127	168	192
h1		27	27	33	39	42	46	49	51	53	55	58
h2		16	16	20	18	19	23	31	32	36	41	43
H		62	62	71	79	81	88	99	102	114	120	127

単位:mm

## OZ-E ホースシャンクアダプター

### ADAPTER HOSE SHANK

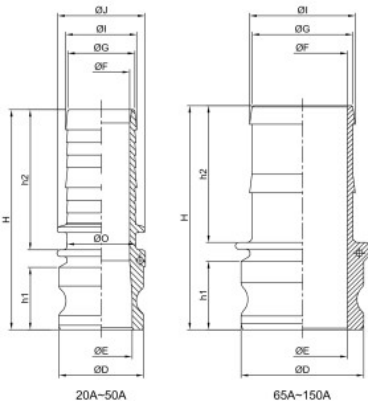


呼び径	mm	20	25	32	40	50	65	80	100	125	150
	inch	3/4	1	1 1/4	1 1/2	2	2 1/2	3	4	5	6
ΦD		32	37	45	53	63	76	92	120	146	176
ΦE		21	20	25	36	46	55	67	92	121	148
ΦF		12	↓	22	31	42	↓	↓	↓	117	140
ΦG		19	25	31	37	50	63	75	101	127	152
ΦI		21	27	34	40	53	65	79	105	130	155
ΦJ		26	32	38	50	65	-	-	-	-	-
ΦO		19	25	32	39	50	-	-	-	-	-
h1		27	34	40	40	47	50	51	53	54	58
h2		62	69	74	90	105	95	102	110	127	143
H		100	113	125	142	164	159	167	178	200	221

単位:mm

## OZ-EP プラスチックホース用アダプター

### ADAPTER HOSE SHANK

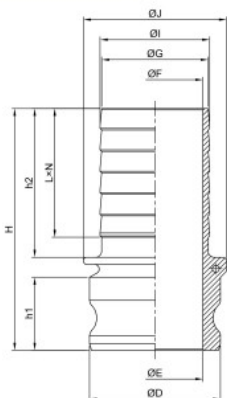

呼び径	mm	40	50	65	80	100	125	150
	inch	1 1/2	2	2 1/2	3	4	5	6
ΦD		53	63	76	92	120	146	176
ΦE		36	45	54	67	92	121	148
ΦF		31	43	↓	↓	↓	117	140
ΦG		36	49	62	75	100	125	149
ΦI		38	51	64	77	102	127	152
ΦJ		56	66	80	100	133	158	184
h1		41	48	50	51	53	54	58
h2		72	83	90	104	113	127	143
L		15	15	15	15	15	20	20
N		4	5	4	6	6	6	6
H		123	143	154	169	181	200	221

単位:mm