




LEVER COUPLINGS ブロンズ

OZ-A メスネジ型アダプター

ADAPTER FEMALE THREAD

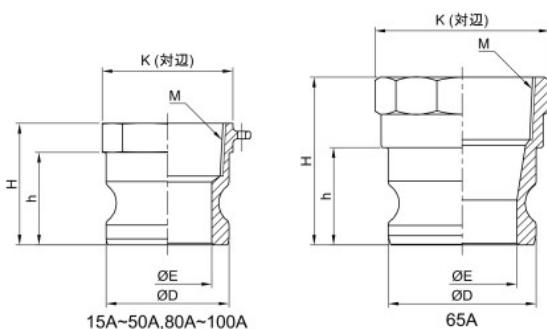


呼び径	mm	15	20	25	32	40	50	65	80	100
	inch	1/2	3/4	1	1 1/4	1 1/2	2	2 1/2	3	4
M(Rc)		1/2B	3/4B	1B	1 1/4B	1 1/2B	2B	2 1/2B	3B	4B
ΦD		32	32	37	45	53	63	76	92	120
ΦE		16	21	24	28	36	46	56	73	99
K		33	33	42	48	56	67	84	96	127
h		26	26	34	40	41	48	50	51	54
H		40	40	48	54	56	62	86	70	78

単位:mm

OZ-F オスネジ型アダプター

ADAPTER MALE THREAD

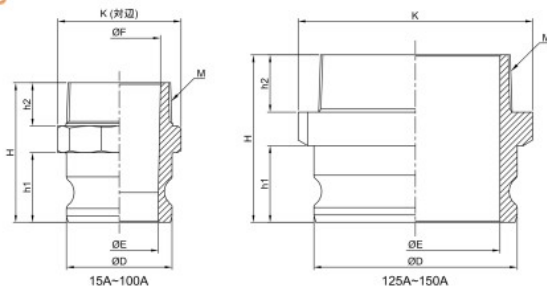


呼び径	mm	15	20	25	32	40	50	65	80	100	125	150
	inch	1/2	3/4	1	1 1/4	1 1/2	2	2 1/2	3	4	5	6
M(R)		1/2B	3/4B	1B	1 1/4B	1 1/2B	2B	2 1/2B	3B	4B	5B	6B
ΦD		32	32	37	45	53	63	76	92	120	146	176
ΦE		14	21	24	28	36	46	56	73	99	122	147
ΦF		↓	↓	↓	↓	↓	↓	59	↓	98	↓	↓
K		33	33	41	48	56	67	84	96	127	168	203
h1		26	26	34	40	41	48	50	51	53	55	60
h2		20	20	23	24	23	25	31	32	36	40	43
H		60	60	71	78	79	88	100	102	114	119	129

単位:mm

OZ-E ホースシャンクアダプター

ADAPTER HOSE SHANK

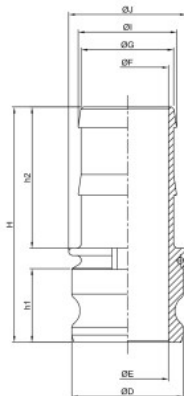


呼び径	mm	20	25	32	40	50	65	80	100	125
	inch	3/4	1	1 1/4	1 1/2	2	2 1/2	3	4	5
ΦD		32	37	45	53	63	76	92	120	146
ΦE		21	24	28	36	46	56	68	99	117
ΦF		14	20	25	31	43	↓	↓	91	↓
ΦG		19	25	32	39	51	63	75	101	127
ΦI		21	27	33	41	53	67	79	103	130
ΦJ		33	40	48	56	66	80	102	133	158
h1		25	34	40	40	47	50	51	55	54
h2		60	66	70	72	85	96	104	111	127
H		97	100	121	124	145	160	170	182	200

単位:mm

OZ-DP ダストプラグ

ADAPTER DUST PLUG

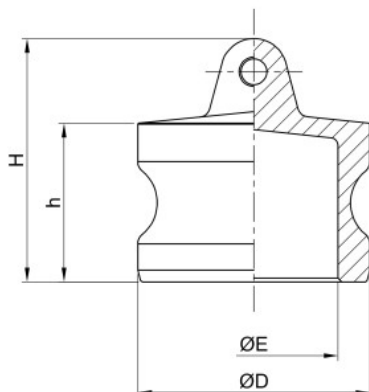

呼び径	mm	20	25	32	40	50	65	80	100	150
	inch	3/4	1	1 1/4	1 1/2	2	2 1/2	3	4	6
ΦD		32	37	45	53	63	76	92	120	176
ΦE		20	24	28	36	46	56	73	99	148
h		26	31	38	39	43	47	49	50	60
H		38	44	54	53	66	72	77	81	95

単位:mm

15Aと20Aは共用です