


■ ネジ⇄チューブの接続

PC SUS ストレート

RoHS対応

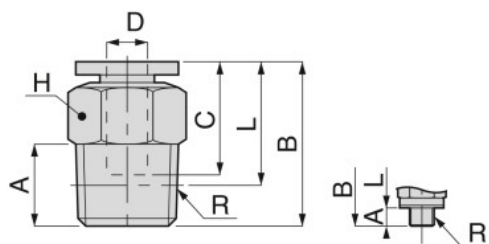

メートルネジタイプ

単位：mm

形 式	チューブ外径 D	R	A	B	L	チューブエンド C	対辺 H	オリフィス径 (mm)	質量 (g)	CAD ファイル名
PC4-M5SUS	4	M5×0.8	3	20.1	17.1	15	10	1.8	5.9	PC4-M5SUS
PC4-M6SUS		M6×1	4	21.1				3	6.2	PC4-M6SUS
PC4-01SUS		R1/8	8		15.1		14		7.8	PC4-01SUS
PC4-02SUS		R1/4	11	15				PC4-02SUS		
PC6-M5SUS	6	M5×0.8	3	22.2	19.2	17.1	12	1.8	8.5	PC6-M5SUS
PC6-M6SUS		M6×1	4	23.2	18.7			3	8.8	PC6-M6SUS
PC6-01SUS		R1/8	8	22.7			14	4.6	8.7	PC6-01SUS
PC6-02SUS		R1/4	11	24.7	17				PC6-02SUS	
PC6-03SUS		R3/8	12	23.7	17.4				26	PC6-03SUS
PC8-01SUS	8	R1/8	8	27.9	23.9	18.2	14	6	15	PC8-01SUS
PC8-02SUS		R1/4	11	26.6	20.6		7	PC8-02SUS		
PC8-03SUS		R3/8	12	23.9	17.6			17	22	PC8-03SUS
PC10-01SUS	10	R1/8	8	30.5	26.5	20.9	17	6	22	PC10-01SUS
PC10-02SUS		R1/4	11	30	24			8.5	20	PC10-02SUS
PC10-03SUS		R3/8	12	29.5	23.2		21		25	PC10-03SUS
PC10-04SUS		R1/2	15	30.5	22.3			47	PC10-04SUS	
PC12-02SUS	12	R1/4	11	36.1	30.1	23.5	21	8.5	41	PC12-02SUS
PC12-03SUS		R3/8	12	32.1	25.8			11	34	PC12-03SUS
PC12-04SUS		R1/2	15	34.1	25.9				47	PC12-04SUS
PC16-03SUS	16	R3/8	12	39.5	33.2	25	24	11	56	PC16-03SUS
PC16-04SUS		R1/2	15	41.5	33.3			13	63	PC16-04SUS

※.テーパネジタイプのL寸法は、ねじ締付け後の参考寸法です。