


PAU SUS ユニオンエイ

RoHS対応

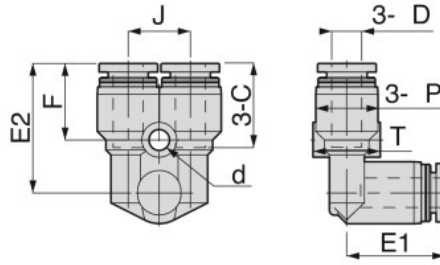


OP. P.868 CAD 2D & 3D

単位：mm

形式	チューブ外径 D	E1	P	チューブエンド C	J	E2	d	F	T	オリフィス径 (mm)	質量 (g)	CAD ファイル名
PAU4SUS	4	17	10	15	10.3	22.8	3.2	14.3	10.4	3.5	7.3	PAU4SUS
PAU6SUS	6	19.9	12.5	17.1	12.5	26.3	4.2	15.6	13.5	4.5	11	PAU6SUS
PAU8SUS	8	22.7	14.5	18.1	14.5	29.4	4.2	16.9	15.6	6.4	15	PAU8SUS
PAU10SUS	10	25.2	17.5	20.4	17.5	33.7	4.2	18.7	18.2	8.5	25	PAU10SUS
PAU12SUS	12	29.6	21	23.6	21	35.4	4.2	20.6	21.7	10.4	38	PAU12SUS

PVU SUS トリポッドユニオン

RoHS対応

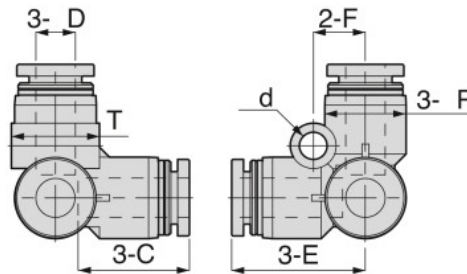


OP. P.868 CAD 2D & 3D

単位：mm

形式	チューブ外径 D	P	チューブエンド C	E	d	F	T	オリフィス径 (mm)	質量 (g)	CAD ファイル名
PVU4SUS	4	10	15	17.9	3.2	6.5	10.4	3	6.8	PVU4SUS
PVU6SUS	6	12.5	17.1	20.7	4.2	8	13.5	4.6	9.4	PVU6SUS
PVU8SUS	8	14.5	18.1	22.7	4.2	10	15.6	6.7	14	PVU8SUS
PVU10SUS	10	17.5	20.4	26.4	4.2	12	18.2	8.3	23	PVU10SUS
PVU12SUS	12	21	23.6	30.4	4.2	14	21.7	10.3	34	PVU12SUS

PE SUS ユニオンティー

RoHS対応

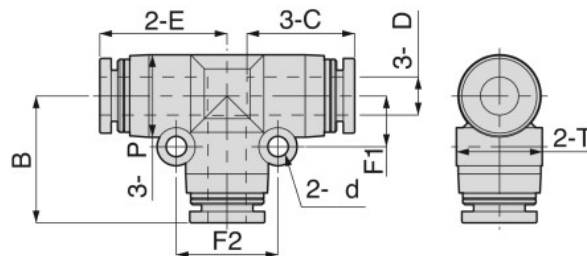

OP. P.868 CAD 2D & 3D

単位：mm

形式	チューブ外径 D	P	チューブエンド C	E	d	T	F1	F2	B	オリフィス径 (mm)	質量 (g)	CAD ファイル名
PE4SUS	4	10	15	17.3	3.2	10.4	6.5	13	17.3	2.8	7.4	PE4SUS
PE6SUS	6	13	17.1	20.2	3.2	13.5	8	16	20.2	4.8	11	PE6SUS
PE8SUS	8	15	18.1	22.2	3.2	15.6	9	18	22.2	6.2	15	PE8SUS
PE10SUS	10	17.5	20.4	25.4	4.2	18.2	12	24	25.4	8.1	25	PE10SUS
PE12SUS	12	21	23.1	28.6	4.2	21.7	14	28	28.4	10	36	PE12SUS
PE16SUS	16	25	24.3	33.3	4.2	25.6	12	24	33.3	13	43	PE16SUS