



KB
NO COVER

ティー カバー無し

RoHS対応

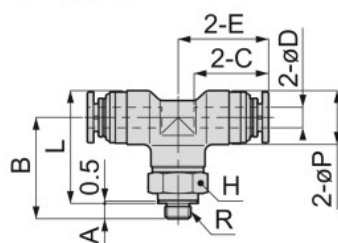

メートルネジの場合

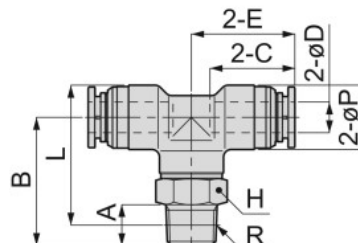

管用テーパネジの場合

単位：mm

形式	チューブ外径 φD	R	A	B	L	E	φP	チューブ C	対辺 H	オリフィス径 (φmm)	質量 (g)	CAD ファイル名
KB4-M5-1□	4	M5×0.8	3	19.8	22.1	17.6	10.5	14.5	10	1.8	23	KB4-M5-1
KB4-01-1□		R1/8	8	22.8	24.1						26	KB4-01-1
KB4-02-1□		R1/4	11	25.8	25				14	2.5	35	KB4-02-1
KB6-M5-1□	6	M5×0.8	3	22	25.3	20.15	12.5	16.6	12	1.8	33	KB6-M5-1
KB6-01-1□		R1/8	8	25	27.3						35	KB6-01-1
KB6-02-1□		R1/4	11	28	28.2				14	4	43	KB6-02-1
KB6-03-1□		R3/8	12	29.8	29.7				17		56	KB6-03-1
KB8-01-1□	8	R1/8	8	28	31.3	22.3	14.5	17.7	14	6	44	KB8-01-1
KB8-02-1□		R1/4	11	31	32.2						50	KB8-02-1
KB8-03-1□		R3/8	12	32.8	33.7				17		63	KB8-03-1
KB10-01-1□	10	R1/8	8	32.5	37.8	26.1	18.5	20	17	6	80	KB10-01-1
KB10-02-1□		R1/4	11	35.5	38.7						83	KB10-02-1
KB10-03-1□		R3/8	12	36.5	39.4				22	8	91	KB10-03-1
KB10-04-1□		R1/2	15	39.5	40.6						118	KB10-04-1
KB12-02-1□	12	R1/4	11	37.5	42.2	29.7	21.5	22.6	21	8	132	KB12-02-1
KB12-03-1□		R3/8	12	38.5	42.9						138	KB12-03-1
KB12-04-1□		R1/2	15	41.5	44.1				22	9	154	KB12-04-1

※1. テーパーネジタイプの L 寸法は、ねじ締付け後の参考寸法です。

※2. 形式末尾の□には、シールゴム材質に FKM を希望される場合記号：-F をご記入ください。