


■ ネジ⇄チューブの接続

NKMF メス隔壁ストレート



RoHS対応

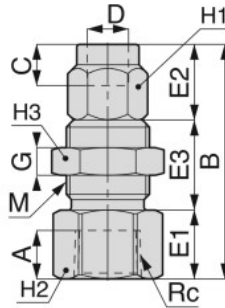

単位：mm

形式	チューブ外径×内径 φD	Rc	A	M	B	E1	E2	E3	G	C	対辺 H1	対辺 H2	対辺 H3	有効断面積 (mm ²)	質量 (g)	CAD ファイル名
NKMF0425-01	4×2.5	Rc1/8	7	M10×1	32.5	10	10.5	12	3	5.5	8	14	12	1	20	NKMF0425-01
NKMF0425-02		Rc1/4	9.5		35.5	13						17			27	NKMF0425-02
NKMF0640-01	6×4	Rc1/8	7	M12×1	34	10	11	13	4	6	10	14	14	5.5	25	NKMF0640-01
NKMF0640-02		Rc1/4	9.5		37	13						17			32	NKMF0640-02
NKMF0640-03		Rc3/8	10.5		39	15						21			44	NKMF0640-03
NKMF0850-01	8×5	Rc1/8	7	M14×1	35	10	12	13	4	7	12	17	17	10	40	NKMF0850-01
NKMF0850-02		Rc1/4	9.5		38	13						17			38	NKMF0850-02
NKMF0850-03		Rc3/8	10.5		40	15						21			50	NKMF0850-03
NKMF0860-01	8×6	Rc1/8	7	M14×1	35	10	12	13	4	7	12	17	17	15	39	NKMF0860-01
NKMF0860-02		Rc1/4	9.5		38	13						17			38	NKMF0860-02
NKMF0860-03		Rc3/8	10.5		40	15						21			50	NKMF0860-03
NKMF1065-02	10×6.5	Rc1/4	9.5	M18×1	40.8	13	14.8	13	4	9	16	21	22	15	74	NKMF1065-02
NKMF1065-03		Rc3/8	10.5		42.8	15						21			68	NKMF1065-03
NKMF1065-04		Rc1/2	13		45.8	18						27			97	NKMF1065-04
NKMF1075-02	10×7.5	Rc1/4	9.5	M18×1	40.8	13	14.8	13	4	9	16	21	22	21	74	NKMF1075-02
NKMF1075-03		Rc3/8	10.5		42.8	15						21			68	NKMF1075-03
NKMF1075-04		Rc1/2	13		45.8	18						27			97	NKMF1075-04
NKMF1280-02	12×8	Rc1/4	9.5	M18×1	41	13	15.4	12.6	4	9	17	21	22	26	73	NKMF1280-02
NKMF1280-03		Rc3/8	10.5		43	15						21			69	NKMF1280-03
NKMF1280-04		Rc1/2	13		46	18						27			94	NKMF1280-04
NKMF1290-02	12×9	Rc1/4	9.5	M18×1	41	13	15.4	12.6	4	9	17	21	22	35	73	NKMF1290-02
NKMF1290-03		Rc3/8	10.5		43	15						21			68	NKMF1290-03
NKMF1290-04		Rc1/2	13		46	18						27			94	NKMF1290-04

285

標準

ミニ

パーブ

耐腐蝕用

ケミカル用

クリーン環境用

帯電防止

耐スパッタ