

VPMB 固定式 真空取出口：横、ワンタッチ継手内蔵ミニタイプ

VPMB0.7RM569


VPMB1RM569

VPMB1.5RM569

VPMB2RM569


VPMB3RM569

VPMB4RM569

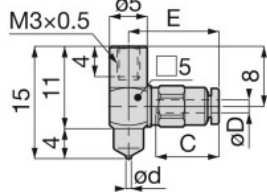


VPMB6R569

VPMB8R569

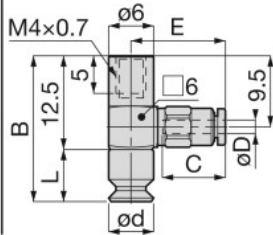

VPMB10R569

VPMB15R(A)569

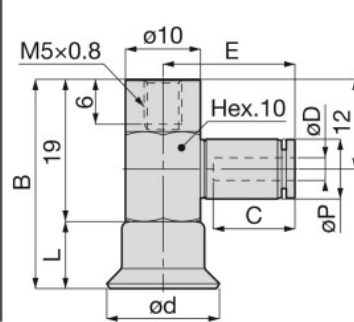


VPMB20R(A) 5 6 9

VPMB25R(A) 5 6 9

VPMB30R(A)569

VPMB40R(A)569

VPMB50R(A) 5 6 9

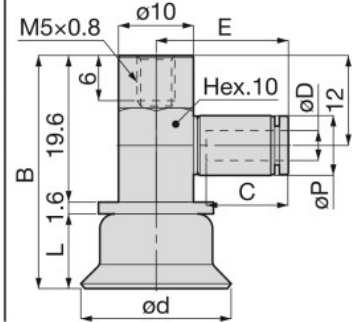

单位：mm

形 式	パッド外径 ød	チューブ外径 øD	B	L	チューブエンド C	E	パッド 接続記号
VPMB0.7RM5-180J	0.7	1.8	—	—	8.4	12	-T4
VPMB0.7RM5-2J		2					
VPMB0.7RM5-3J		3					
VPMB0.7RM5-4J9		4					
VPMB1RM5-180J	1	1.8	—	—	8.4	12	
VPMB1RM5-2J		2					
VPMB1RM5-3J		3					
VPMB1RM5-4J9		4					
VPMB1.5RM5-180J	1.5	1.8	—	—	8.4	12	
VPMB1.5RM5-2J		2					
VPMB1.5RM5-3J		3					
VPMB1.5RM5-4J9		4					
VPMB2RM5-180J	2	1.8	—	—	8.4	12	
VPMB2RM5-2J		2					
VPMB2RM5-3J		3					
VPMB2RM5-4J9		4					
VPMB3RM5-180J	3	1.8	—	—	8.4	12	
VPMB3RM5-2J		2					
VPMB3RM5-3J		3					
VPMB3RM5-4J9		4					
VPMB4RM5-180J	4	1.8	—	—	8.4	12	
VPMB4RM5-2J		2					
VPMB4RM5-3J		3					
VPMB4RM5-4J9		4					
VPMB6R5-180J	6	1.8	19.5	7	8.4	12.5	-T8
VPMB6RM5-2J		2					
VPMB6R5-3J		3					
VPMB6RM5-4J9		4					
VPMB8R5-180J	8	1.8	18	5.5	8.4	12.5	
VPMB8RM5-2J		2					
VPMB8R5-3J		3					
VPMB8RM5-4J9		4					